



Luminator sensor with two weatherproof, corrosionproof floodlights and round mounting plate. PRE-WIRED FOR EASY INSTALLATION. Both floods and sensor have universal ball swivels for easy tool-less adjustment. Lamps not supplied.

Color: White

Weight: 1.4 lbs

<b>Project:</b>	<b>Type:</b>
<b>Prepared By:</b>	<b>Date:</b>

## Technical Specifications

### Listings

#### UL Listing:

Suitable for wet locations

### Electrical

#### Voltage:

120 volts AC 60 Hz

#### Power Consumption:

1W

#### Wall Switch Manual Override:

Two flip logic prevents activation by momentary power outages. Override resets to auto after 6 hours or at dawn. No extra wiring needed.

#### Surge Protection:

Withstands up to 3000 volts

#### Switching Capacity:

300 watts incandescent @ 120 volts, 2.5 amps.

### Sensor Characteristics

#### Time Adjustment:

8 seconds to 10 minutes

#### Photo Control:

Deactivates lights during daylight. Fully adjustable for 24 hour operation or custom applications.

#### Detector Sensitivity:

Adjustable from 100% to 50%

#### Auto Test Logic:

5 minutes of test time when power is turned on, Rests to auto mode without further adjustment

#### Sensor Housing:

Made of tough, corrosion resistant polycarbonate

#### Detection:

110° view

### Construction

#### Floodlights:

Made of tough, corrosion-resistant polycarbonate. Accepts PAR-38 lamps, medium base, 150 watts max. Lamps not included.

### Other


#### Warranty:

3 year sensor warranty

#### Buy American Act Compliance:

RAB values USA manufacturing! Upon request, RAB may be able to manufacture this product to be compliant with the Buy American Act (BAA). Please contact customer service to request a quote for the product to be made BAA compliant.

## Dimensions

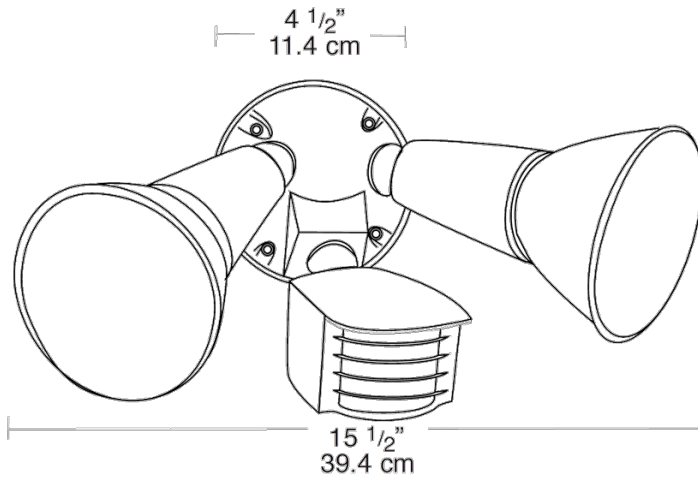

## Features

- 300 Watt switching capacity
- Manual override
- Fully adjustable positioning
- 110° double look down lens
- Tough, vandal resistant lens and grill
- LS300 fits 1/2" standard threaded cover plates
- 3-Year Warranty