


## SLATER® PLASTIC BOXES

## Low-Voltage Brackets

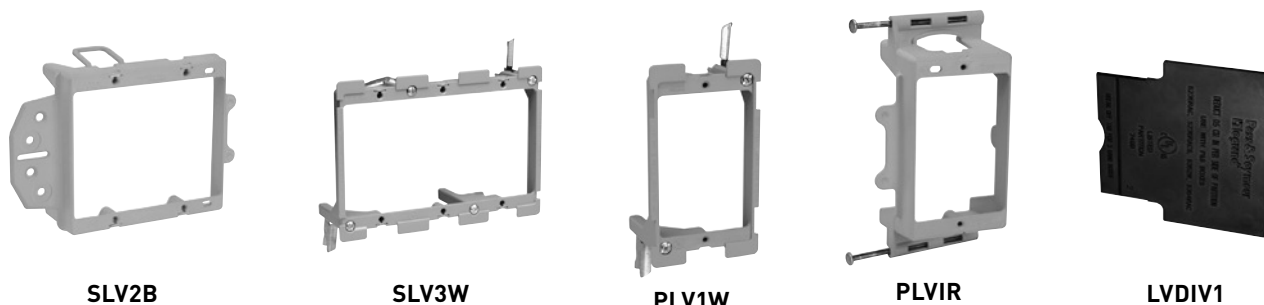

| CATALOG NUMBER  | CU. IN.<br>VOL. | DESCRIPTION   | DIMENSIONS |    |    | WIRE FILL<br>(AWG)                 | QTY. PER<br>CARTON |
|---|-----------------|---|------------|----|----|------------------------------------|--------------------|
|   |                 |   | L          | W  | D  |                                    |                    |
| LOW-VOLTAGE BRACKETS WITH QUICK/CLICK® for class 2 low-voltage applications |                 |   |            |    |    |                                    |                    |
| SDV2B   | 22.5            | Two gang. For dual-voltage. Face mount box and bracket for new construction.  | 3¾         | 4  | 3¾ | 11 No. 14<br>10 No. 12<br>9 No. 10 | 12                 |
| SLV1R   | –               | Single gang. Nail on for new construction.  | 3¾         | 2¼ | –  | –                                  | 12                 |
| SLV1S   | –               | Single gang. Nail on for new construction.  | 3¾         | 2¼ | –  | –                                  | 12                 |
| SLV1B   | –               | Single gang. Face mount bracket for new construction.   | 3¾         | 2¼ | –  | –                                  | 12                 |
| SLV2B   | –               | Two gang. Face mount bracket for new construction.  | 3¾         | 4  | –  | –                                  | 12                 |
| SLV1W   | –               | Single gang. Swing bracket mount for old work.  | 3¾         | 2¼ | –  | –                                  | 12                 |
| SLV2W   | –               | Two gang. Swing bracket mount for old work.   | 3¾         | 4  | –  | –                                  | 12                 |
| SLV3W   | –               | Three gang. Swing bracket mount for old work.   | 3¾         | 6  | –  | –                                  | 12                 |
| LOW-VOLTAGE BRACKETS for class 2 low-voltage applications                   |                 |   |            |    |    |                                    |                    |
| P100WD  | 8.0             | Single Gang. Gangable. Swing bracket for mounting, adjusts from 1¼" down to 1/8", for old work, stand alone applications. | 3¾         | 2  | –  | –                                  | 15                 |
| P100ND  | 8.0             | Single gang. With vertical side bracket for new construction, with wire retaining fingers.                                | 3¾         | 2⅞ | 1¼ | –                                  | 15                 |
| PDV2B   | 22.5            | Two gang. For dual-voltage. Face mount box and bracket for new construction.  | 3¾         | 4  | 3¾ | 11 No. 14<br>10 No. 12<br>9 No. 10 | 12                 |
| PLV1R*  | –               | Single gang. Nail on for new construction.  | 3¾         | 2¼ | –  | –                                  | 12                 |
| PLV1S   | –               | Single gang. Screw on for new construction.   | 3¾         | 2¼ | –  | –                                  | 12                 |
| PLV1B*  | –               | Single gang. Face mount bracket for new construction.   | 3¾         | 2¼ | –  | –                                  | 12                 |
| PLV2B   | –               | Two gang. Face mount bracket for new construction.  | 3¾         | 4  | –  | –                                  | 12                 |
| PLV1W*  | –               | Single gang. Swing bracket mount for old work.  | 3¾         | 2¼ | –  | –                                  | 12                 |
| PLV2W   | –               | Two gang. Swing bracket mount for old work.   | 3¾         | 4  | –  | –                                  | 12                 |
| PLV3W   | –               | Three gang. Swing bracket mount for old work.   | 3¾         | 6  | –  | –                                  | 12                 |
| DIVIDER PLATE   |                 |   |            |    |    |                                    |                    |
| LVDIV1  | -.5             | Suitable for low-voltage or multiple 277V devices. For use with S235RAC, S235RACS, P235RAC, S235S50AC, S354RAC and S352W. | –          | –  | –  | –                                  | 12                 |

All boxes are UL listed.

\* Bulk pack solutions are available for 100 packs.

Please add suffix "BP" to catalog numbers (i.e., PLV1WBP - bulk pack PLV1W).