

DESCRIPTION

The Lumark LVL20UG vaportight area light provides an indoor / outdoor solution in applications where lighting fixture protection is required. The fixture provides equivalent light output up to 100-watt incandescent and 23-watt CFL fixtures with high-quality and long lasting illumination. The fixture is vaportight to protect against dust and moisture. Ideal for garages, storage, and industrial areas.

Catalog #		Type	
Project			
Comments		Date	
Prepared by			

SPECIFICATION FEATURES

Construction

- Durable die-cast aluminum housing and cage provides protection against vandalism
- Vaportight IP65 rating protects against dust and moisture
- Versatile mounting options - wall, ceiling and post
- Frosted glass lens
- (5) 1/2" NPT conduit openings

Electrical

- Frosted glass lens
- Maintenance-free LEDs with L70 50,000 hours of life
- Universal 120-277V power supply
- Fixture operating temperature range from -20°C to 40°C
- cULus listed for wet locations

Optics

- 3500K color temperature
- Fixture produces up to 1450 Lumens

Warranty

- Five-year warranty




LVL20UG VAPORTIGHT LED

Solid State LED


AREA LUMINAIRE

DIMENSIONS

Top View

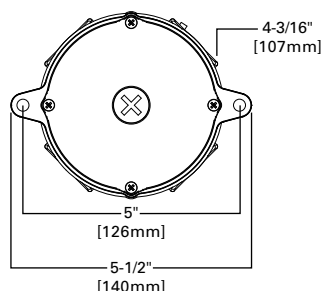


Side View

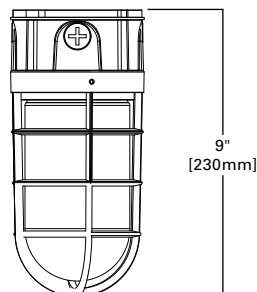


MOUNTING OPTIONS


Wall Mount

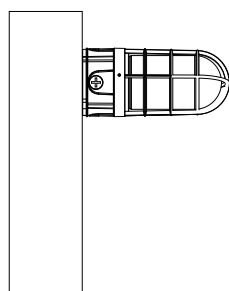

Post Mount

 

Ceiling Mount

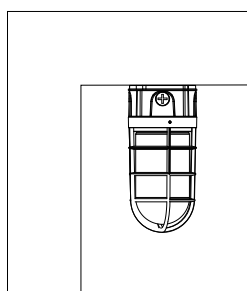

POWER LUMENS

Delivered Lumens	1,450
CCT (Kelvin)	3,500
CRI (Color Rendering Index)	80
Power Consumption (W)	17.7

ORDERING INFORMATION

Model	Description
LVL20UG	Die-cast Aluminum Vaportight LED