


Fitting/KO type



Images

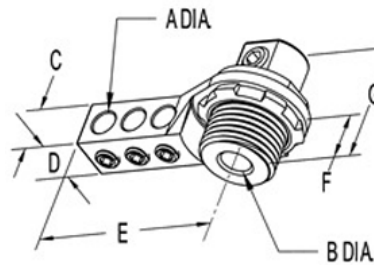

Application

Used to bond one continuous length of grounding conductor to an enclosure thru a 3/4" trade size knockout, inside or outside of an enclosure or panel board and provides 3-equipment bonding terminations. Meets the requirement for Intersystem Bonding. Patented

Product Information

Material: Brass-Body, Stainless Steel Screws, Steel Locknut

Certifications & Codes:

NEMA

Standard FB-1

:

UL File Individual components listed for use with
Number: each other: MCC-075 and IGB-075 in file
E20412

UL

Standard UL467

:

UNSPS 39121613

C:

Patent #D626,087 and 7,927,157
Number:

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 0.26

Dimension B in Inches: 0.48

Dimension C in Inches: 0.50

Dimension D in Inches: 0.50

Dimension E in Inches: 2.10

Dimension F in Inches: 0.56

Dimension G in Inches: 1.25

Catalog ID: MBG-075

UPC Number: 78174702375

Description: 3/4" Mighty-Bond® Intersystem Bonding Bridge and Coupling combination

Application: Used to bond one continuous length of grounding conductor to an enclosure thru a 3/4" trade size knockout, inside or outside of an enclosure or panel board and provides 3-equipment bonding terminations. Meets the requirement for Intersystem Bonding. Patented

Trade Size: 3/4"

Std Pkg Qty: 50

Unit Qty: 10