

CATALOG NUMBER	DESCRIPTION
-------------------	-------------

HIGH-BAYS

ALUMINUM UNIT PACKS

HIGH PRESSURE SODIUM	
HPSS40	400W HPS Multi-Tap 15" w/Lamp
METAL HALIDE	
MHSS40	400W MH Multi-Tap 15" w/Lamp
MHSS40-5T	400W MH 5-Tap 15" w/Lamp
MHSS40-5T-OR	400W MH 5-Tap 15" w/Open Rated Socket Lamp
MHSS40-OR	400W MH Multi-Tap 15" w/Open Rated Socket Lamp
MHSS40Q-5T	400W MH 5-Tap 15" w/Lamp & Quartz Unit Pack
MHSS40Q-5T-OR	400W MH 5-Tap 15" w/Open Rated Socket Lamp & Quartz
PULSE START METAL HALIDE	
MPSS40	400W MP Multi-Tap 15" w/Lamp
MPSS40-OR	400W MP Multi-Tap 15" Open Rated Socket w/Lamp

ACRYLIC UNIT PACKS

MHSS40-PD-5T	400W MH 5-Tap 22" w/Lamp
MHSS40-PD-5T-OR	400W MH 5-Tap 22" w/Open Rated Socket Lamp

STEELER BALLAST HOUSINGS

HIGH PRESSURE SODIUM	
HPSS-250-MT	250W HPS Multi-Tap
HPSS-400-MT	400W HPS Multi-Tap
HPSS-400-480V	400W HPS 480V
HPSS-1000-MT	1000W HPS Multi-Tap
HPSS-1000-480V	1000W HPS 480V
METAL HALIDE	
MHSS-250-MT	250W MH Multi-Tap
MHSS-400-MT	400W MH Multi-Tap
MHSS-400-MT-L/TCB	400W MH Multi-Tap/Less TCB (Use TWMBSS Accessory)
MHSS-400-MT-Q	400W MH Multi-Tap & Quartz
MHSS-400-5T	400W MH 5-Tap
MHSS-400-480V-Q	400W MH 480V & Quartz
MHSS-400-5T-OR	400W MH 5-Tap w/Open Rated Socket
MHSS-400-MT-OR-Q	400W MH Multi-Tap w/Open Rated Socket & Quartz
MHSS-1000-MT	1000W MH Multi-Tap
MHSS-1000-480V	1000W MH 480V
MHSS-1000-MT-Q	1000W MH Multi-Tap & Quartz
MHSS-1000-MT-OR	1000W MH Multi-Tap w/Open Rated Socket
MHSS-1000-MT-OR-Q	1000W MH Multi-Tap w/Open Rated Socket & Quartz
MHSS-1000-480V-OR	1000W MH 480V w/Open Rated Socket
PULSE START METAL HALIDE	
MPSS-320-MT-OR	320W MP Multi-Tap w/Open Rated Socket
MPSS-320-MT-OR-Q	320W MP Multi-Tap w/Open Rated Socket & Quartz
MPSS-350-MT-OR	350W MP Multi-Tap w/Open Rated Socket
MPSS-350-MT-OR-Q	350W MP Multi-Tap w/Open Rated Socket & Quartz
MPSS-400-MT	400W MP Multi-Tap
MPSS-400-MT-Q	400W MP Multi-Tap & Quartz
MPSS-400-MT-OR	400W MP Multi-Tap w/Open Rated Socket
MPSS-400-MT-OR-Q	400W MP Multi-Tap w/Open Rated Socket & Quartz

BENCHMARK BALLAST HOUSINGS

METAL HALIDE	
MHHB-250-MT	250W MH Multi-Tap
MHHB-400-MT	400W MH Multi-Tap
ECON™ ELECTRONIC PULSE START METAL HALIDE	
MDHB-320-E-OR	320W ECON™ MP 208-277V w/Open Rated Socket
MDHB-400-E-OR	400W ECON™ MP 208-277V w/Open Rated Socket

REFLECTORS/ENCLOSURES/WIRE GUARDS [OPEN HIGH-BAYS]

ALUMINUM REFLECTORS

SA15	15" Aluminum High-Bay Reflector
SA15E	15" Aluminum High-Bay Reflector w/Quartz Mounting
SA18	18" Aluminum High-Bay Reflector
SA18E	18" Aluminum High-Bay Reflector w/Quartz Mounting
SA23	23" Aluminum High-Bay Reflector
SA23E	23" Aluminum High-Bay Reflector w/Quartz Mounting
AV19	19" VertX Aisle Lighter

ENCLOSURES

SGB15	15" Safety Glass Bottom
SGB18	18" Safety Glass Bottom
SGB19	19" VertX Safety Glass Bottom
SGB23	23" Safety Glass Bottom

REFLECTORS/ENCLOSURES/WIRE GUARDS [OPEN HIGH-BAYS]

WIRE GUARDS


WG15	15" Wire Guard
WG15/GLC	15" Wire Guard w/Safety Glass
WG18	18" Wire Guard
WG18/GLC	18" Wire Guard w/Safety Glass
WG23	23" Wire Guard

15 OFF THE SHELF—IN-STOCK GUIDE

CATALOG NUMBER	DESCRIPTION
-------------------	-------------

HIGH-BAYS

ALUMINUM UNIT PACKS

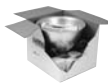


HIGH PRESSURE SODIUM	
HPSS40	400W HPS Multi-Tap 15" w/Lamp
METAL HALIDE	
MHSS40	400W MH Multi-Tap 15" w/Lamp
MHSS40-5T	400W MH 5-Tap 15" w/Lamp
MHSS40-5T-OR	400W MH 5-Tap 15" w/Open Rated Socket Lamp
MHSS40-OR	400W MH Multi-Tap 15" w/Open Rated Socket Lamp
MHSS40Q-5T	400W MH 5-Tap 15" w/Lamp & Quartz Unit Pack
MHSS40Q-5T-OR	400W MH 5-Tap 15" w/Open Rated Socket Lamp & Quartz
PULSE START METAL HALIDE	
MPSS40	400W MP Multi-Tap 15" w/Lamp
MPSS40-OR	400W MP Multi-Tap 15" Open Rated Socket w/Lamp

ACRYLIC UNIT PACKS


MHSS40-PD-5T	400W MH 5-Tap 22" w/Lamp
MHSS40-PD-5T-OR	400W MH 5-Tap 22" w/Open Rated Socket Lamp

STEELER BALLAST HOUSINGS



HIGH PRESSURE SODIUM	
HPSS-250-MT	250W HPS Multi-Tap
HPSS-400-MT	400W HPS Multi-Tap
HPSS-400-480V	400W HPS 480V
HPSS-1000-MT	1000W HPS Multi-Tap
HPSS-1000-480V	1000W HPS 480V
METAL HALIDE	
MHSS-250-MT	250W MH Multi-Tap
MHSS-400-MT	400W MH Multi-Tap
MHSS-400-MT-L/TCB	400W MH Multi-Tap/Less TCB (Use TWMBSS Accessory)
MHSS-400-MT-Q	400W MH Multi-Tap & Quartz
MHSS-400-5T	400W MH 5-Tap
MHSS-400-480V-Q	400W MH 480V & Quartz
MHSS-400-5T-OR	400W MH 5-Tap w/Open Rated Socket
MHSS-400-MT-OR-Q	400W MH Multi-Tap w/Open Rated Socket & Quartz
MHSS-1000-MT	1000W MH Multi-Tap
MHSS-1000-480V	1000W MH 480V
MHSS-1000-MT-Q	1000W MH Multi-Tap & Quartz
MHSS-1000-MT-OR	1000W MH Multi-Tap w/Open Rated Socket
MHSS-1000-MT-OR-Q	1000W MH Multi-Tap w/Open Rated Socket & Quartz
MHSS-1000-480V-OR	1000W MH 480V w/Open Rated Socket
PULSE START METAL HALIDE	
MPSS-320-MT-OR	320W MP Multi-Tap w/Open Rated Socket
MPSS-320-MT-OR-Q	320W MP Multi-Tap w/Open Rated Socket & Quartz
MPSS-350-MT-OR	350W MP Multi-Tap w/Open Rated Socket
MPSS-350-MT-OR-Q	350W MP Multi-Tap w/Open Rated Socket & Quartz
MPSS-400-MT	400W MP Multi-Tap
MPSS-400-MT-Q	400W MP Multi-Tap & Quartz
MPSS-400-MT-OR	400W MP Multi-Tap w/Open Rated Socket
MPSS-400-MT-OR-Q	400W MP Multi-Tap w/Open Rated Socket & Quartz

BENCHMARK BALLAST HOUSINGS



METAL HALIDE	
MHBB-250-MT	250W MH Multi-Tap
MHBB-400-MT	400W MH Multi-Tap
ECON™ ELECTRONIC PULSE START METAL HALIDE	
MDHB-320-E-OR	320W ECON™ MP 208-277V w/Open Rated Socket
MDHB-400-E-OR	400W ECON™ MP 208-277V w/Open Rated Socket

REFLECTORS/ENCLOSURES/WIRE GUARDS [OPEN HIGH-BAYS]

ALUMINUM REFLECTORS

SA15	15" Aluminum High-Bay Reflector
SA15E	15" Aluminum High-Bay Reflector w/Quartz Mounting
SA18	18" Aluminum High-Bay Reflector
SA18E	18" Aluminum High-Bay Reflector w/Quartz Mounting
SA23	23" Aluminum High-Bay Reflector
SA23E	23" Aluminum High-Bay Reflector w/Quartz Mounting
AV19	19" VertX Aisle Lighter

ENCLOSURES

SGB15	15" Safety Glass Bottom
SGB18	18" Safety Glass Bottom
SGB19	19" VertX Safety Glass Bottom
SGB23	23" Safety Glass Bottom

REFLECTORS/ENCLOSURES/WIRE GUARDS [OPEN HIGH-BAYS]

WIRE GUARDS

WG15	15" Wire Guard
WG15/GLC	15" Wire Guard w/Safety Glass
WG18	18" Wire Guard
WG18/GLC	18" Wire Guard w/Safety Glass
WG23	23" Wire Guard

15 OFF THE SHELF—IN-STOCK GUIDE