

Search Catalog

By Keyword

All Categories CVJ Series Enclosure with 2 Captive Stainless Steel Cover Screws and a Stainless Steel Piano Hinge

Shopping Cart [0 items](#)
Request for Quote [0 items](#)

[All Categories](#) > [APO Series Enclosures](#)
[7" X 6" to 24" X 24"](#) > [CVJ Series Enclosure with 2 Captive Stainless Steel Cover Screws and a Stainless Steel Piano Hinge](#) > Item # CVJ1210HW

Item # CVJ1210HW CVJ Series Enclosure with 2 Captive Stainless Steel Cover Screws and a Stainless Steel Piano Hinge
\$271.2156

-
-
-


CVJ Series Enclosure with 2 Captive Stainless Steel Cover Screws and a Stainless Steel Piano Hinge

Clearview Bonded Window on Cover

- All CVJ Series enclosures are designed to meet the Joint Industrial Council (JIC) standards in the United States.
- CVJ's are made from corrosion resistant hot compression molded fiberglass reinforced polyester with transparent lexana window. These enclosures do not contain halogens.
- The CVJ series "HW" enclosures have two stainless steel captive screws and a stainless steel piano hinge that secure the cover to the base. Two threaded brass inserts contained in the base secure the cover screws, rivets connect the hinge to the cover and self-tapping screws connect the hinge to the base.
- Seven sizes are available from 6 x 6 inch to 18 x 16 inch
- Vynckier's CVJ enclosures are capable of withstanding continuous temperatures from -58°F (-50°C) up to 302°F (150°C).
- CVJ enclosures are capable of equipment and operators from indirect electrical contact.
- All CVJ enclosures are UL listed per UL Standard 508 for NEMA 3, 3R, 4, 4X, 12 and 13; CSA Certified per Standard C22.2-0, 0.4, 0.7, 0.6, 94 Type 3, 3R, 4, 4X, 12 and 13.



[larger image](#)

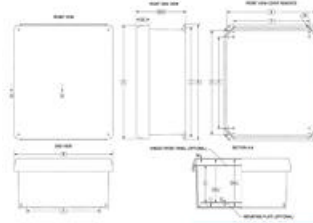

[larger image](#)

Specifications	VJ Series Features	CVJ Clear Cover Enclosures - Optional Accessories
FRP UL Type Rating	3, 3R, 4, 4X, 12, 13	
Temperature Resistance (°F)	-58 to +302	
Temperature Resistance (°C)	-50 to +150	
Outside Height (inch)	13.31	
Outside Height (mm)	338.2	
Outside Width (inch)	11.31	
Outside Width (mm)	287.4	

Outside Depth (inch)	5.59
Outside Depth (mm)	142.0
Inside Dim. A (inch)	12.00
Inside Dim. A (mm)	304.8
Inside Dim. B (inch)	10.00
Inside Dim. B (mm)	254.0
Inside Dim. C (inch)	4.84
Inside Dim. C (mm)	123.0
Weight (lbs)	6.3
Weight (kg)	2.85
Mounting Plate Part No. (Aluminum Steel Non-Metallic)	MP1210A MP1210N MP1210S
Dim. Mounting Plate (inch)	10.50 x 8.88
Dim. Mounting Plate (mm)	267 x 226
Front Panel - Plain	VFP1210A
Front Panel - Hinged	VFPH1210A
Dim. E (inch)	1.62
Dim. E (mm)	41.2
Dim. F (inch)	4.13
Dim. F (mm)	105.0
Dim. I (inch)	0.37
Dim. I (mm)	9.5
Dim. J (inch)	12.76
Dim. J (mm)	324.0
Dim. K (inch)	8.00
Dim. K (mm)	203.2
Dim. L (inch)	0.31
Dim. L (mm)	8.0
Dim. M (inch)	0.12
Dim. M (mm)	3.0
Dim. N (inch)	13.50
Dim. N (mm)	343.0
Dim. O (inch)	8.25
Dim. O (mm)	209.5
Dim. P (inch)	10.26
Dim. P (mm)	260.5
Dim. Q (inch)	0.08
Dim. Q (mm)	2.0
Dim. R (inch)	5.30
Dim. R (mm)	134.5
Window Height (inch)	12.00
Window Height (mm)	305
Window Width (inch)	10.00
Window Width (mm)	254
UPC Code	635394005142
Availability	Standard Modified