

Search Catalog By Keyword <input type="text"/> <input type="button" value="Go"/> <input checked="" type="radio"/> All Categories <input type="radio"/> CVJ Series Enclosure with 2 Captive Stainless Steel Cover Screws and 2 Non-Metallic Hinges	<input type="button" value="View Cart"/> <input type="button" value="View RFQ's"/> Shopping Cart 0 items Request for Quote 0 items
--	--

[All Categories](#) > [APO Series Enclosures](#) > [7" X 6" to 24" X 24"](#) > [CVJ Series Enclosure with 2 Captive Stainless Steel Cover Screws and 2 Non-Metallic Hinges](#) > [Item # CVJ1412NHW](#)

Item # CVJ1412NHW CVJ Series Enclosure with 2 Captive Stainless Steel Cover Screws and 2 Non-Metallic Hinges
 \$352.3997


- [Printable Page](#)
- [Email This Page](#)
- [Save To Favorites](#)

CVJ Series Enclosure with 2 Captive Stainless Steel Cover Screws and 2 Non-Metallic Hinges
 Clearview Bonded Window on Cover

- All CVJ Series enclosures are designed to meet the Joint Industrial Council (JIC) standards in the United States.
- CVJ's are made from corrosion resistant hot compression molded fiberglass reinforced polyester with transparent lexana window. These enclosures do not contain halogens.
- The CVJ series "NHW" enclosures include two stainless steel captive screws and two non-metallic hinges that secure the cover to the base. Two threaded brass inserts contained in the base secure the cover screws. Self-tapping screws connect the hinges to the cover and base.
- Seven sizes are available from 6 x 6 inch to 18 x 16 inch
- Vynckier's CVJ enclosures are capable of withstanding continuous temperatures from -58°F (-50°C) up to 302° F (150° C).
- CVJ enclosures are capable of equipment and operators from indirect electrical contact.
- All CVJ enclosures are UL listed per UL Standard 508 for NEMA 3, 3R, 4, 4X, 12 and 13; CSA Certified per Standard C22.2-0, 0.4, 0.7, 0.6, 94 Type 3, 3R, 4, 4X, 12 and 13.
- Clearview Bonded window on cover



[larger image](#)

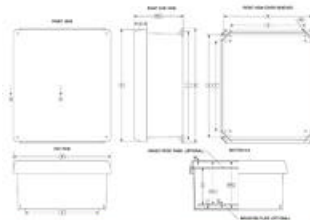

[larger image](#)

Specifications	VJ Series Features	CVJ Clear Cover Enclosures - Optional Accessories
FRP UL Type Rating		3, 3R, 4, 4X, 12, 13
Resistance (°F)		-58 to +302
Temperature Resistance (°C)		-50 to +150
Outside Height (inch)		15.32
Outside Height (mm)		389
Outside Width (inch)		13.30
Outside Width (mm)		338

Outside Depth (inch)	6.70
Outside Depth (mm)	170.0
Inside Dim. A (inch)	14.00
Inside Dim. A (mm)	355.6
Inside Dim. B (inch)	12.00
Inside Dim. B (mm)	304.8
Inside Dim. C (inch)	5.82
Inside Dim. C (mm)	147.8
Weight (lbs)	8.6
Weight (kg)	3.90
Mounting Plate Part No. (Aluminum Steel Non-Metallic)	MP1412A MP1412N MP1412S
Dim. Mounting Plate (inch)	12.75 x 10.88
Dim. Mounting Plate (mm)	324 x 276
Front Panel - Plain	VFP1412A
Front Panel - Hinged	VFPH1412A
Dim. E (inch)	1.75
Dim. E (mm)	44.8
Dim. F (inch)	4.92
Dim. F (mm)	125.0
Dim. I (inch)	0.50
Dim. I (mm)	12.7
Dim. J (inch)	14.75
Dim. J (mm)	374.6
Dim. K (inch)	10.00
Dim. K (mm)	254.0
Dim. L (inch)	0.31
Dim. L (mm)	8.0
Dim. M (inch)	0.12
Dim. M (mm)	3.0
Dim. N (inch)	15.51
Dim. N (mm)	394.0
Dim. O (inch)	10.24
Dim. O (mm)	260.0
Dim. P (inch)	12.26
Dim. P (mm)	311.5
Dim. Q (inch)	0.08
Dim. Q (mm)	2.0
Dim. R (inch)	6.40
Dim. R (mm)	162.5
Window Height (inch)	14.00
Window Height (mm)	356
Window Width (inch)	12.00
Window Width (mm)	305
UPC Code	635394005272
Availability	Standard Modified