

Search Catalog By Keyword <input type="text"/> <input type="button" value="Go"/> <input checked="" type="radio"/> All Categories <input type="radio"/> CVJ Series Enclosure with Stainless Steel Twist Latch(s) and 2 Non-Metallic Hinges	<input type="button" value="View Cart"/> <input type="button" value="View RFQ's"/> Shopping Cart 0 items Request for Quote 0 items
--	--

[All Categories](#) > [APO Series Enclosures](#)
[7" X 6" to 24" X 24"](#) > [CVJ Series Enclosure with Stainless Steel Twist Latch\(s\) and 2 Non-Metallic Hinges](#) > Item # CVJ1614NHWLL2

<input type="button" value="Request Information"/>	<input type="button" value="Add to Cart"/>	<input type="button" value="Request Quote"/>
--	--	--

Item # CVJ1614NHWLL2 CVJ Series Enclosure with Stainless Steel Twist Latch(s) and 2 Non-Metallic Hinges
 \$418.3027


<input type="button" value="Printable Page"/>
<input type="button" value="Email This Page"/>
<input type="button" value="Save To Favorites"/>

CVJ Series Enclosure with Stainless Steel Twist Latch(s) and 2 Non-Metallic Hinges
 Clearview Bonded Window on Cover

- All CVJ Series enclosures are designed to meet the Joint Industrial Council (JIC) standards in the United States.
- CVJ's are made from corrosion resistant hot compression molded fiberglass reinforced polyester with transparent lexana window. These enclosures do not contain halogens.
- The CVJ series "NHWLL" enclosures include one or two stainless steel twist latches to secure one side of the cover to the base with two non-metallic hinges that secures the other. Self-tapping screws connect the hinge to the cover and base.
- Seven sizes are available from 6 x 6 inch to 18 x 16 inch
- Vynckier's CVJ enclosures are capable of withstanding continuous temperatures from -58°F (-50° C) up to 302° F (150° C).
- CVJ enclosures are capable of equipment and operators from indirect electrical contact.
- All CVJ enclosures are UL listed per UL Standard 508 for NEMA 3, 3R, 4, 4X, 12 and 13; CSA Certified per Standard C22.2-0, 0.4, 0.7, 0.6, 94 Type 3, 3R, 4, 4X, 12 and 13.



[larger image](#)

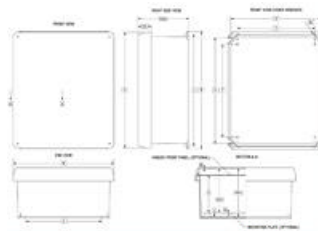

[larger image](#)

Specifications	VJ Series Features	CVJ Clear Cover Enclosures - Optional Accessories
FRP UL Type Rating	3, 3R, 4, 4X, 12, 13	
Temperature Resistance (°F)	-58 to +302	
Temperature Resistance (°C)	-50 to +150	
Outside Height (inch)	17.31	
Outside Height (mm)	439.8	
Outside Width (inch)	15.31	
Outside Width (mm)	389	
Outside Depth (inch)	6.69	

Outside Depth (mm)	170.0
Inside Dim. A (inch)	16.00
Inside Dim. A (mm)	406.4
Inside Dim. B (inch)	14.00
Inside Dim. B (mm)	355.6
Inside Dim. C (inch)	5.82
Inside Dim. C (mm)	147.8
Weight (lbs)	10.6
Weight (kg)	4.80
Mounting Plate Part No. (Aluminum Steel Non-Metallic)	MP1614A MP1614N MP1614S
Dim. Mounting Plate (inch)	14.75 x 12.88
Dim. Mounting Plate (mm)	375 x 327
Front Panel - Plain	VFP1614A
Front Panel - Hinged	VFPH1614A
Dim. E (inch)	1.75
Dim. E (mm)	44.4
Dim. F (inch)	5.01
Dim. F (mm)	127.3
Dim. I (inch)	0.50
Dim. I (mm)	12.7
Dim. J (inch)	16.75
Dim. J (mm)	425.5
Dim. K (inch)	12.01
Dim. K (mm)	305.0
Dim. L (inch)	0.31
Dim. L (mm)	8.0
Dim. M (inch)	0.12
Dim. M (mm)	3.0
Dim. N (inch)	17.52
Dim. N (mm)	445.0
Dim. O (inch)	12.24
Dim. O (mm)	311.0
Dim. P (inch)	14.25
Dim. P (mm)	362.0
Dim. Q (inch)	0.08
Dim. Q (mm)	2.0
Dim. R (inch)	6.40
Dim. R (mm)	162.5
Latch Spacing (inch)	9.56
Latch Spacing (mm)	243
Window Height (inch)	16.00
Window Height (mm)	406
Window Width (inch)	14.00
Window Width (mm)	356
UPC Code	635394005418