

**Search Catalog**

By Keyword

All Categories  VJ Series Enclosure with 2 Captive Stainless Steel Cover Screws and 2 Non-Metallic Hinges

Shopping Cart [0 items](#)  
Request for Quote [0 items](#)

[All Categories](#) > [CVJ Series Enclosure with Stainless Steel Twist Latch\(s\) and 2 Non-Metallic Hinges](#) > [VJ Series Enclosure with 2 Captive Stainless Steel Cover Screws and 2 Non-Metallic Hinges](#) > [Item # VJ606NHW](#)

**Item # VJ606NHW VJ Series Enclosure with 2 Captive Stainless Steel Cover Screws and 2 Non-Metallic Hinges**  
\$93.3451


- [Printable Page](#)
- [Email This Page](#)
- [Save To Favorites](#)

**VJ Series Enclosure with 2 Captive Stainless Steel Cover Screws and 2 Non-Metallic Hinges**

- All VJ Series enclosures are designed to meet the Joint Industrial Council (JIC) standards in the United States.
- VJ's are made from corrosion resistant hot compression molded fiberglass reinforced polyester and do not contain halogens.
- The VJ series "NHW" enclosures include two stainless steel captive screws and two non-metallic hinges that secure the cover to the base. Two threaded brass inserts contained in the base secure the cover screws. Self-tapping screws connect the hinge to the cover and base.
- Seven sizes are available from 6 x 6 inch to 18 x 16 inch
- Vynckier's VJ enclosures are capable of withstanding continuous temperatures from -58°F (-50°C) up to 302°F (150°C).
- VJ enclosures provide protection for equipment and operators from indirect electrical contact.
- All VJ enclosures are UL listed per UL Standard 508 for NEMA 3, 3R, 4, 4X, 12 and 13; CSA Certified per Standard C22.2-0, 0.4, 0.7, 0.6, 94 Type 3, 3R, 4, 4X, 12 and 13.



[larger image](#)

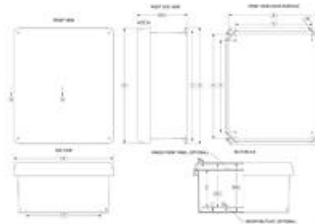

[larger image](#)

Specifications	<a href="#">VJ Series Features</a>	<a href="#">VJ Polyester Cover Enclosures - Optional Accessories</a>
<b>FRP UL Type Rating</b>	3, 3R, 4, 4X, 12, 13	
<b>Temperature Resistance (°F)</b>	-58 to +302	
<b>Temperature Resistance (°C)</b>	-50 to +150	
<b>Outside Height (inch)</b>	7.31	
<b>Outside Height (mm)</b>	185.8	
<b>Outside Width (inch)</b>	7.31	
<b>Outside Width (mm)</b>	185.8	
<b>Outside Depth (inch)</b>	4.96	

<b>Outside Depth (mm)</b>	126.0
<b>Inside Dim. A (inch)</b>	6.00
<b>Inside Dim. A (mm)</b>	152.4
<b>Inside Dim. B (inch)</b>	6.00
<b>Inside Dim. B (mm)</b>	152.4
<b>Inside Dim. C (inch)</b>	4.21
<b>Inside Dim. C (mm)</b>	107.0
<b>Weight (lbs)</b>	2.8
<b>Weight (kg)</b>	1.27
<b>Mounting Plate Part No. (Aluminum Steel Non-Metallic)</b>	MP606A MP606N MP606S
<b>Dim. Mounting Plate (inch)</b>	4.88 x 4.88
<b>Dim. Mounting Plate (mm)</b>	124 x 124
<b>Front Panel - Plain</b>	VFP606A
<b>Front Panel - Hinged</b>	VFP606A
<b>Dim. E (inch)</b>	1.38
<b>Dim. E (mm)</b>	35.0
<b>Dim. F (inch)</b>	3.76
<b>Dim. F (mm)</b>	95.5
<b>Dim. I (inch)</b>	0.37
<b>Dim. I (mm)</b>	9.5
<b>Dim. J (inch)</b>	6.75
<b>Dim. J (mm)</b>	171.5
<b>Dim. K (inch)</b>	4.00
<b>Dim. K (mm)</b>	101.6
<b>Dim. L (inch)</b>	0.31
<b>Dim. L (mm)</b>	8.0
<b>Dim. M (inch)</b>	0.12
<b>Dim. M (mm)</b>	3.0
<b>Dim. N (inch)</b>	7.50
<b>Dim. N (mm)</b>	190.5
<b>Dim. O (inch)</b>	4.25
<b>Dim. O (mm)</b>	108.0
<b>Dim. P (inch)</b>	4.25
<b>Dim. P (mm)</b>	108.0
<b>Dim. Q (inch)</b>	0.08
<b>Dim. Q (mm)</b>	2.0
<b>Dim. R (inch)</b>	4.67
<b>Dim. R (mm)</b>	118.5
<b>UPC Code</b>	635394014106
<b>Availability</b>	Stock
<b>Shipment in Days</b>	1

[Request Information](#) [Add to Cart](#) [Request Quote](#)