

# NEER Service Entrance Flashings

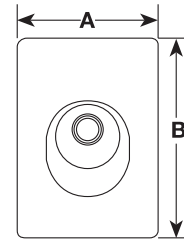
## NC: No Caulk, Galvanized Steel




### Applications

- These are used to provide a watertight connection between the roof line and ventilation pipes.

### Standard Material

- NC and 1000: galvanized steel
- 1000-N: neoprene



	Trade Size (Inches)	Catalog Number	Dimensions in Inches/Millimeters	
			A	B
	<b>NC: No Caulk, Galvanized</b>			
	1-1/4 - 1-1/2	<b>NC-1069</b>	8.75/222.3	12.50/317.5
	2	<b>NC-1070</b>	8.88/225.6	12.50/317.5
	2-1/2 - 3-1/2	<b>NC-1071</b>	10.75/273.1	14.50/368.3
	<b>1000: Galvanized with Collar</b>			
	2	<b>1070</b>	10.75/273.1	14.50/368.3
	2-1/2	<b>1071</b>	10.75/273.1	14.50/368.3
	<b>1000-N: All-Neoprene</b>			
	1-1/4 - 1-1/2	<b>1069-N</b>	9.00/228.6	11.25/285.8
	2	<b>1070-N</b>	9.00/228.6	11.50/292.1
	2-1/2 - 3-1/2	<b>1071-N</b>	9.00/228.6	11.50/292.1
	3	<b>1072-N</b>	10.00/254.0	13.50/342.9

# NEER Service Entrance Flashings

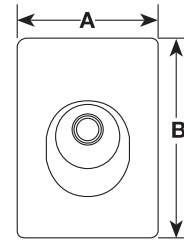
## NC: No Caulk, Galvanized Steel




### Applications

- These are used to provide a watertight connection between the roof line and ventilation pipes.

### Standard Material

- NC and 1000: galvanized steel
- 1000-N: neoprene



	Trade Size (Inches)	Catalog Number	Dimensions in Inches/Millimeters	
			A	B
<b>NC: No Caulk, Galvanized</b>				
	1-1/4 - 1-1/2	<b>NC-1069</b>	8.75/222.3	12.50/317.5
	2	<b>NC-1070</b>	8.88/225.6	12.50/317.5
	2-1/2 - 3-1/2	<b>NC-1071</b>	10.75/273.1	14.50/368.3
<b>1000: Galvanized with Collar</b>				
	2	<b>1070</b>	10.75/273.1	14.50/368.3
	2-1/2	<b>1071</b>	10.75/273.1	14.50/368.3
<b>1000-N: All-Neoprene</b>				
	1-1/4 - 1-1/2	<b>1069-N</b>	9.00/228.6	11.25/285.8
	2	<b>1070-N</b>	9.00/228.6	11.50/292.1
	2-1/2 - 3-1/2	<b>1071-N</b>	9.00/228.6	11.50/292.1
	3	<b>1072-N</b>	10.00/254.0	13.50/342.9