

Type \_\_\_\_\_

-20

P2533

**Finish**


Catalog No	Antique Bronze
P2533	-20

**Dimensions (Inches)**

A	B
54	18-3/4

**Blades**

Side 1 & 2	Toasted Oak
------------	-------------

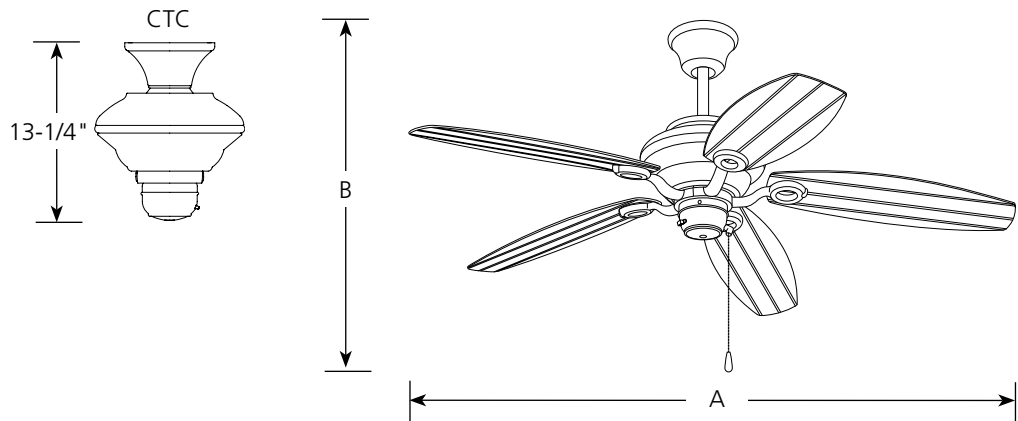

<b>ENERGYGUIDE</b>	
<p>Estimated Yearly Energy Cost</p> <p><b>\$11</b></p> <p>\$3       \$34</p> <p>Cost Range of Similar Models (19" - 84")</p> <p><small>• Based on 12 cents per kWh and 6.4 hours use per day • Your cost depends on rates and use • Energy Use: 40 Watts</small></p>	<p><b>Airflow</b></p> <p><b>2,980</b></p> <p>Cubic Feet Per Minute</p> <p><small>• The higher the airflow, the more air the fan will move • Airflow Efficiency: 74 Cubic Feet Per Minute Per Watt</small></p>

Fan mounted as close-to-ceiling.

**Specifications:**

General

- 30 year limited warranty

Blades

- Five blades
- 12 degree pitch
- Sure Connect blade attachment system
  - Screws preinstalled in blades for attachment to motor arms
  - Special guides align blades to motor arms
  - Preinstalled rubber isolation pads minimize vibration noise

Motor

- ABS all-weather blade construction
- Three speed control; manual reverse control
- 153mm dia x 18mm high
- Pull chain is antique brass with walnut fob

Mounting

- Dual ceiling mounting on downrod, or close to ceiling
- A 3/4" x 6" downrod is included. Longer accessory downrods can be ordered separately
- Standard canopy designed for sloped ceilings up to 45 degrees (12:12 ceiling pitch) using downrod supplied or accessory downrods
- Oversized, textured die cast hanger ball reduces noise and wobble vibrations
- Canopy covers standard recessed 4" octagonal outlet box. Note: An outlet box assembly designed for fan installation is required (not included)

- Mounting hardware is included

Electrical

- 80" lead wires included
- Light fixture adaptable

- Pre-wired

Labeling

- UL wet location listed

**ENERGY INFORMATION AT HIGH SPEED**

AIRFLOW: 4587 CFM cubic feet per minute

ELECTRICITY USE: 66 watts (excludes lights)

AIRFLOW EFFICIENCY: 69 cubic feet per minute per watt

Progress Lighting  
701 Millennium Blvd.  
Greenville, South Carolina  
29607