
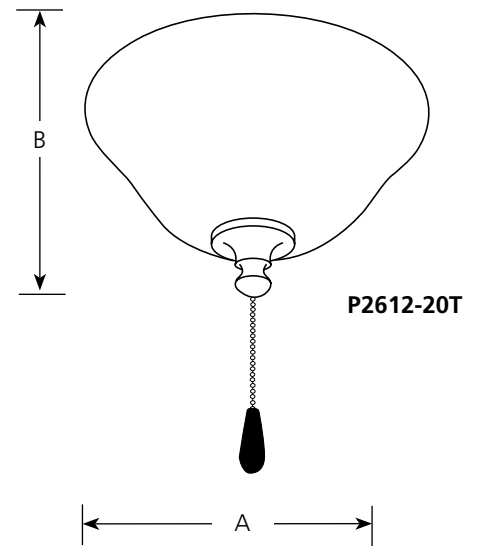


Type _____

	-09	-20	-20T	-30
P2612	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>

Finish

Catalog No.	Brushed Nickel	Antique Bronze	Antique Bronze	White	Dimensions (Inches)	
					A	B
P2612	-09	-20	-20T	-30	10-3/4	6

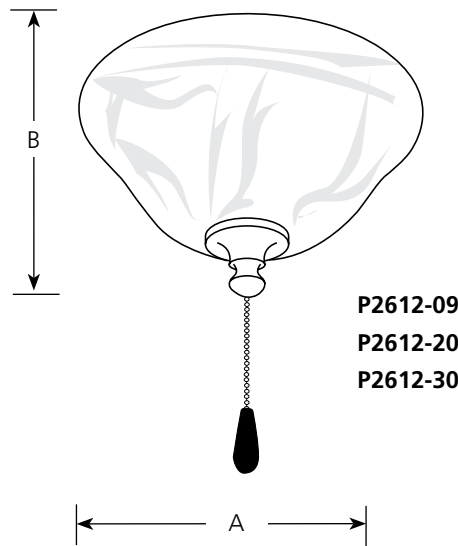

Specifications:

General

- Brushed Nickel (-09), Antique Bronze (-20) and White (-30) has an Alabaster glass bowl. Antique Bronze (-20T) has an etched light umber glass bowl.
- Pull chain on brushed nickel (-09) is chrome with a maple fob and white (-30) finish is chrome with a white fob, the rest are antique brass with a medium oak fob
- Utilizes (3) 40-watt candelabra based lamps. Included.

Mounting

- Universal - use with any indoor fan with a 1/8" IPS light kit mount.

Electrical

- Porcelain candelabra sockets
- Quick connect wiring to fan
- Prewired
- 190-watt limiter

Labeling

- UL listed