


Type	_____	
	-15	-20
P5138	<input type="checkbox"/>	<input type="checkbox"/>

Catalog No.	Finish		Lamping	Dimensions (Inches)		
	Polished Chrome	Antique Bronze		A	B	C
P5138	-15	-20	1 (m) 100w	12	12-3/4	79

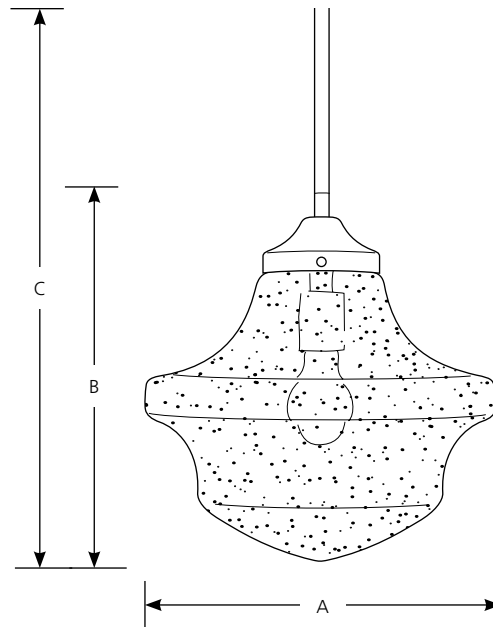

Specifications:

General

- Clear Light Seeded glass (-15), Clear Light Umber Seeded glass (-20): 12" dia.
- Plated Polished Chrome (-15) finish
- Painted Antique Bronze (-20) finish
- Steel construction
- Two 6", one 12", two 15" lengths of stem included
- 6 links of 9 gauge chain included
- Companion fixtures are available

Mounting

- Ceiling stem mounted with 6 links of chain mount
- Canopy covers a standard 4" hexagonal recessed outlet box
- Mounting strap for outlet box included

Electrical

- Medium base socket
- 10 feet of wire supplied
- Pre-wired

Labeling

- UL-CUL Dry location listed