



UPC: 192552024358



Color: White



Weight: 0.2 lbs

Project:	Type:
Prepared By:	Date:

Technical Specifications

Performance

Product Type:

PAR20

Description:

This dimmable, PAR20 is a perfect replacement for legacy halogen lamps. This lamp offers >80 CRI, wet rated, and great for use outdoors.

Wattage Equivalency:

50W Halogen

Input Wattage:

5W

Lumens (Nominal):

500 Lm

Efficacy:

100 Lm/W

L70 Lifespan:

15,000-Hour LED lifespan based on IES LM-70 results

Beam Angle:

40-degree

Electrical

THD:

<80%

Power Factor:

>0.7

Input Voltage:

120V

Operating Frequency:

60 Hz

Operating Temperature:

-13°F to 113°F (-25°C to 45°C)

LED Characteristics

Color Accuracy (CRI):

≥80 CRI

R9 Value:

High color performance with R9 greater than or equal to 0

Color Consistency:

<6-step MacAdam Ellipse binning to achieve consistent fixture-to-fixture color

Construction

Base Type:

E26 Edison

Finish:

White

Bulb Shape:

PAR20

Endcap Material:

Nickel-Aluminum

Lens:

Single optic and full face lens for precise beam angle control

Compliance

Safety Listing:

UL Listed

Environment:

Suitable for use in indoor and outdoor application in dry, damp, and wet environments

Fixture Rating:

Suitable for use in enclosed fixtures

Energy Star Approved:

This product is ENERGY STAR® Version 2.2 Certified

T20 Compliant:

Not Title 20 Compliant

California Title 24 JA8 Compliant:

Not Compliant

California Energy Commission (CEC) Status:

Not Lawful for Sales in California

NSF Listed:

No

RoHS:

Mercury and UV free. RoHS-compliant components.

FCC:

Complies with Part 15B of the FCC Rules

PAR20-5-830-40D-DIM



Dimmable:

Yes, TRIAC/ELV
See Dimmer Compatibility List

Enclosure Material:

Plastic

Technical Specifications (continued)

Other

Warranty:

RAB warrants that our LED products will be free from defects in materials and workmanship for a period of three (3) years from the date of delivery to the end user, including coverage of light output, color stability, driver performance and fixture finish. RAB's warranty is subject to all terms and conditions found at rablighting.com/warranty.

Note:

All values are typical (tolerance +/- 10%)


Buy American Act Compliance:

RAB values USA manufacturing! Upon request, RAB may be able to manufacture this product to be compliant with the Buy American Act (BAA). Please contact customer service to request a quote for the product to be made BAA compliant.

Case and Pallet Dimensions

	QTY	LENGTH (in)	WIDTH (in)	HEIGHT (in)
CASE	12	10.787	8.15	4.094
PALLET	2592	46.024	35.236	49.134

Dimension

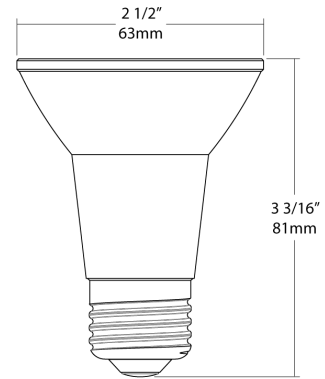

Features

- Energy efficient replacement for incandescent and halogen PAR lamps
- Constructed from durable materials which lowers risk of breakage
- Rated for use in enclosed and open fixtures in wet locations
- Single optic and full face lens for precise beam angle control
- Longer lifespan compared to legacy equivalents minimizes replacement and maintenance costs
- Replacements for halogen PAR lamps. Dimmable LED with 80 CRI and wet rated, great for use outdoors.