



Project:

Type:

Prepared By:

Date:



UPC: 019813749952

**Features and Benefits**

Energy efficient replacement for incandescent and halogen PAR lamps  
 Constructed from durable materials which lowers risk of breakage  
 Rated for use in enclosed and open fixtures in wet locations  
 Single optic and full face lens for precise beam angle control  
 Longer lifespan compared to legacy equivalents minimizes replacement and maintenance costs  
 Replacements for halogen PAR lamps. Dimmable LED with 80 CRI and wet rated, great for use outdoors.

**Technical Specifications****Performance****Product Type:**

PAR

**Input Wattage:**

15W

**Lumens:**

1,050lm

**Efficacy:**

70lm/W

**L70 Lifespan:**

25,000 Hours

**Construction****Bulb Shape:**

PAR38

**For Use Outdoors in Open Fixtures:**

Yes

**LED Characteristics****Color Temperature:**

3000K Warm White

**Color Accuracy (CRI):**

80 CRI

**Beam Angle:**

40°

**Installation****Base Type:**

E26 Edison

**Electrical****Power Factor:**

0.7

**Operating Temperature:**

-20°C to 45°C (-4°F to 113°F)

**Dimmable:**

Yes, down to 20%

**Input Voltage:**

120V

**Flicker:**

&lt;30%

**Other****4-Year, No-Compromise Warranty:**

RAB warrants that our LED products will be free from defects in materials and workmanship for a period of four (4) years from the date of delivery to the end user, including coverage of light output, color stability, driver performance and fixture finish. RAB's warranty is subject to all terms and conditions found at [rablighting.com/warranty](http://rablighting.com/warranty).

**Compliance****UL Listed:**

Yes

**Energy Star Approved:**

This product is ENERGY STAR® Version 2.0 Certified

**Energy Star ID:**

2330084

**California Energy Commission (CEC) Status:**


Not Lawful for Sales in California



## Case and Pallet Dimensions

	QTY	LENGTH (in)	WIDTH (in)	HEIGHT (in)
CASE	6	15.1	10.2	6
PALLET	360	45.4	35.5	48.5

## Dimension

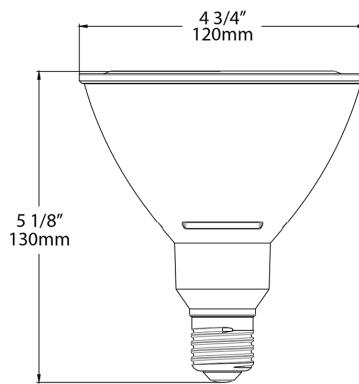

## Light Distribution

