


HALO

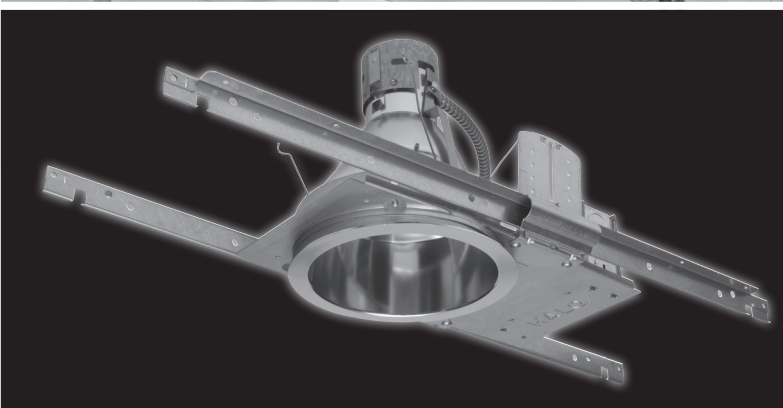

Halo Commercial

Product Line Directory

AHC120263

COOPER Lighting

Halo Commercial Product Line Directory

Catalog Number	Description	Angle Cut Trim - Lens 1G = Prismatic glass 2G = Diffuse glass 3G = Clear glass	Option WF = White Flange	Option CB = Crossblade Reflector	Option CP = Chicago Plenum
PA4	Housing, 4" PAR20/30S Directional, 120V				PA4CP
4ABB	Reflector, 4" Angle Cut Open Black Baffle	4A1GBB, 4A2GBB, 4A3GBB			
4AC	Reflector, 4" Angle Cut Open Reflector, Specular Clear	4A1GC, 4A2GC, 4A3GC	4ACWF, 4A1GCWF, 4A2GCWF, 4A3GCWF		
4AG	Reflector, 4" Angle Cut Open Reflector, Specular Gold	4A1GG, 4A2GG, 4A13GG	4AGWF, 4A1GGWF, 4A2GGWF, 4A13GGWF		
4AH	Reflector, 4" Angle Cut Open Reflector, Semi Specular Clear	4A1GH, 4A2GH, 4A3GH	4AHWF, 4A1GHWF, 4A2GHWF, 4A3GHWF		
4AW	Reflector, 4" Angle Cut Open Reflector, Gloss White	4A1GW, 4A2GW, 4A3GW			
4AWB	Reflector, 4" Angle Cut Open White Baffle	4A1GWB, 4A2GWB, 4A3GWB			
PA6	Housing, 6" PAR30L/38 Directional, 120V				PA6CP
PD6H113E	Housing, 6" (1) 13W DTT Horz., 120-277V UNV				PD6CPH113E
PD6H1133E	Housing, 6" (1) 13W DTT Horz., 347V				
PD6H113REM	Housing, 6" (1) 13W DTT Horz., 120-277V EM				PD6CPH113REM
PD6H118E	Housing, 6" (1) 18W DTT Horz., 120-277V UNV				PD6CPH118E
PD6H1183E	Housing, 6" (1) 18W DTT Horz., 347V				
PD6H1181DMARKX	Housing, 6" (1) 18W DTT Horz., 120V Dimming				PD6CPH1181DMARKX
PD6H1182DMARKX	Housing, 6" (1) 18W DTT Horz., 277V Dimming				PD6CPH1182DMARKX
PD6H118REM	Housing, 6" (1) 18W DTT Horz., 120-277V EM				PD6CPH118REM
PD6H142E	Housing, 6" (1) 26W DTT, 26/32/42W TTT Horz., 120-277V UNV				PD6CPH142E
PD6H1423E	Housing, 6" (1) 26W DTT, 26/32/42W TTT Horz., 347V				
PD6H1421DMARKX	Housing, 6" (1) 26W DTT, 26/32/42W TTT Horz., 120V Dimming				PD6CPH1421DMARKX
PD6H1422DMARKX	Housing, 6" (1) 26W DTT, 26/32/42W TTT Horz., 277V Dimming				PD6CPH1422DMARKX
PD6H142REM	Housing, 6" (1) 26W DTT, 26/32/42W TTT Horz., 120-277V EM				PD6CPH142REM
PD6H213E	Housing, 6" (2) 13W DTT Horz., 120-277V UNV				PD6CPH213E
PD6H2133E	Housing, 6" (2) 13W DTT Horz., 347V				
PD6H213REM	Housing, 6" (2) 13W DTT Horz., 120-277V EM				PD6CPH213REM
PD6H218E	Housing, 6" (2) 18W DTT Horz., 120-277V UNV				PD6CPH218E
PD6H2183E	Housing, 6" (2) 18W DTT Horz., 347V				
PD6H2181DMARKX	Housing, 6" (2) 18W DTT Horz., 120V Dimming				PD6CPH2181DMARKX
PD6H2182DMARKX	Housing, 6" (2) 18W DTT Horz., 277V Dimming				PD6CPH2182DMARKX
PD6H218REM	Housing, 6" (2) 18W DTT Horz., 120-277V EM				PD6CPH218REM
PD6H226E	Housing, 6" (2) 26W DTT Horz., 120-277V UNV				PD6CPH226E
PD6H2263E	Housing, 6" (2) 26W DTT Horz., 347V				
PD6H2261DMARKX	Housing, 6" (2) 26W DTT Horz., 120V Dimming				PD6CPH2261DMARKX
PD6H2262DMARKX	Housing, 6" (2) 26W DTT Horz., 277V Dimming				PD6CPH2262DMARKX
PD6H226REM	Housing, 6" (2) 26W DTT Horz., 120-277V EM				PD6CPH226REM
PD6V142E	Housing, 6" (1) 26W DTT, 26/32/42W TTT Vert., 120-277V UNV				PD6CPV142E
PD6V1423E	Housing, 6" (1) 26W DTT, 26/32/42W TTT Vert., 347V				
PD6V1421DMARKX	Housing, 6" (1) 26W DTT, 26/32/42W TTT Vert., 120V Dimming				PD6CPV1421DMARKX
PD6V1422DMARKX	Housing, 6" (1) 26W DTT, 26/32/42W TTT Vert., 277V Dimming				PD6CPV1422DMARKX
PD6V142REM	Housing, 6" (1) 26W DTT, 26/32/42W TTT Vert., 120-277V EM				PD6CPV142REM

Halo Commercial Product Line Directory

Catalog Number	Description	Angle Cut Trim - Lens 1G = Prismatic glass 2G = Diffuse glass 3G = Clear glass	Option WF = White Flange	Option CB = Crossblade Reflector	Option CP = Chicago Plenum
PD6V120	Housing, 6" Vertical E26, 120V				PD6CPV120
PD6V50E	Housing, 6" Vertical, E26 (protected) 50W MH, 120/277V UNV				PD6CPV50E
PD6V503E	Housing, 6" Vertical, E26 (protected) 50W MH, 347V				
PD6V70E	Housing, 6" Vertical, E26 (protected) 70W MH, 120/277V UNV				PD6CPV70E
PD6V703E	Housing, 6" Vertical, E26 (protected) 70W MH, 347V				
PD6V100E	Housing, 6" Vertical, E26 (protected) 100W MH, 120/277V UNV				PD6CPV100E
PD6V1003E	Housing, 6" Vertical, E26 (protected) 100W MH, 347V				
PD6P39E	Housing, 6" Vertical, E26 PAR 39W MH, 120/277V UNV				PD6CPP39E
PD6P393E	Housing, 6" Vertical, E26 PAR 39W MH, 347V				
PD6P70E	Housing, 6" Vertical, E26 PAR 70W MH, 120/277V UNV				PD6CPP70E
PD6P703E	Housing, 6" Vertical, E26 PAR 70W MH, 347V				
PD6P100E	Housing, 6" Vertical, E26 PAR 100W MH, 120/277V UNV				PD6CPP100E
PD6P1003E	Housing, 6" Vertical, E26 PAR 100W MH, 347V				
6ABB	Reflector, 6" Angle Cut Open Black Baffle	6A1GBB, 6A2GBB, 6A3GBB			
6AC	Reflector, 6" Angle Cut Open Reflector, Specular Clear	6A1GC, 6A2GC, 6A3GC	6ACWF, 6A1GCWF, 6A2GCWF, 6A3GCWF		
6AG	Reflector, 6" Angle Cut Open Reflector, Specular Gold	6A1GG, 6A2GG, 6A13GG	6AGWF, 6A1GGWF, 6A2GGWF, 6A13GGWF		
6AH	Reflector, 6" Angle Cut Open Reflector, Semi Specular Clear	6A1GH, 6A2GH, 6A3GH	6AHWF, 6A1GHWF, 6A2GHWF, 6A3GHWF		
6AW	Reflector, 6" Angle Cut Open Reflector, Gloss White	6A1GW, 6A2GW, 6A3GW			
6AWB	Reflector, 6" Angle Cut Open White Baffle	6A1GWB, 6A2GWB, 6A3GWB			
62HBB	Reflector, 6" Horz, Black Baffle, Specular Clear Reflector				
62HC	Reflector, 6" Horz, Open Reflector, Specular Clear		62HCWF	62HCBC	
62HG	Reflector, 6" Horz, Open Reflector, Specular Gold		62HGWF	62HCBG	
62HH	Reflector, 6" Horz, Open Reflector, Semi Specular Clear		62HHWF	62HCBH	
62HW	Reflector, 6" Horz, Open Reflector, Gloss White			62HCBW	
62HWB	Reflector, 6" Horz, White Baffle, Specular Clear Reflector				
62H1GDF	Reflector, 6" Horz, Lens, Prismatic Glass Spec. Clear Flush Mount (dead front)				
62H1GBB	Reflector, 6" Horz, Lens, Prismatic Glass Black Baffle, Specular Clear				
62H1GC	Reflector, 6" Horz, Lens, Prismatic Glass Specular Clear		62H1GCWF		
62H1GG	Reflector, 6" Horz, Lens, Prismatic Glass Specular Gold		62H1GGWF		
62H1GH	Reflector, 6" Horz, Lens, Prismatic Glass Semi Specular Clear		62H1GHWF		
62H1GW	Reflector, 6" Horz, Lens, Prismatic Glass Gloss White				
62H1GWB	Reflector, 6" Horz, Lens, Prismatic Glass White Baffle, Specular Clear				
62H2GDF	Reflector, 6" Horz, Lens, Diffuse Glass Spec. Clear Flush Mount (dead front)				
62H2GBB	Reflector, 6" Horz, Lens, Diffuse Glass Black Baffle, Specular Clear				

Halo Commercial Product Line Directory

Catalog Number	Description	Angle Cut Trim - Lens 1G = Prismatic glass 2G = Diffuse glass 3G = Clear glass	Option WF = White Flange	Option CB = Crossblade Reflector	Option CP = Chicago Plenum
62H2GC	Reflector, 6" Horz, Lens, Diffuse Glass Specular Clear		62H2GCWF		
62H2GG	Reflector, 6" Horz, Lens, Diffuse Glass Specular Gold		62H2GGWF		
62H2GH	Reflector, 6" Horz, Lens, Diffuse Glass Semi Specular Clear		62H2GHWF		
62H2GW	Reflector, 6" Horz, Lens, Diffuse Glass Gloss White				
62H2GWB	Reflector, 6" Horz, Lens, Diffuse Glass White Baffle, Specular Clear				
62H3GDF	Reflector, 6" Horz, Lens, Clear Glass Spec. Clear Flush Mount (dead front)				
62H3GBB	Reflector, 6" Horz, Lens, Clear Glass Black Baffle, Specular Clear				
62H3GC	Reflector, 6" Horz, Lens, Clear Glass Specular Clear		62H3GCWF		
62H3GG	Reflector, 6" Horz, Lens, Clear Glass Specular Gold		62H3GGWF		
62H3GH	Reflector, 6" Horz, Lens, Clear Glass Semi Specular Clear		62H3GHWF		
62H3GW	Reflector, 6" Horz, Lens, Clear Glass Gloss White				
62H3GWB	Reflector, 6" Horz, Lens, Clear Glass White Baffle, Specular Clear				
62H4GDF	Reflector, 6" Horz, Lens, Fresnel Glass Flush Mount (dead front trim)				
62H5GDF	Reflector, 6" Horz, Lens, Drop Opal Glass Flush Mount (dead front trim)				
62HWWC	Reflector, 6" Horz, Open Wall Wash Specular Clear		62HWWCWF		
62HWWG	Reflector, 6" Horz, Open Wall Wash Specular Gold		62HWWGWF		
62HWWH	Reflector, 6" Horz, Open Wall Wash Semi Specular Clear		62HWWHWF		
62HWWW	Reflector, 6" Horz, Open Wall Wash Gloss White				
60VBB	Reflector, 6" Vert, Black Baffle, Specular Clear Reflector				
60VC	Reflector, 6" Vert, Open Reflector, Specular Clear		60VCWF		
60VG	Reflector, 6" Vert, Open Reflector, Specular Gold		60VGWF		
60VH	Reflector, 6" Vert, Open Reflector, Semi Specular Clear		60VHWF		
60VW	Reflector, 6" Vert, Open Reflector, Gloss White				
60VWB	Reflector, 6" Vert, White Baffle, Specular Clear Reflector				
60V1GDF	Reflector, 6" Vert, Lens, Prismatic Glass Spec. Clear Flush Mount (dead front)				
60V1GBB	Reflector, 6" Vert, Lens, Prismatic Glass Black Baffle, Specular Clear				
60V1GC	Reflector, 6" Vert, Lens, Prismatic Glass Specular Clear		60V1GCWF		
60V1GG	Reflector, 6" Vert, Lens, Prismatic Glass Specular Gold		60V1GGWF		
60V1GH	Reflector, 6" Vert, Lens, Prismatic Glass Semi Specular Clear		60V1GHWF		
60V1GW	Reflector, 6" Vert, Lens, Prismatic Glass Gloss White				
60V1GWB	Reflector, 6" Vert, Lens, Prismatic Glass White Baffle, Specular Clear				
60V2GDF	Reflector, 6" Vert, Lens, Diffuse Glass Spec. Clear Flush Mount (dead front)				
60V2GBB	Reflector, 6" Vert, Lens, Diffuse Glass Black Baffle, Specular Clear				
60V2GC	Reflector, 6" Vert, Lens, Diffuse Glass Specular Clear		60V2GCWF		
60V2GG	Reflector, 6" Vert, Lens, Diffuse Glass Specular Gold		60V2GGWF		

Halo Commercial Product Line Directory

Catalog Number	Description	Angle Cut Trim - Lens 1G = Prismatic glass 2G = Diffuse glass 3G = Clear glass	Option WF = White Flange	Option CB = Crossblade Reflector	Option CP = Chicago Plenum
60V2GH	Reflector, 6" Vert, Lens, Diffuse Glass Semi Specular Clear		60V2GHWF		
60V2GW	Reflector, 6" Vert, Lens, Diffuse Glass Gloss White				
60V2GWB	Reflector, 6" Vert, Lens, Diffuse Glass White Baffle, Specular Clear				
60V3GDF	Reflector, 6" Vert, Lens, Clear Glass Spec. Clear Flush Mount (dead front)				
60V3GBB	Reflector, 6" Vert, Lens, Clear Glass Black Baffle, Specular Clear				
60V3GC	Reflector, 6" Vert, Lens, Clear Glass Specular Clear		60V3GCWF		
60V3GG	Reflector, 6" Vert, Lens, Clear Glass Specular Gold		60V3GGWF		
60V3GH	Reflector, 6" Vert, Lens, Clear Glass Semi Specular Clear		60V3GHWF		
60V3GW	Reflector, 6" Vert, Lens, Clear Glass Gloss White				
60V3GWB	Reflector, 6" Vert, Lens, Clear Glass White Baffle, Specular Clear				
60V4GDF	Reflector, 6" Vert, Lens, Fresnel Glass Spec. Clear Flush Mount (dead front)				
60V5GDF	Reflector, 6" Vert, Lens, Drop Opal Glass Spec. Clear Flush Mount (dead front)				
60VWWC	Reflector, 6" Vert, Open Wall Wash Specular Clear		60VWWCWF		
60VWWG	Reflector, 6" Vert, Open Wall Wash Specular Gold		60VWWGWF		
60VWWH	Reflector, 6" Vert, Open Wall Wash Semi Specular Clear		60VWWHWF		
60VWWW	Reflector, 6" Vert, Open Wall Wash Gloss White				
PD8H142E	Housing, 8" (1) 26W DTT, 26/32/42W TTT Horz., 120-277V UNV				PD8CPH142E
PD8H1423E	Housing, 8" (1) 26W DTT, 26/32/42W TTT Horz., 347V				
PD8H1421DMARKX	Housing, 8" (1) 26W DTT, 26/32/42W TTT Horz., 120V Dimming				PD8CPH1421DMARKX
PD8H1422DMARKX	Housing, 8" (1) 26W DTT, 26/32/42W TTT Horz., 277V Dimming				PD8CPH1422DMARKX
PD8H142REM	Housing, 8" (1) 26W DTT, 26/32/42W TTT Horz., 120-277V EM				PD8CPH142REM
PD8H213E	Housing, 8" (2) 13W DTT, Horz., 120-277V UNV				PD8CPH213E
PD8H2133E	Housing, 8" (2) 13W DTT, Horz., 347V				
PD8H213REM	Housing, 8" (2) 13W DTT, Horz., 120-277V EM				PD8CPH213REM
PD8H218E	Housing, 8" (2) 18W DTT, Horz., 120-277V UNV				PD8CPH218E
PD8H2183E	Housing, 8" (2) 18W DTT, Horz., 347V				
PD8H2181DMARKX	Housing, 8" (2) 18W DTT, Horz., 120V Dimming				PD8CPH2181DMARKX
PD8H2182DMARKX	Housing, 8" (2) 18W DTT, Horz., 277V Dimming				PD8CPH2182DMARKX
PD8H218REM	Housing, 8" (2) 18W DTT, Horz., 120-277V EM				PD8CPH218REM
PD8H242E	Housing, 8" (2) 26W DTT, 26/32/42W TTT Horz., 120-277V UNV				PD8CPH242E
PD8H2423E	Housing, 8" (2) 26W DTT, 26/32/42W TTT Horz., 347V				
PD8H242REM	Housing, 8" (2) 26W DTT, 26/32/42W TTT Horz., 120-277V EM				PD8CPH242REM
PD8H2261DMARKX	Housing, 8" (2) 26W DTT, 26W TTT Horz., 120V Dimming				PD8CPH2261DMARKX
PD8H2262DMARKX	Housing, 8" (2) 26W DTT, 26W TTT Horz., 277V Dimming				PD8CPH2262DMARKX
PD8H2421DMARKX	Housing, 8" (2) 32/42W TTT Horz., 120V Dimming				PD8CPH2421DMARKX
PD8H2422DMARKX	Housing, 8" (2) 32/42W TTT Horz., 277V Dimming				PD8CPH2422DMARKX

Halo Commercial Product Line Directory

Catalog Number	Description	Angle Cut Trim - Lens 1G = Prismatic glass 2G = Diffuse glass 3G = Clear glass	Option WF = White Flange	Option CB = Crossblade Reflector	Option CP = Chicago Plenum
PD8V142E	Housing, 8" (1) 26W DTT, 26/32/42W TTT Vert., 120-277V UNV				PD8CPV142E
PD8V1423E	Housing, 8" (1) 26W DTT, 26/32/42W TTT Vert., 347V				
PD8V1421DMARKX	Housing, 8" (1) 26W DTT, 26/32/42W TTT Vert., 120V Dimming				PD8CPV1421DMARKX
PD8V1422DMARKX	Housing, 8" (1) 26W DTT, 26/32/42W TTT Vert., 277V Dimming				PD8CPV1422DMARKX
PD8V142REM	Housing, 8" (1) 26W DTT, 26/32/42W TTT Vert., 120-277V EM				PD8CPV142REM
PD8V120	Housing, 8" Vertical E26, 120V				PD8CPV120
PD8V50E	Housing, 8" Vertical, E26 (protected) 50W MH, 120/277V UNV				PD8CPV50E
PD8V503E	Housing, 8" Vertical, E26 (protected) 50W MH, 347V				
PD8V70E	Housing, 8" Vertical, E26 (protected) 70W MH, 120/277V UNV				PD8CPV70E
PD8V703E	Housing, 8" Vertical, E26 (protected) 70W MH, 347V				
PD8V100E	Housing, 8" Vertical, E26 (protected) 100W MH, 120/277V UNV				PD8CPV100E
PD8V1003E	Housing, 8" Vertical, E26 (protected) 100W MH, 347V				
PD8V150E	Housing, 8" Vertical, E26 (protected) 150W MH, 120/277V UNV				PD8CPV150E
PD8V1503E	Housing, 8" Vertical, E26 (protected) 150W MH, 347V				
PD8P70E	Housing, 8" Vertical, E26 PAR 70W MH, 120/277V UNV				PD8CPP70E
PD8P703E	Housing, 8" Vertical, E26 PAR 70W MH, 347V				
PD8P100E	Housing, 8" Vertical, E26 PAR 100W MH, 120/277V UNV				PD8CPP100E
PD8P1003E	Housing, 8" Vertical, E26 PAR 100W MH, 347V				
PD8P150E	Housing, 8" Vertical, E26 PAR 150W MH, 120/277V UNV				PD8CPP150E
PD8P1503E	Housing, 8" Vertical, E26 PAR 150W MH, 347V				
82HBB	Reflector, 8" Horz, Black Baffle, Specular Clear Reflector				
82HC	Reflector, 8" Horz, Open Reflector, Specular Clear		82HCWF	82HCBC	
82HG	Reflector, 8" Horz, Open Reflector, Specular Gold		82HGWF	82HCBG	
82HH	Reflector, 8" Horz, Open Reflector, Semi Specular Clear		82HHWF	82HCBH	
82HW	Reflector, 8" Horz, Open Reflector, Gloss White			82HCBW	
82HWB	Reflector, 8" Horz, White Baffle, Specular Clear Reflector				
82H1GBB	Reflector, 8" Horz, Lens, Prismatic Glass Black Baffle, Specular Clear				
82H1GC	Reflector, 8" Horz, Lens, Prismatic Glass Specular Clear		82H1GCWF		
82H1GG	Reflector, 8" Horz, Lens, Prismatic Glass Specular Gold		82H1GGWF		
82H1GH	Reflector, 8" Horz, Lens, Prismatic Glass Semi Specular Clear		82H1GHWF		
82H1GW	Reflector, 8" Horz, Lens, Prismatic Glass Gloss White				
82H1GWB	Reflector, 8" Horz, Lens, Prismatic Glass White Baffle, Specular Clear				
82H2GBB	Reflector, 8" Horz, Lens, Diffuse Glass Black Baffle, Specular Clear				
82H2GC	Reflector, 8" Horz, Lens, Diffuse Glass Specular Clear		82H2GCWF		

Halo Commercial Product Line Directory

Catalog Number	Description	Angle Cut Trim - Lens 1G = Prismatic glass 2G = Diffuse glass 3G = Clear glass	Option WF = White Flange	Option CB = Crossblade Reflector	Option CP = Chicago Plenum
82H2GG	Reflector, 8" Horz, Lens, Diffuse Glass Specular Gold		82H2GGWF		
82H2GH	Reflector, 8" Horz, Lens, Diffuse Glass Semi Specular Clear		82H2GHWF		
82H2GW	Reflector, 8" Horz, Lens, Diffuse Glass Gloss White				
82H2GWB	Reflector, 8" Horz, Lens, Diffuse Glass White Baffle, Specular Clear				
82H3GBB	Reflector, 8" Horz, Lens, Clear Glass Black Baffle, Specular Clear				
82H3GC	Reflector, 8" Horz, Lens, Clear Glass Specular Clear		82H3GCWF		
82H3GG	Reflector, 8" Horz, Lens, Clear Glass Specular Gold		82H3GGWF		
82H3GH	Reflector, 8" Horz, Lens, Clear Glass Semi Specular Clear		82H3GHWF		
82H3GW	Reflector, 8" Horz, Lens, Clear Glass Gloss White				
82H3GWB	Reflector, 8" Horz, Lens, Clear Glass White Baffle, Specular Clear				
82HWWC	Reflector, 8" Horz, Open Wall Wash Specular Clear		82HWWCWF		
82HWWG	Reflector, 8" Horz, Open Wall Wash Specular Gold		82HWWGWF		
82HWWH	Reflector, 8" Horz, Open Wall Wash Semi Specular Clear		82HWWHWF		
82HWWW	Reflector, 8" Horz, Open Wall Wash Gloss White				
80VBB	Reflector, 8" Vert, Black Baffle, Specular Clear Reflector				
80VC	Reflector, 8" Vert, Open Reflector, Specular Clear		80VCWF		
80VG	Reflector, 8" Vert, Open Reflector, Specular Gold		80VGWF		
80VH	Reflector, 8" Vert, Open Reflector, Semi Specular Clear		80VHWF		
80VW	Reflector, 8" Vert, Open Reflector, Gloss White				
80VWB	Reflector, 8" Vert, White Baffle, Specular Clear Reflector				
80V1GBB	Reflector, 8" Vert, Lens, Prismatic Glass Black Baffle, Specular Clear				
80V1GC	Reflector, 8" Vert, Lens, Prismatic Glass Specular Clear		80V1GCWF		
80V1GG	Reflector, 8" Vert, Lens, Prismatic Glass Specular Gold		80V1GGWF		
80V1GH	Reflector, 8" Vert, Lens, Prismatic Glass Semi Specular Clear		80V1GHWF		
80V1GW	Reflector, 8" Vert, Lens, Prismatic Glass Gloss White				
80V1GWB	Reflector, 8" Vert, Lens, Prismatic Glass White Baffle, Specular Clear				
80V2GBB	Reflector, 8" Vert, Lens, Diffuse Glass Black Baffle, Specular Clear				
80V2GC	Reflector, 8" Vert, Lens, Diffuse Glass Specular Clear		80V2GCWF		
80V2GG	Reflector, 8" Vert, Lens, Diffuse Glass Specular Gold		80V2GGWF		
80V2GH	Reflector, 8" Vert, Lens, Diffuse Glass Semi Specular Clear		80V2GHWF		
80V2GW	Reflector, 8" Vert, Lens, Diffuse Glass Gloss White				
80V2GWB	Reflector, 8" Vert, Lens, Diffuse Glass White Baffle, Specular Clear				
80V3GBB	Reflector, 8" Vert, Lens, Clear Glass Black Baffle, Specular Clear				
80V3GC	Reflector, 8" Vert, Lens, Clear Glass Specular Clear		80V3GCWF		
80V3GG	Reflector, 8" Vert, Lens, Clear Glass Specular Gold		80V3GGWF		
80V3GH	Reflector, 8" Vert, Lens, Clear Glass Semi Specular Clear		80V3GHWF		
80V3GW	Reflector, 8" Vert, Lens, Clear Glass Gloss White				

Halo Commercial Product Line Directory

Catalog Number	Description	Angle Cut Trim - Lens 1G = Prismatic glass 2G = Diffuse glass 3G = Clear glass	Option WF = White Flange	Option CB = Crossblade Reflector	Option CP = Chicago Plenum
80V3GWB	Reflector, 8" Vert, Lens, Clear Glass White Baffle, Specular Clear				
80VWWC	Reflector, 8" Vert, Open Wall Wash Specular Clear		80VWWCWF		
80VWWG	Reflector, 8" Vert, Open Wall Wash Specular Gold		80VWWGWF		
80VWWH	Reflector, 8" Vert, Open Wall Wash Semi Specular Clear		80VWWHWF		
80VWWW	Reflector, 8" Vert, Open Wall Wash Gloss White				
RMB22	Optional Bar Hanger (pair) with Integral Nail for Frame Construction				