

Project:	Type:	Prepared By:	Date:
-----------------	--------------	---------------------	--------------



Features and Benefits

- Replaces 18W/26W/32W G24d & G24q CFL Lamps
- Ballast Bypass. Integral Driver enables lamp to be wired directly to line voltage without need for an external driver or ballast
- Compatible with G24d / GX24d & G24q / GX24q installations
- 50,000 hour Lifespan
- Environmentally friendly, no mercury used
- UL Classified
- Rated for use in enclosed and open fixtures in dry or damp locations
- Non-Dimmable
- 5 Year No Compromise Warranty

Technical Specifications		
Performance	L70 Lifespan:	Other
Product Type: Compact	50,000 Hours	Equivalency: 26W Fluorescent
Input Wattage: 9W	Dimmable: No	Warranty (Years): RAB warrants that our LED products will be free from defects in materials and workmanship for a period of five (5) years from the date of delivery to the end user, including coverage of light output, color stability, driver performance and fixture finish. RAB's warranty is subject to all terms and conditions found at rablighting.com/warranty .
Typical Lumen Output: 1000	Construction	Electrical
Efficacy: 111 lm/W	Bulb Shape: PLC	Power Factor: 0.9
Color Temperature: 4000K Cool White	Finish: Frosted	Operating Temperature: -20°C - 45°C
CRI: 82	Base Type: G24d	Input Voltage: 120-277V AC
	For Use Outdoors in Open Fixtures: No	

Technical Specifications (continued)

Electrical

Operating Frequency:

50/60 Hz

Installation

Installation Type:

Type B, Ballast Bypass

Installation Orientation:

Horizontal

Electrical Characteristics

THDi:

<20%

Compliance

UL Recognized:

Yes

UL Classified:

Yes

CEC Status:

Lawful for sale in California

 

Application:

Suitable for damp locations and totally enclosed fixtures.


Case and Pallet Dimensions

	QTY	LENGTH (in)	WIDTH (in)	HEIGHT (in)
CASE	12	6.5	4.9	7.1
PALLET	4032	47.2	39.4	49.6

Wiring Diagram

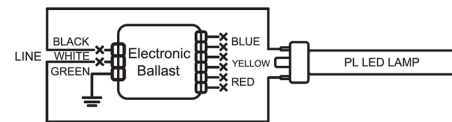

Dimension

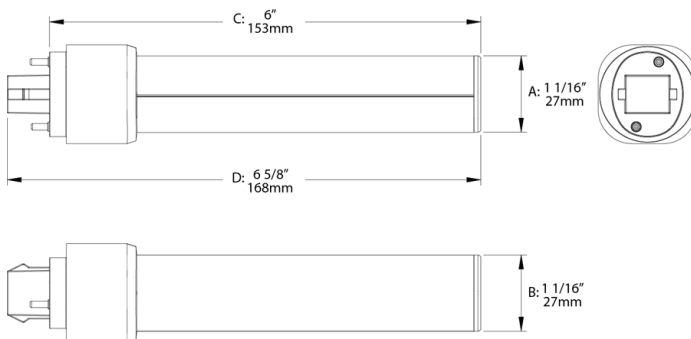

Light Distribution

