


PLF13

High quality polycarbonate PL floodlight. Supplied with one, two or three 13 watt twin tube compact fluorescent lamps. Adjustable swivel mounting arm with 1/2" thread. Lamps supplied.

Color: Bronze

Weight: 1.9 lbs

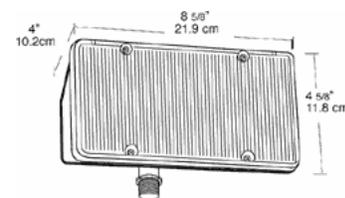

Lamp Info

Type: 13W Twin
 Watts: 13W
 Shape/Size: N/A
 Base: N/A
 ANSI: N/A
 Hours: 10,000
 Lamp Lumens: 900
 Efficacy: N/A

Ballast Info

Type: NPF 120V
 120V: N/A
 208V: N/A
 240V: N/A
 277V: N/A
 Input Watts: 0W
 Efficiency: N/A

Technical Specifications

UL Listing:

Suitable for wet locations. (PLF 13 &26) For side wall mounting only.

Housing and Lens:

Corrosionproof and vandal resistant polycarbonate.

Lens Gasket:

High temperature tubular silicone.

Reflector:

Anodized aluminum.

Sockets:

GX23 base.

Lamp:

13 watt compact fluorescent lamps supplied with fixture.

Minimum Temperature:

0°F .

F13:

Compact Fluorescent 13W.

Correlated Color Temp. (Nominal CCT):

2700K.

Patents:

RAB sensor and fixture designs are protected under U.S. and International Intellectual Property laws.

Country of Origin:

Designed by RAB in New Jersey and assembled in Taiwan.

Trade Agreements Act Compliant:

This product is a product of Taiwan and a "designated country" end product that complies with the Trade Agreements Act.

GSA Schedule:

Suitable in accordance with FAR Subpart 25.4.