


| <br><b>POWER-STRUT®</b> | Part No. |  | Std | Qty | Wt./ | List Price  |
|-------------------------------------------------------------------------------------------------------|----------|--|-----|-----|------|-------------|
|                                                                                                       | & Length |  |     |     |      |             |
|                                                                                                       | Fin.     |  |     |     | 100  | per 100 pcs |

### PS 1100


100 Pair Rigid Steel Conduit Clamps  
Also For IMC and GRC

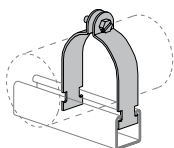

|               |    |     |     |           |
|---------------|----|-----|-----|-----------|
| PS 1100 3/8   | EG | 100 | 10  | \$184.25  |
| PS 1100 3/8   | AL | 100 | 3   | P.O.A.    |
| PS 1100 1/2   | EG | 100 | 11  | \$148.12  |
| PS 1100 1/2   | AL | 100 | 4   | P.O.A.    |
| PS 1100 3/4   | EG | 100 | 15  | \$155.04  |
| PS 1100 3/4   | AL | 100 | 5   | P.O.A.    |
| PS 1100 1     | EG | 100 | 17  | \$176.78  |
| PS 1100 1     | AL | 100 | 5   | P.O.A.    |
| PS 1100 1-1/4 | EG | 100 | 19  | \$197.95  |
| PS 1100 1-1/4 | AL | 100 | 6   | P.O.A.    |
| PS 1100 1-1/2 | EG | 50  | 29  | \$243.43  |
| PS 1100 1-1/2 | AL | 50  | 9   | P.O.A.    |
| PS 1100 2     | EG | 50  | 34  | \$256.87  |
| PS 1100 2     | AL | 50  | 12  | P.O.A.    |
| PS 1100 2-1/2 | EG | 50  | 40  | \$291.23  |
| PS 1100 2-1/2 | AL | 50  | 14  | P.O.A.    |
| PS 1100 3     | EG | 50  | 47  | \$318.38  |
| PS 1100 3     | AL | 50  | 15  | P.O.A.    |
| PS 1100 3-1/2 | EG | 25  | 62  | \$372.28  |
| PS 1100 3-1/2 | AL | 25  | 19  | P.O.A.    |
| PS 1100 4     | EG | 25  | 67  | \$416.53  |
| PS 1100 4     | AL | 25  | 21  | P.O.A.    |
| PS 1100 5     | EG | 25  | 80  | \$627.80  |
| PS 1100 5     | AL | 25  | 24  | P.O.A.    |
| PS 1100 6     | EG | 25  | 102 | \$754.49  |
| PS 1100 6     | AL | 25  | 25  | P.O.A.    |
| PS 1100 8     | EG | 25  | 130 | \$1164.51 |
| PS 1100 8     | AL | 25  | 27  | P.O.A.    |
| PS 1100 10    | EG | 10  | 143 | \$1548.74 |
| PS 1100 10    | AL | 10  | 29  | P.O.A.    |
| PS 1100 12    | EG | 10  | 174 | \$1917.90 |
| PS 1100 12    | AL | 10  | 31  | P.O.A.    |

### PS 1100 AS


100 Pair Pre-Assembled Rigid Steel Conduit And Pipe Clamps  
Also For IMC and GRC

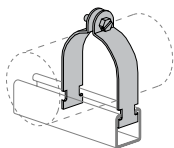

|                  |    |     |     |          |
|------------------|----|-----|-----|----------|
| PS 1100 3/8 AS   | EG | 100 | 10  | \$197.69 |
| PS 1100 1/2 AS   | EG | 100 | 11  | \$159.53 |
| PS 1100 3/4 AS   | EG | 100 | 15  | \$164.01 |
| PS 1100 1 AS     | EG | 100 | 17  | \$188.04 |
| PS 1100 1-1/4 AS | EG | 100 | 19  | \$212.62 |
| PS 1100 1-1/2 AS | EG | 50  | 29  | \$257.69 |
| PS 1100 2 AS     | EG | 50  | 34  | \$271.94 |
| PS 1100 2-1/2 AS | EG | 50  | 40  | \$309.02 |
| PS 1100 3 AS     | EG | 50  | 47  | \$338.75 |
| PS 1100 3-1/2 AS | EG | 25  | 62  | \$400.25 |
| PS 1100 4 AS     | EG | 25  | 67  | \$441.65 |
| PS 1100 5 AS     | EG | 25  | 80  | \$684.68 |
| PS 1100 6 AS     | EG | 25  | 102 | \$862.14 |

### PS 1154

 Splice Connection  
Use With PS 349 Continuous Insert




|         |    |    |    |          |
|---------|----|----|----|----------|
| PS 1154 | EG | 50 | 10 | \$365.91 |
|---------|----|----|----|----------|

| <br><b>POWER-STRUT®</b> | Part No. |      | Std | Wt./ | List Price  |
|--------------------------------------------------------------------------------------------------------|----------|------|-----|------|-------------|
|                                                                                                        | & Length | Fin. | Qty | 100  | per 100 pcs |

### PS 1200

100 Pair O.D. Tubing Clamp

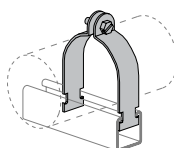

|               |    |     |    |          |
|---------------|----|-----|----|----------|
| PS 1200 1/4   | CC | 100 | 8  | P.O.A.   |
| PS 1200 1/4   | EG | 100 | 8  | \$207.05 |
| PS 1200 3/8   | CC | 100 | 8  | \$263.94 |
| PS 1200 3/8   | EG | 100 | 8  | \$212.75 |
| PS 1200 1/2   | CC | 100 | 9  | \$270.87 |
| PS 1200 1/2   | EG | 100 | 9  | \$216.42 |
| PS 1200 5/8   | CC | 100 | 10 | \$275.21 |
| PS 1200 5/8   | EG | 100 | 10 | \$218.99 |
| PS 1200 3/4   | CC | 100 | 11 | P.O.A.   |
| PS 1200 3/4   | EG | 100 | 11 | \$227.02 |
| PS 1200 7/8   | CC | 100 | 12 | \$299.37 |
| PS 1200 7/8   | EG | 100 | 12 | \$235.84 |
| PS 1200 1     | CC | 100 | 14 | P.O.A.   |
| PS 1200 1     | EG | 100 | 14 | \$263.39 |
| PS 1200 1-1/8 | CC | 100 | 15 | \$333.16 |
| PS 1200 1-1/8 | EG | 100 | 15 | \$270.46 |
| PS 1200 1-1/4 | CC | 100 | 16 | P.O.A.   |
| PS 1200 1-1/4 | EG | 100 | 16 | \$274.54 |
| PS 1200 1-3/8 | CC | 100 | 17 | \$387.08 |
| PS 1200 1-3/8 | EG | 100 | 17 | \$282.26 |
| PS 1200 1-1/2 | CC | 100 | 18 | P.O.A.   |
| PS 1200 1-1/2 | EG | 100 | 18 | \$289.74 |
| PS 1200 1-5/8 | CC | 100 | 19 | \$404.19 |
| PS 1200 1-5/8 | EG | 100 | 19 | \$295.44 |
| PS 1200 1-3/4 | CC | 50  | 29 | P.O.A.   |
| PS 1200 1-3/4 | EG | 50  | 29 | \$384.23 |
| PS 1200 1-7/8 | CC | 50  | 28 | P.O.A.   |
| PS 1200 1-7/8 | EG | 50  | 28 | \$384.23 |
| PS 1200 2     | CC | 50  | 31 | P.O.A.   |
| PS 1200 2     | EG | 50  | 31 | \$391.56 |
| PS 1200 2-1/8 | CC | 50  | 32 | \$548.37 |
| PS 1200 2-1/8 | EG | 50  | 32 | \$391.56 |
| PS 1200 2-1/4 | CC | 50  | 33 | P.O.A.   |
| PS 1200 2-1/4 | EG | 50  | 33 | \$415.60 |
| PS 1200 2-3/8 | CC | 50  | 34 | P.O.A.   |
| PS 1200 2-3/8 | EG | 50  | 34 | \$415.60 |
| PS 1200 2-1/2 | CC | 50  | 35 | P.O.A.   |
| PS 1200 2-1/2 | EG | 50  | 35 | \$431.47 |
| PS 1200 2-5/8 | CC | 50  | 37 | \$611.64 |
| PS 1200 2-5/8 | EG | 50  | 37 | \$431.47 |
| PS 1200 2-3/4 | CC | 50  | 38 | P.O.A.   |
| PS 1200 2-3/4 | EG | 50  | 38 | \$350.28 |
| PS 1200 2-7/8 | CC | 50  | 40 | P.O.A.   |
| PS 1200 2-7/8 | EG | 50  | 40 | \$454.02 |
| PS 1200 3     | CC | 50  | 41 | P.O.A.   |
| PS 1200 3     | EG | 50  | 41 | \$477.37 |
| PS 1200 3-1/8 | CC | 50  | 43 | \$668.81 |
| PS 1200 3-1/8 | EG | 50  | 43 | \$488.64 |
| PS 1200 3-1/4 | CC | 50  | 45 | P.O.A.   |
| PS 1200 3-1/4 | EG | 50  | 45 | \$504.66 |
| PS 1200 3-3/8 | CC | 50  | 46 | P.O.A.   |
| PS 1200 3-3/8 | EG | 50  | 46 | \$515.79 |
| PS 1200 3-1/2 | CC | 50  | 47 | P.O.A.   |
| PS 1200 3-1/2 | EG | 50  | 47 | \$515.79 |
| PS 1200 3-5/8 | CC | 25  | 56 | \$826.57 |
| PS 1200 3-5/8 | EG | 25  | 56 | \$540.09 |
| PS 1200 3-3/4 | CC | 25  | 58 | P.O.A.   |
| PS 1200 3-3/4 | EG | 25  | 58 | \$595.36 |
| PS 1200 3-7/8 | CC | 25  | 60 | P.O.A.   |
| PS 1200 3-7/8 | EG | 25  | 60 | \$676.00 |

Continue on Following Page