




GE
Lighting

20839 - Q50MR16/C/NSP15

GE ConstantColor® Precise™ MR16

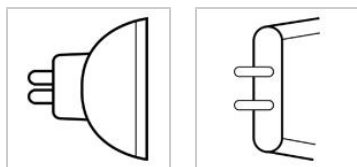

CAUTIONS & WARNINGS

Caution

- Lamp may shatter and cause injury if broken
 - Dispose of lamp in a closed container.
 - Do not use lamp if outer glass is scratched or broken.

Warning

- Risk of Burn
 - Allow lamp/fixture to cool before handling.
 - Turn power off before installing lamp.
- Risk of Fire
 - Keep combustible materials away from lamp.
 - Use in enclosed fixture rated for this product-- see instructions.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
 - Do not touch glass with bare hands.
 - Do not use lamp if outer glass is scratched or broken.
 - Use eye protection when handling lamp.
 - Use in enclosed fixture rated for this product.

GENERAL CHARACTERISTICS

| | |
|---------------------------|---------------------------|
| Lamp Type | Halogen - MR |
| Bulb | MR16 |
| Base | 2-Pin (GX5.3) |
| Filament | C-6 |
| Rated Life | 6000.0 hrs |
| Lamp Enclosure Type (LET) | Open or enclosed fixtures |

PHOTOMETRIC CHARACTERISTICS

| | |
|--------------------------------|----------|
| Initial Lumens | 750.0 |
| Center Beam Candlepower (CBCP) | 9100.0 |
| Color Temperature | 3050.0 K |
| Beam Spread | 15.0 ° |

ELECTRICAL CHARACTERISTICS

| | |
|---------|------|
| Wattage | 50.0 |
| Voltage | 12.0 |

DIMENSIONS

| | |
|------------------------------|--------------------|
| Maximum Overall Length (MOL) | 1.8750 in(47.6 mm) |
| Bulb Diameter (DIA) | 2.000 in(50.8 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|-----------------|
| Product Code | 20839 |
| Description | Q50MR16/C/NSP15 |
| ANSI Code | EXT |
| Standard Package | BUNDLE |
| Standard Package GTIN | 00043168208390 |
| Standard Package Quantity | 20 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 20 |
| UPC | 043168994286 |



GE
Lighting

20839 - Q50MR16/C/NSP15

GE ConstantColor® Precise™ MR16



GENERAL CHARACTERISTICS

| | |
|---------------------------|---------------------------|
| Lamp Type | Halogen - MR |
| Bulb | MR16 |
| Base | 2-Pin (GX5.3) |
| Filament | C-6 |
| Rated Life | 6000.0 hrs |
| Lamp Enclosure Type (LET) | Open or enclosed fixtures |

PHOTOMETRIC CHARACTERISTICS

| | |
|--------------------------------|----------|
| Initial Lumens | 750.0 |
| Center Beam Candlepower (CBCP) | 9100.0 |
| Color Temperature | 3050.0 K |
| Beam Spread | 15.0 ° |

ELECTRICAL CHARACTERISTICS


| | |
|---------|------|
| Wattage | 50.0 |
| Voltage | 12.0 |

DIMENSIONS

| | |
|------------------------------|--------------------|
| Maximum Overall Length (MOL) | 1.8750 in(47.6 mm) |
| Bulb Diameter (DIA) | 2.000 in(50.8 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|-----------------|
| Product Code | 20839 |
| Description | Q50MR16/C/NSP15 |
| ANSI Code | EXT |
| Standard Package | BUNDLE |
| Standard Package GTIN | 00043168208390 |
| Standard Package Quantity | 20 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 20 |
| UPC | 043168994286 |

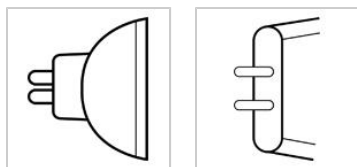

CAUTIONS & WARNINGS

Caution

- Lamp may shatter and cause injury if broken
 - Dispose of lamp in a closed container.
 - Do not use lamp if outer glass is scratched or broken.

Warning

- Risk of Burn
 - Allow lamp/fixture to cool before handling.
 - Turn power off before installing lamp.
- Risk of Fire
 - Keep combustible materials away from lamp.
 - Use in enclosed fixture rated for this product-- see instructions.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
 - Do not touch glass with bare hands.
 - Do not use lamp if outer glass is scratched or broken.
 - Use eye protection when handling lamp.
 - Use in enclosed fixture rated for this product.