



GE
Lighting

12715 - Q75CL/MC/CD

GE halogen 75 watt T3 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- Uses Halogen technology for a brighter, crisper light
- 120 volts
- GE halogen bulbs deliver crisp, white light. This unsurpassed light quality is ideal for adding depth, drama and interest to any room or space. Use GE halogen specialty bulbs to create a dramatic effect
- Lasts .9 years based on 3 hours per day usage
- T3 shape with candelabra base for use in outdoor carriage and post lights



GENERAL CHARACTERISTICS

Lamp Type	Halogen - Single-Ended
Bulb	T3
Base	Miniature Candelabra Screw (E11)
Filament	CC-8
Rated Life (NOM)	1000.0 h

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	1050.0
Color Temperature (NOM)	2850.0 K
Nominal Initial Lumens per Watt (NOM)	14.0

ELECTRICAL CHARACTERISTICS


Wattage (NOM)	75.0
Voltage (NOM)	120.0

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	2.500 in(63.5 mm)
Bulb Diameter (DIA) (NOM)	0.375 in(9.5 mm)
Light Center Length (LCL) (NOM)	1.250 in(31.8 mm)

PRODUCT INFORMATION

Product Code	12715
Description	Q75CL/MC/CD
Standard Package	BUNDLE
Standard Package GTIN	30043168127159
Standard Package Quantity	25
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	25
UPC	043168127158

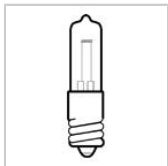

CAUTIONS & WARNINGS

Caution

- Lamp may shatter and cause injury if broken
 - Dispose of lamp in a closed container.
 - Do not use lamp if outer glass is scratched or broken.

Warning

- Risk of Electric Shock
 - Turn power off before inspection, installation or removal.
- Risk of Burn
 - Allow lamp/fixture to cool before handling.
 - Turn power off before installing lamp.
- Risk of Fire
 - Keep combustible materials away from lamp.
 - Use in enclosed fixture rated for this product.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
 - Do not exceed 110% of rated voltage.
 - Do not touch glass with bare hands.
 - Do not use lamp if outer glass is scratched or broken.
 - Use eye protection when handling lamp.
 - Use in enclosed fixture rated for this product.



GE
Lighting

12715 - Q75CL/MC/CD

GE halogen 75 watt T3 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- Uses Halogen technology for a brighter, crisper light
- 120 volts
- GE halogen bulbs deliver crisp, white light. This unsurpassed light quality is ideal for adding depth, drama and interest to any room or space. Use GE halogen specialty bulbs to create a dramatic effect
- Lasts .9 years based on 3 hours per day usage
- T3 shape with candelabra base for use in outdoor carriage and post lights



GENERAL CHARACTERISTICS

Lamp Type	Halogen - Single-Ended
Bulb	T3
Base	Miniature Candelabra Screw (E11)
Filament	CC-8
Rated Life (NOM)	1000.0 h

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	1050.0
Color Temperature (NOM)	2850.0 K
Nominal Initial Lumens per Watt (NOM)	14.0

ELECTRICAL CHARACTERISTICS


Wattage (NOM)	75.0
Voltage (NOM)	120.0

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	2.500 in(63.5 mm)
Bulb Diameter (DIA) (NOM)	0.375 in(9.5 mm)
Light Center Length (LCL) (NOM)	1.250 in(31.8 mm)

PRODUCT INFORMATION

Product Code	12715
Description	Q75CL/MC/CD
Standard Package	BUNDLE
Standard Package GTIN	30043168127159
Standard Package Quantity	25
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	25
UPC	043168127158

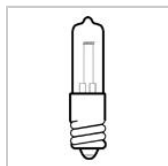

CAUTIONS & WARNINGS

Caution

- Lamp may shatter and cause injury if broken
 - Dispose of lamp in a closed container.
 - Do not use lamp if outer glass is scratched or broken.

Warning

- Risk of Electric Shock
 - Turn power off before inspection, installation or removal.
- Risk of Burn
 - Allow lamp/fixture to cool before handling.
 - Turn power off before installing lamp.
- Risk of Fire
 - Keep combustible materials away from lamp.
 - Use in enclosed fixture rated for this product.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
 - Do not exceed 110% of rated voltage.
 - Do not touch glass with bare hands.
 - Do not use lamp if outer glass is scratched or broken.
 - Use eye protection when handling lamp.
 - Use in enclosed fixture rated for this product.