

STEELER Aluminum High-Bay


- 400W High Pressure Sodium Unit Pack
- 400W Metal Halide Unit Pack
- 400W Pulse Start Metal Halide Unit Pack

Applications

Gymnasium • Recreation • Retail
Transportation • Warehouse

Specifications


- High efficiency, computer-designed 15" spun aluminum reflector
- Formed steel open-air ballast housing, white finish
- Slide-on die-cast aluminum mounting box with 3/4" tapped conduit opening
- Mogul-base porcelain lamp socket, open rated. 2005 NEC Compliant available
- Lamp included and available in 400W HPS, MH and MHPS
- Field-adjustable ladder brackets with eleven (11) distribution patterns
- Optional 5-Tap, 120/208/240/277/480V, ballast (5T) reduces inventory and ordering errors
- Optional Quartz Restrike (Q) for hot strike after momentary power interruption, 250W (max) lamp included
- Minimum starting temperature is -40°C (-40°F) for HPS and 30°C (-20°F) for MH and MHPS
- U.L. listed for damp location. CSA certified
- 65°C (149°F) ambient operation
- Approx. net weight: 30 lbs. (13 kgs.)

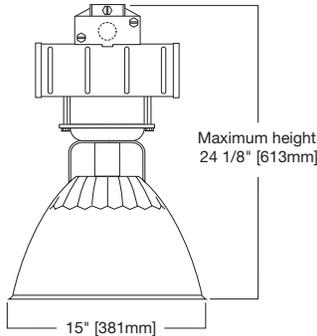

Photometry

Mounting Height	Footcandle Value for Isofootcandle lines					Multiplier			
	A	B	C	D	E	Watts	HPS	MH	MP
25'	5.00	2.00	1.00	.50	.20	400	1.29	1.00	1.22
30'	3.47	1.39	.69	.35	.14				
35'	1.63	.65	.33	.16	.07				

Example of 400W MH at 25ft. mounting height, 36,000 lumen lamp

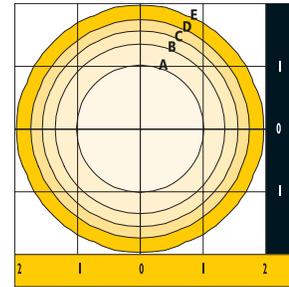

Accessories



Cord (C3)
3' 16/3 white cord (order hook separately)



Cord & Plug (PC3-480V)
3' Cord with NEMA 480V L8-20P Plug



Wire Guard (WG15)
Heavy-gauge 15" wire guard provides additional lamp protection



Cord & Plug (PC3-120V)
3' Cord with NEMA 120V L5-15P Plug



Hook (FH-1)
Die-cast aluminum hook with 3/4" threads



Safety Hook (SHK)
Die-cast aluminum hook with safety screw and 3/4" threads



Cord & Plug (PC3-208V)
3' Cord with NEMA 208V L6-15P Plug



Loop (FL-1)
Malleable iron plated fixture loop with 3/4" threads



Thru-Way Mounting Box (TWMB)
Surface mounted thru-way mounting box objects



Cord & Plug (PC3-240V)
3' Cord with NEMA 240V L6-15P Plug



Safety Glass (SGB15)
Safety glass bottom for 15" aluminum reflector, not compatible with WG15. 2005 NEC Compliant



Wire Guard w/Safety Glass (WG15/GLC)
Heavy-gauge 15" wire guard and safety glass lens provides additional lamp protection



Cord & Plug (PC3-277V)
3' Cord with NEMA 277V L7-15P Plug