


## Grounding - Zinc

### Images

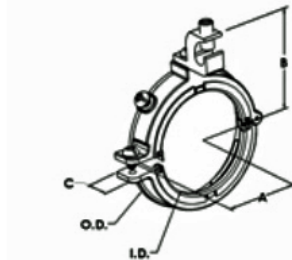

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 2.74  
Dimension B in Inches: 4.00  
Dimension C in Inches: 0.73  
Dimension D in Inches: 3.37  
Dimension E in Inches: 4.50

### Application

Used in situations where wires have already been pulled through Rigid/IMC conduit or EMT Fittings, and an insulated Grounding bushing is required. Rated 150 Degree C. cULus listed. Patented. Now featuring UV Stabilized Insulators and Stainless Steel Hardware, perfect for solar and other outdoor installations!

### Product Information

Material: Zinc Alloy  
Finish: Ball Burnished, Mirror Smooth,  
Grounding Lug: Tin Electro-plate

### Certifications & Codes:

Federal Specification Number: A-A-50553  
NEMA Standard: FB-1  
UL File Number: E20412  
UL Standard: UL-514B  
UNSPSC: 39121312  
Patent Number: 7,182,611; 6,840,782;  
8,419,449

**Catalog ID:** SGB-389CL

**UPC Number:** 78174790389

**Description:** Split Bushing, Insulated, Grounding, Zinc Die Cast, Size 3-1/2 Inch, 14-1/0 Lug

**Application:** Used in situations where wires have already been pulled through Rigid/IMC conduit or EMT Fittings, and an insulated Grounding bushing is required. Rated 150 Degree C. cULus listed. Patented. Now featuring UV Stabilized Insulators and Stainless Steel Hardware, perfect for solar and other outdoor installations!

**Trade Size:** 3-1/2"

**Std Pkg Qty:** 25

**Unit Qty:** -