


Smooth Wall Plate 1-Gang Single Receptacle

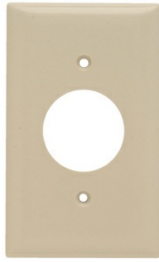

## Features & Benefits

Molded of non-combustible mar-proof material.

Available in 'SP' series in Standard, Junior-Jumbo, and Jumbo sizes.

Seven standard colors available -- Ivory, White, Brown, Gray, Black, Red, and Light Almond.

Individually wrapped with color-matching screws.

Resistant to discoloration, grease, oil, solvent, and moisture.

Nominal thickness, .070 inch.

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Ivory
Finish	Matte	UPC Number	785007682120
Country Of Origin	Mexico	Material	Thermoset Plastic
Construction	Plastic	Wall Plate Size	Standard Size
Wall Plate Type	Single Receptacle	Application Sector	Commercial, Residential
Standard	CSA, UL514	Warranty Type	1-Year Limited Warranty
Type	Wall Plate		

### Dimensions

Product Width US	2.75 in	Product Depth US	0.2 in
Product Height US	4.5 in		

---

## Listing Agencies / 3rd Party Agencies

---

CSA Listed	Yes	CSA File Number	17695
------------	-----	-----------------	-------

---

## Additional Information

---

Product Environmental Profile	Yes
-------------------------------	-----

---

## Technical Information

---

Thickness	0.07 in	Number of Gangs	1
-----------	---------	-----------------	---

---

Indoor/Outdoor	Indoor	Mounting Type	Strap Mounted
----------------	--------	---------------	---------------

---

Orientation	Vertical
-------------	----------

---

Smooth Wall Plate 1-Gang Single Receptacle



## Features & Benefits

Molded of non-combustible mar-proof material.

Available in 'SP' series in Standard, Junior-Jumbo, and Jumbo sizes.

Seven standard colors available -- Ivory, White, Brown, Gray, Black, Red, and Light Almond.

Individually wrapped with color-matching screws.

Resistant to discoloration, grease, oil, solvent, and moisture.

Nominal thickness, .070 inch.

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Ivory
Finish	Matte	UPC Number	785007682120
Country Of Origin	Mexico	Material	Thermoset Plastic
Construction	Plastic	Wall Plate Size	Standard Size
Wall Plate Type	Single Receptacle	Application Sector	Commercial, Residential
Standard	CSA, UL514	Warranty Type	1-Year Limited Warranty
Type	Wall Plate		

### Dimensions

Product Width US	2.75 in	Product Depth US	0.2 in
Product Height US	4.5 in		

---

### Listing Agencies / 3rd Party Agencies

---

CSA Listed	Yes	CSA File Number	17695
------------	-----	-----------------	-------

---

### Additional Information

---

Product Environmental Profile	Yes
-------------------------------	-----

---

### Technical Information

---

Thickness	0.07 in	Number of Gangs	1
-----------	---------	-----------------	---

---

Indoor/Outdoor	Indoor	Mounting Type	Strap Mounted
----------------	--------	---------------	---------------

---

Orientation	Vertical
-------------	----------

---