

Project: _____ Type: _____ Prepared By: _____ Date: _____



Features and Benefits

- PREMIUM, FULL GLASS DESIGN - Mimics traditional bulbs
- 90 CRI - Produces rich and vibrant colors.
- 15,000-HOUR LIFESPAN - Lasts up to 13.7 years at 3 hours per day
- ENCLOSED FIXTURE RATED - May be used in both enclosed and open fixtures
- OMNIDIRECTIONAL Light output
- WET RATED - Suitable for wet locations

Technical Specifications		
Performance	L70 Lifespan:	For Use Outdoors in Open Fixtures:
Product Type: Decorative	15,000 Hours	Yes
Input Wattage: 3W	Dimmable: Yes, down to 10%	Other
Typical Lumen Output: 350	Construction	Equivalency: 40W Incandescent
Efficacy: 92 lm/W	Bulb Shape: ST19	Warranty (Years): RAB warrants that our LED products will be free from defects in materials and workmanship for a period of three (3) years from the date of delivery to the end user, including coverage of light output, color stability, driver performance and fixture finish. RAB's warranty is subject to all terms and conditions found at rablighting.com/warranty .
Color Temperature: 2700K Soft White	Finish: Clear	Electrical
CRI: 90	Base Type: E26	Power Factor: 0.7
	Beam Angle: 360°	Operating Temperature: -20°C - 45°C

Technical Specifications (continued)

Electrical

Input Voltage:

120V

Electrical Characteristics

Flicker:

<30%

Compliance

UL Listed:

Yes

ENERGY STAR V2.0:

This product is ENERGY STAR® Version 2.0 Certified

Energy Star ID:

2330353


CEC Status:

Lawful for sale in California

Case and Pallet Dimensions

	QTY	LENGTH (in)	WIDTH (in)	HEIGHT (in)
CASE	8	11.4	5.8	6.4
PALLET	768	46.3	35.4	39.5

Dimension

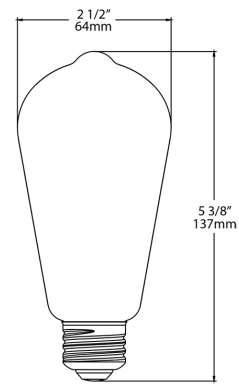

Light Distribution

