

P4D

High Performance Parabolic

PARABOLICS




FEATURES

- Nominal 3" deep louver
- Black reveal with full air handling capabilities
- Matte anodized low iridescent, semi-specular (MA) louver finish virtually eliminates visibility of fingerprints and construction dust
- Shallow housing
- Lightweight
- Recessed, surface, or cable mount
- UL listed 1598, cUL or CSA. Damp Location standard

ORDERING INFORMATION

P4D									
MODEL	NO. OF LAMPS	CEILING TYPE	CELLS WIDE BY CELLS LONG	BALLAST	VOLTAGE	OPTIONS			
P4D High Performance Parabolic	2 Two 3 Three 4 Four (N/A in 2x2) See Product Availability table below.	G Grid SM Surface Mount (static only) CM Cable Mount (static only) ⁴ For hard ceilings, use flange kit. See options in Technical section.	See Product Availability table below.	NOTE: See Technical Section for other ballast options. E Electronic T8, Instant Start 3E 3-Lamp Electronic T8, Instant Start 4E 4-Lamp Electronic T8, Instant Start EP Electronic T5 or T8, Programmed Start 3EP 3-Lamp Electronic T5H0 or T8, Programmed Start 4EP 4-Lamp Electronic T5H0 (N/A 347V) or T8, Programmed Start 24E 2 or 4-Lamp Electronic T8, Instant Start (For 3-Lamp Master/Satellite only) ELW 2-Lamp Electronic T8, 0.77 Ballast Factor, Low Wattage, Instant Start 3ELW 3-Lamp Electronic T8, 0.77 Ballast Factor, Low Wattage, Instant Start 4ELW 4-Lamp Electronic T8, 0.77 Ballast Factor, Low Wattage, Instant Start ETT Electronic Twin Tube, Instant Start (Specify voltage)	U 120V-277V 347 347V	F0735 35K 75CRI T8 Lamps Installed F0741 41K 75CRI T8 Lamps Installed F0835 35K 82CRI T8 Lamps Installed F0841 41K 82CRI T8 Lamps Installed F5835 35K 85CRI T5 Lamps Installed 2BC Two Ballast Covers C388 3-Wire Flex C488 4-Wire Flex EL Emergency Battery Pack GLR Fast Blow Fuse GMF Slow Blow Fuse MS9 Master/Satellite w/9' Harness MS11 Master/Satellite w/ 11' Harness PAF Paint After Fabrication TB4 (4) Bulk T-Bar Clips EOR End of Row (SM/CM only. Provides end wiring access for continuous row mounting) ⁵ INT Intermediate (SM/CM only. Provides ends with wiring access for continuous row mounting) ⁵ NYC NYC Compliant NYCU NYC Compliant, Union Label			
SIZE	LAMP TYPE	LOUVER FINISH	AIR HANDLING						
22 2' x 2' ¹³	14 2', T5: 14 Watt 17 2', T8: 17 Watt 24 2', T5H0: 24 Watt 28 4', T5: 28 Watt 31U1 U-Bent, 1 1/8" Leg Spacing T8: 31 Watt 32 4', T8: 32, 30, 28 or 25 Watt 32U6 U-Bent, 6" Leg Spacing T8: 32 Watt 40TT Twin Tube Compact, 2G11 Base: 40 Watt 54 4', T5H0: 54 or 51 Watt	LS Low Iridescent Specular MA Matte Anodized Low Iridescent Semi-Specular Aluminum (Std.)	S Static ¹ A Air Handling ¹ AV Air Handling with Supply Vanes ¹ C Combination Supply/Extract ² CV Combination Supply Vanes/Extract ² CD Combination Supply Extract Dampers ² CVD Combination Supply Vanes Extract Dampers ² H Heat Extract ² HD Heat Extract with Dampers ²						

¹ All fixtures supplied with integral T-Bar clips.
² 2' x 2' fixtures supplied with integral T-Bar clips, 2' x 4' fixtures supplied with two non-integral T-Bar clips.
³ Various options may increase fixture height on 2' x 2'.
⁴ Order hanger accessories separately.
⁵ Contact factory for continuous row, 3-lamp fixtures.

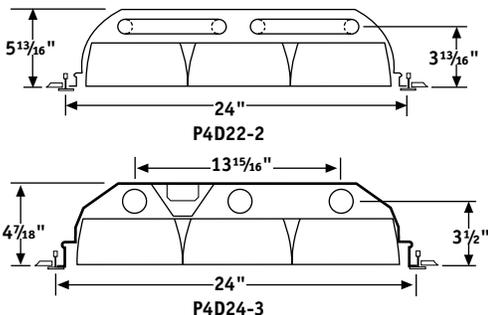

PRODUCT AVAILABILITY

SIZE	NO. OF LAMPS	LAMP TYPE	LOUVER CONFIGURATIONS
2' x 2'	2	14, 17, 24, 31U1, 32U6, 40TT	2 x 3 (6), 2 x 4 (8), 3 x 3 (9) , 4 x 4 (16)
	3	14, 17, 24, 31U1, 40TT	3 x 3 (9) , 4 x 4 (16)
	4	17	3 x 3 (9) , 4 x 4 (16)
2' x 4'	2	28, 32, 54	2 x 6 (12) , 2 x 8 (16), 4 x 6 (24), 4 x 8 (32)
	3	28, 32, 54	3 x 6 (18) , 3 x 8 (24)
	4	28, 32, 54	2 x 6 (12), 2 x 8 (16), 4 x 6 (24), 4 x 8 (32)

Standard louver configurations shown in bold. Ballast quantities or emergency pack options may be restricted in some models.