

JUNO®

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

5" UNIVERSAL TC REMODEL HOUSING

INCANDESCENT LAMPS

TC20R

PRODUCT DESCRIPTION

TC Housing for remodel application where back side of ceiling is not accessible • Installs through an opening in the ceiling from below • Secured in place by factory installed remodel springs • Design for use in non-insulated areas • If installed where insulation is present, the insulation must be pulled back 3" from all sides of the TC housing.

PRODUCT SPECIFICATIONS

Lamp Lamp ratings based on trim selected—see page 2.

Socket Medium base porcelain with nickel-plated copper screw shell • Drop socket with spring to accommodate certain trim installation.

Trims Trim selection shown on reverse.

Labels UL listed for through-branch wiring, damp locations and IP • Product thermally protected against improper use of lamps or insulation • Union made • UL Listed/CSA certified • Trims 210N and 212N are wet location approved for covered ceiling applications • Trims 215 and 216 are wet location approved for covered ceiling applications, **when used with outdoor rated lamps.**



Testing All reports are based on published industry procedures; field performance may differ from laboratory performance.

INSTALLATION

Junction Box Pre-wired junction box, UL listed/CSA certified for through-branch wiring maximum 4 No. 12 AWG 90° C branch circuit conductors (2 in, 2 out) • Junction box provided with removable access plate, (5) ½" knockouts, (4) Non-metallic sheathed cable connectors and ground wire • Knockouts equipped with pryout slots.

Housing TC aluminum housing • Slot cut outs and riveted spring mounting tabs accommodate various trim designs • Remodel springs accommodate up to 1 ¼" ceiling thickness.

DIMENSIONS

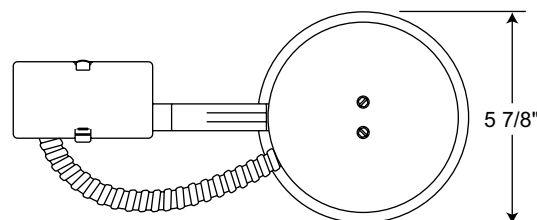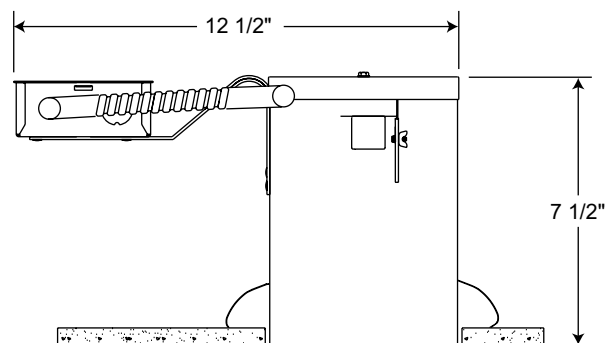

5 1/2" CEILING CUTOUT

PRODUCT CODES

Catalog Number	Input Voltage	Lamp Rating
TC20R 5" Incandescent Remodel Non-TC Housing	120V	A19/BR30/PAR20/PAR30/PAR30L/R20 (See page 2 for max. trim rating)

Housing and trim can be ordered together or separate, but will always ship separately.

Warranty 1-year limited warranty. This is the only warranty provided and no other statements in this specification sheet create any warranty of any kind. All other express and implied warranties are disclaimed. Complete warranty terms located at: www.acuitybrands.com/support/warranty/terms-and-conditions.














Note: Actual performance may differ as a result of end-user environment and application. Specifications subject to change without notice.

5" UNIVERSAL TC REMODEL HOUSING

INCANDESCENT LAMPS

TC20R

TRIMS/LAMPS

	Catalog Number	Description	Max. Lamp Rating
** 	205 BWH 205 WWH 205 BSC 205 BBRZ	Black Baffle, White Trim Ring White Baffle, White Trim Ring Black Baffle, Satin Chrome Trim Ring Black Baffle, Bronze Trim Ring	75W PAR30, 65W BR30
** 	204 CWH 204 GWH 204 BWH 204 HZWH 204 WWH 204 WHZWH 204 WHZBRZ	Clear Alzak® Cone, White Trim Ring Gold Alzak® Cone, White Trim Ring Black Alzak® Cone, White Trim Ring Haze Cone, White Trim Ring Gloss White Cone, White Trim Ring Wheat Haze Cone, White Trim Ring Wheat Haze Cone, Bronze Trim Ring	75W PAR30L, 75W PAR30, 65W BR30
** 	206 CWH 206 BWH 206 HZWH 206 WHZWH 206 WHZBRZ	Clear Alzak® Cone, White Trim Ring Black Cone, White Trim Ring Haze Cone, White Trim Ring Wheat Haze Cone, White Trim Ring Wheat Haze Cone, Bronze Trim Ring	75W PAR30, 65W BR30
** 	207 CWH 207 BWH 207 WWH 207 HZWH	Clear Alzak® Cone, White Trim Ring Black Cone, White Trim Ring White Cone, White Trim Ring Haze Cone, White Trim Ring	50W PAR20/R20
 	215 BWH ◆◆ 215 WWH ◆◆	Black Baffle, White Trim Ring White Baffle, White Trim Ring	75W PAR30L, 75W PAR30 w/Socket Extender, 60W A19, 85W BR30
 	216 CWH ◆◆ 216 WWH ◆◆ 216 HZWH ◆◆ 216 WHZWH ◆◆	Clear Alzak® Cone, White Trim Ring White Cone, White Trim Ring Haze Cone, White Trim Ring Wheat Haze Cone, White Trim Ring	75W PAR30L, 75W PAR30 w/Socket Extender, 85W BR30, 60W A19 (Clear, Gold, Haze and Wheat Haze Cones), 40W A19 (White Cone)
	688 BWH 688 WWH	Black Baffle, White Trim Ring White Baffle, White Trim Ring	75W PAR30
 	210N WH ◆	Lensed Flat Glass Shower Trim, White	40W A19
 	212N WH ◆	Frosted Lens with Clear Center Trim, White	60W A15, 75W PAR30

Trim Size: 6¼" O.D.

Alzak is a registered trademark of Alcoa Corp.

Note: In Canada when insulation is present,
Type IC fixtures must be used.

◆ UL Listed for use in wet location.

◆◆ UL Listed for use in wet location with outdoor rated lamp.

** NOTE: TR5 Trim Ring compatible with 204, 205, 206, 207 trims.

Housing and trim can be ordered together or separate, but will always ship separately.

JUNO®

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

5" UNIVERSAL TC REMODEL HOUSING

INCANDESCENT LAMPS

TC20R

PRODUCT DESCRIPTION

TC Housing for remodel application where back side of ceiling is not accessible • Installs through an opening in the ceiling from below
 • Secured in place by factory installed remodel springs • Design for use in non-insulated areas • If installed where insulation is present, the insulation must be pulled back 3" from all sides of the TC housing.

PRODUCT SPECIFICATIONS

Lamp Lamp ratings based on trim selected—see page 2.

Socket Medium base porcelain with nickel-plated copper screw shell
 • Drop socket with spring to accommodate certain trim installation.

Trims Trim selection shown on reverse.

Labels UL listed for through-branch wiring, damp locations and IP • Product thermally protected against improper use of lamps or insulation • Union made • UL Listed/CSA certified • Trims 210N and 212N are wet location approved for covered ceiling applications • Trims 215 and 216 are wet location approved for covered ceiling applications, **when used with outdoor rated lamps.**



Testing All reports are based on published industry procedures; field performance may differ from laboratory performance.

INSTALLATION

Junction Box Pre-wired junction box, UL listed/CSA certified for through-branch wiring maximum 4 No. 12 AWG 90° C branch circuit conductors (2 in, 2 out) • Junction box provided with removable access plate, (5) ½" knockouts, (4) Non-metallic sheathed cable connectors and ground wire • Knockouts equipped with pryout slots.

Housing TC aluminum housing • Slot cut outs and riveted spring mounting tabs accommodate various trim designs • Remodel springs accommodate up to 1 ¼" ceiling thickness.

DIMENSIONS

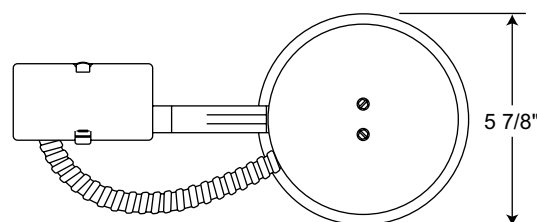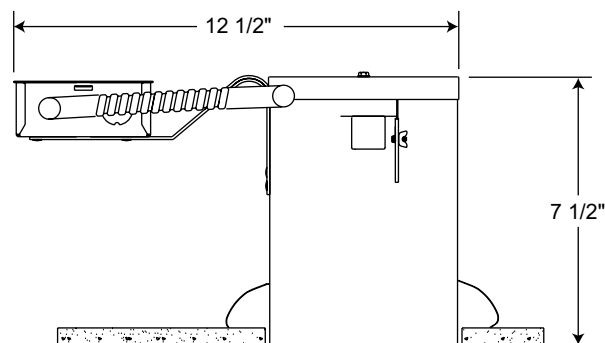

5 1/2" CEILING CUTOUT

PRODUCT CODES

Catalog Number	Input Voltage	Lamp Rating
TC20R 5" Incandescent Remodel Non-TC Housing	120V	A19/BR30/PAR20/PAR30/PAR30L/R20 (See page 2 for max. trim rating)

Housing and trim can be ordered together or separate, but will always ship separately.

Warranty 1-year limited warranty. This is the only warranty provided and no other statements in this specification sheet create any warranty of any kind. All other express and implied warranties are disclaimed. Complete warranty terms located at: www.acuitybrands.com/support/warranty/terms-and-conditions.














Note: Actual performance may differ as a result of end-user environment and application. Specifications subject to change without notice.

5" UNIVERSAL TC REMODEL HOUSING

INCANDESCENT LAMPS

TC20R

TRIMS/LAMPS

	Catalog Number	Description	Max. Lamp Rating
**	 205 BWH 205 WWH 205 BSC 205 BBRZ	Black Baffle, White Trim Ring White Baffle, White Trim Ring Black Baffle, Satin Chrome Trim Ring Black Baffle, Bronze Trim Ring	75W PAR30, 65W BR30
**	 204 CWH 204 GWH 204 BWH 204 HZWH 204 WWH 204 WHZWH 204 WHZBRZ	Clear Alzak® Cone, White Trim Ring Gold Alzak® Cone, White Trim Ring Black Alzak® Cone, White Trim Ring Haze Cone, White Trim Ring Gloss White Cone, White Trim Ring Wheat Haze Cone, White Trim Ring Wheat Haze Cone, Bronze Trim Ring	75W PAR30L, 75W PAR30, 65W BR30
**	 206 CWH 206 BWH 206 HZWH 206 WHZWH 206 WHZBRZ	Clear Alzak® Cone, White Trim Ring Black Cone, White Trim Ring Haze Cone, White Trim Ring Wheat Haze Cone, White Trim Ring Wheat Haze Cone, Bronze Trim Ring	75W PAR30, 65W BR30
**	 207 CWH 207 BWH 207 WWH 207 HZWH	Clear Alzak® Cone, White Trim Ring Black Cone, White Trim Ring White Cone, White Trim Ring Haze Cone, White Trim Ring	50W PAR20/R20
	 215 BWH ◆◆ 215 WWH ◆◆	Black Baffle, White Trim Ring White Baffle, White Trim Ring	75W PAR30L, 75W PAR30 w/Socket Extender, 60W A19, 85W BR30
	 216 CWH ◆◆ 216 WWH ◆◆ 216 HZWH ◆◆ 216 WHZWH ◆◆	Clear Alzak® Cone, White Trim Ring White Cone, White Trim Ring Haze Cone, White Trim Ring Wheat Haze Cone, White Trim Ring	75W PAR30L, 75W PAR30 w/Socket Extender, 85W BR30, 60W A19 (Clear, Gold, Haze and Wheat Haze Cones), 40W A19 (White Cone)
	 688 BWH 688 WWH	Black Baffle, White Trim Ring White Baffle, White Trim Ring	75W PAR30
	 210N WH ◆	Lensed Flat Glass Shower Trim, White	40W A19
	 212N WH ◆	Frosted Lens with Clear Center Trim, White	60W A15, 75W PAR30

Trim Size: 6¼" O.D.

Alzak is a registered trademark of Alcoa Corp.

Note: In Canada when insulation is present,
Type IC fixtures must be used.

◆ UL Listed for use in wet location.

◆◆ UL Listed for use in wet location with outdoor rated lamp.

** NOTE: TR5 Trim Ring compatible with 204, 205, 206, 207 trims.

Housing and trim can be ordered together or separate, but will always ship separately.