



Project: \_\_\_\_\_

Fixture Type: \_\_\_\_\_

Location: \_\_\_\_\_

Contact/Phone: \_\_\_\_\_

# 5" UNIVERSAL TC REMODEL HOUSING

## INCANDESCENT LAMPS TC20R

### PRODUCT DESCRIPTION

TC Housing for remodel application where back side of ceiling is not accessible • Installs through an opening in the ceiling from below • Secured in place by factory installed remodel springs • Design for use in non-insulated areas • If installed where insulation is present, the insulation must be pulled back 3" from all sides of the TC housing.

### PRODUCT SPECIFICATIONS

**Lamp** Lamp ratings based on trim selected—see page 2.

**Socket** Medium base porcelain with nickel-plated copper screw shell • Drop socket with spring to accommodate certain trim installation.

**Trims** Trim selection shown on reverse.

**Labels** UL listed for through-branch wiring, damp locations and IP • Product thermally protected against improper use of lamps or insulation • Union made • UL Listed/CSA certified • Trims 210N, 211 and 212N are wet location approved for covered ceiling applications • Trims 215 and 216 are wet location approved for covered ceiling applications, **when used with outdoor rated lamps.**

**Testing** All reports are based on published industry procedures; field performance may differ from laboratory performance.



Specifications subject to change without notice.

### INSTALLATION

**Junction Box** Pre-wired junction box, UL listed/CSA certified for through-branch wiring maximum 4 No. 12 AWG 90° C branch circuit conductors (2 in, 2 out) • Junction box provided with removable access plate, (5) ½" knockouts, (4) Non-metallic sheathed cable connectors and ground wire • Knockouts equipped with pryout slots.

**Housing** TC aluminum housing • Slot cut outs and riveted spring mounting tabs accommodate various trim designs • Remodel springs accommodate up to 1 ½" ceiling thickness.

### DIMENSIONS

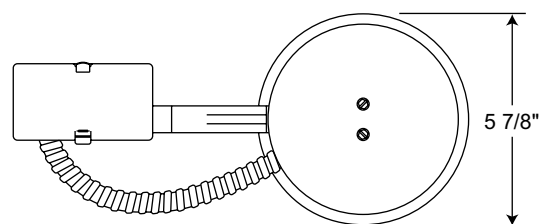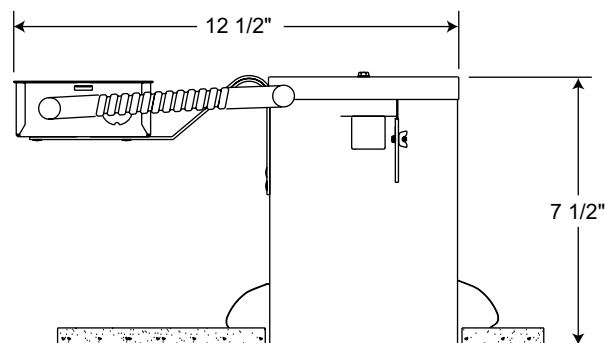

5 1/2" CEILING CUTOUT

### PRODUCT CODES

| Catalog Number                               | Input Voltage | Lamp Rating   |
|--|---------------|---|
| TC20R 5" Incandescent Remodel Non-IC Housing | 120V          | A19/BR30/PAR20/PAR30/PAR30L/R20 (See page 2 for max. trim rating) |

 













Housing and trim can be ordered together or separate, but will always ship separately.

# 5" UNIVERSAL TC REMODEL HOUSING

## INCANDESCENT LAMPS

### TC20R

#### TRIMS/LAMPS

|   | Catalog Number   | Description   | Max. Lamp Rating  |
|---|--|---|---|
| **   | <b>203 WWH</b>   | White Baffle, White Trim Ring   | 75W PAR30, 65W BR30   |
|   | <b>205 BWH</b><br><b>205 WWH</b><br><b>205 BSC</b><br><b>205 BBRZ</b>  | Black Baffle, White Trim Ring<br>White Baffle, White Trim Ring<br>Black Baffle, Satin Chrome Trim Ring<br>Black Baffle, Bronze Trim Ring  | 75W PAR30, 65W BR30   |
| **   | <b>204 CWH</b><br><b>204 GWH</b><br><b>204 BWH</b><br><b>204 HZWH</b><br><b>204 WWH</b><br><b>204 WHZWH</b><br><b>204 WHZBRZ</b> | Clear Alzak® Cone, White Trim Ring<br>Gold Alzak® Cone, White Trim Ring<br>Black Alzak® Cone, White Trim Ring<br>Haze Cone, White Trim Ring<br>Gloss White Cone, White Trim Ring<br>Wheat Haze Cone, White Trim Ring<br>Wheat Haze Cone, Bronze Trim Ring | 75W PAR30L, 75W PAR30, 65W BR30   |
| **   | <b>206 CWH</b><br><b>206 BWH</b><br><b>206 HZWH</b><br><b>206 WHZWH</b><br><b>206 WHZBRZ</b>                                     | Clear Alzak® Cone, White Trim Ring<br>Black Cone, White Trim Ring<br>Haze Cone, White Trim Ring<br>Wheat Haze Cone, White Trim Ring<br>Wheat Haze Cone, Bronze Trim Ring  | 75W PAR30, 65W BR30   |
| **   | <b>207 CWH</b><br><b>207 BWH</b><br><b>207 WWH</b><br><b>207 HZWH</b>  | Clear Alzak® Cone, White Trim Ring<br>Black Cone, White Trim Ring<br>White Cone, White Trim Ring<br>Haze Cone, White Trim Ring  | 50W PAR20/R20   |
|   | <b>215 BWH</b> ◆◆<br><b>215 WWH</b> ◆◆   | Black Baffle, White Trim Ring<br>White Baffle, White Trim Ring  | 75W PAR30L, 75W PAR30 w/Socket Extender,<br>60W A19, 85W BR30   |
|   | <b>216 CWH</b> ◆◆<br><b>216 WWH</b> ◆◆<br><b>216 HZWH</b> ◆◆<br><b>216 WHZWH</b> ◆◆  | Clear Alzak® Cone, White Trim Ring<br>White Cone, White Trim Ring<br>Haze Cone, White Trim Ring<br>Wheat Haze Cone, White Trim Ring   | 75W PAR30L, 75W PAR30 w/Socket Extender,<br>85W BR30, 60W A19 (Clear, Gold, Haze and<br>Wheat Haze Cones), 40W A19 (White Cone) |
|    | <b>688 BWH</b><br><b>688 WWH</b>   | Black Baffle, White Trim Ring<br>White Baffle, White Trim Ring  | 75W PAR30   |
|    | <b>689 CWH</b>   | Clear Alzak® Cone, White Trim Ring  | 75W PAR30   |
|   | <b>210N WH</b> ◆   | Lensed Flat Glass Shower Trim, White  | 40W A19   |
|   | <b>212N WH</b> ◆   | Frosted Lens with Clear Center Trim, White  | 60W A15,<br>75W PAR30   |

Trim Size: 6¼" O.D.

Alzak is a registered trademark of Alcoa Corp.

Note: In Canada when insulation is present,

Type IC fixtures must be used.

◆ UL Listed for use in wet location.

◆◆ UL Listed for use in wet location with outdoor rated lamp.

\*\* NOTE: TR5 Trim Ring compatible with 203, 204, 205, 206, 207 trims.

Housing and trim can be ordered together or separate, but will always ship separately.