




PREMIUM WIRE CONNECTORS

Features & Benefits

TERMINATOR® Premium Wire Connectors reduce your inventory requirements by allowing three connectors to do the work of six standard connectors. The swept-back wing design and grooved body let you apply more torque, forming more secure connections and reducing call backs. The flexible skirt provides additional protection against over-strips and conforms to the wire to fit into boxes.

- A)** Extra thick end cap prevents wire breakthroughs
- B)** Steel square-wire springs provide a quick and reliable bite
- C)** Rounded wings and ergonomic grooves allow you to apply more torque, forming a reliable connection with less effort
- D)** Dual-color connector fits the wire range of two standard connectors, reducing inventory requirements
- E)** Deep, flexible skirt provides additional protection against over-strips and allows the connector to fit into tight spaces

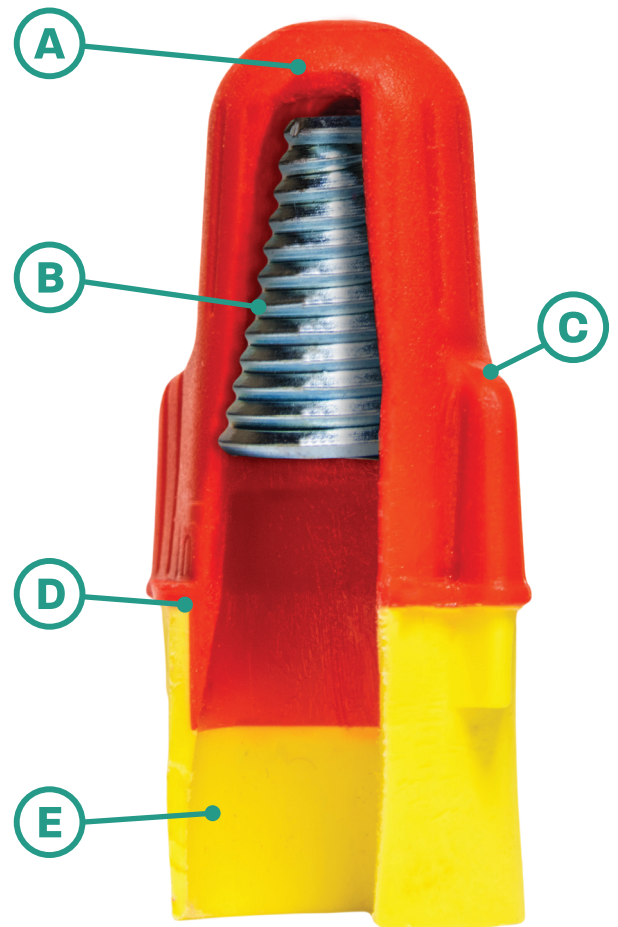




PREMIUM WIRE CONNECTORS



Product Data

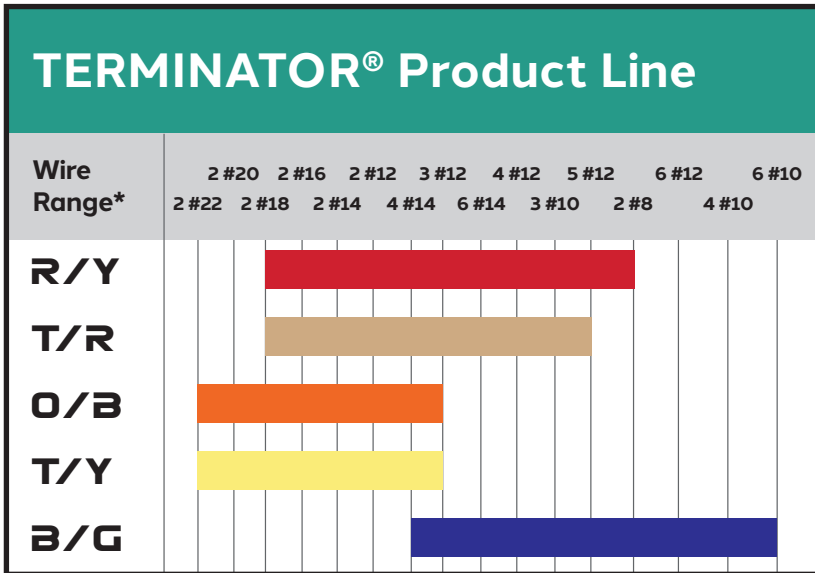

- Thermoplastic shell rated at 105C (221F)
- Terminator Wire connectors are rated to 600V maximum in building wire; 1000V maximum in signs or lighting fixtures (luminaires)
- Approved for use with copper wire



Scan for more information



*Scan for complete listing of wire combinations and installation instructions

Product	Part #	Pack Qty
BLUE/GRAY		
B/G Pouch	TM-BG-50P	50
B/G Jar	TM-BG-250J	250
RED/YELLOW		
R/Y Pouch	TM-RY-100P	100
R/Y Jar	TM-RY-500J	500
R/Y Drum	TM-RY-17D	17,000
TAN/RED		
T/R Pouch	TM-TR-100P	100
T/R Jar	TM-TR-750J	750
T/R Drum	TM-TR-25D	25,000
ORANGE/BLUE		
O/B Pouch	TM-OB-100P	100
O/B Jar	TM-OB-500J	500
TAN/YELLOW		
T/Y Pouch	TM-TY-100P	100
T/Y Jar	TM-TY-500J	500



NSI Industries
800.321.5847
nsiindustries.com

TRM_LINE_WRC_PRODSHEET
©2023 NSI Industries, LLC