



Pass & Seymour




Switches TradeMaster® Decorator Combination Switches

Unique “Up/Down” switches match the look and feel of standard Decorator switches.

Easy-to-use oversized main switch for primary load.

Patented Snap-In Light Module (sold separately) transforms a combination switch into an illuminated switch in seconds.

Identification modules (sold separately) identifies each switch — light, fan, heat lamp.

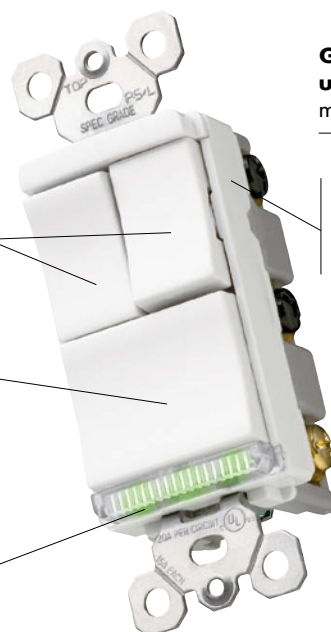

TM8113WCC
Shown with Snap-In Light Module TM8LMCC.

Fully rounded back body protects wires from being damaged by sharp edges.

Ground screw position under the end of the strap minimizes the risk of contact.

Impact-resistant face and body.

Full wraparound metal strap, commercial grade with lock-in tabs.




All screws are tri-drive.

Patented split circuit tab — easily accessible, and can be reinstalled without a tool.

External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG.

Adding a Snap-In Light Module

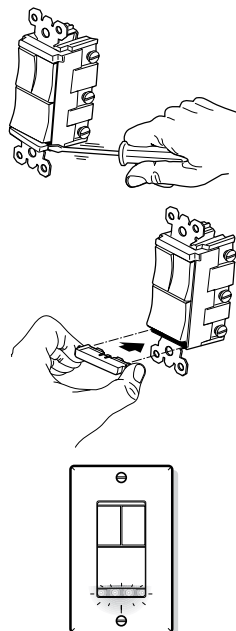

Features

- Module simply snaps-in for easy installation.
 - Can be installed with the following devices: TM811, TM813, TM833, TM818, TM838, TM8111, TM8113, TM81111, TM8118 and the LS Series of Dimmers & Fan Speed Controls (see Pages M-13 through M-15).
- Snap-In Light Module:**
- Lights when OFF.
 - Uses energy-efficient 1/4 watt LED light.
 - LED light will not generate heat and will last on average 47 years.



Catalog Number	Rating A. VAC	Color	3rd Party Compliance
			cULus cULus
Snap-In Light Module			
TM8LMCC	15 120/125	Clear	•
Identification Modules			
TM8IDICC	— —	Ivory	
TM8IDWCC	— —	White	
TM8IDCC	— —	Brown	
TM8IDBKCC	— —	Black	
TM8IDLACC	— —	Light Almond	

For Decorator Hallway Lights and Combination Devices, see Page D-24.

All devices listed on this page conform to NEMA WD-1 and WD-6.

Switches TradeMaster® Decorator Combination Switches

15A, 120VAC




Pass & Seymour




Features


- Impact-resistant face and body.
- Fully rounded back body protects wires from being damaged by sharp edges.
- Clear identification of circuits.
- External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG.
- Ground screw position under the end of the strap minimizes the risk of contact.
- Full wraparound metal strap with lock-in tabs.
- Patented split circuit tab – easily accessible, and can be reinstalled without a tool.
- Unique “Up/Down” switches match the look and feel of standard Decorator switches.
- Largest breadth of 15 amp offering.
- All screws are tri-drive.
- Tamper-resistant version features dual mechanical shutter system to help prevent insertion of foreign objects (see Page A-26).

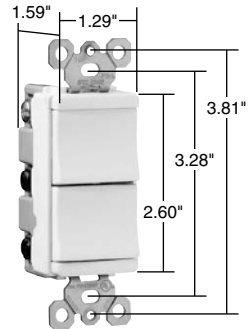

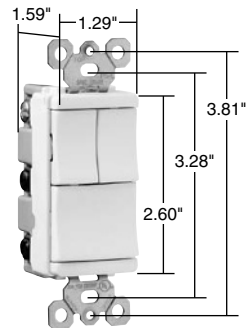

TM811WCC

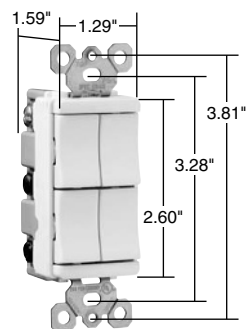

TM8111WCC



TM81111WCC


Catalog Number	Rating A. VAC	Color	3rd Party Compliance	
			 UL20	 cULus
Two Single Pole Switches				
TM811ICC	15 120	Ivory	•	•
TM811WCC	15 120	White	•	•
TM811CC	15 120	Brown	•	•
TM811BKCC	15 120	Black	•	•
TM811LACC	15 120	Light Almond	•	•
Single Pole Switch & Three-Way Switch				
TM813ICC	15 120	Ivory	•	•
TM813WCC	15 120	White	•	•
TM813CC	15 120	Brown	•	•
TM813BKCC	15 120	Black	•	•
TM813LACC	15 120	Light Almond	•	•
Two Three-Way Switches				
TM833ICC	15 120	Ivory	•	•
TM833WCC	15 120	White	•	•
TM833CC	15 120	Brown	•	•
TM833BKCC	15 120	Black	•	•
TM833LACC	15 120	Light Almond	•	•
Three Single Pole Switches				
TM8111ICC	15 120	Ivory	•	•
TM8111WCC	15 120	White	•	•
TM8111CC	15 120	Brown	•	•
TM8111BKCC	15 120	Black	•	•
TM8111LACC	15 120	Light Almond	•	•
Two Single Pole Switches & Three-Way Switch				
TM8113ICC	15 120	Ivory	•	•
TM8113WCC	15 120	White	•	•
TM8113CC	15 120	Brown	•	•
TM8113BKCC	15 120	Black	•	•
TM8113LACC	15 120	Light Almond	•	•
Four Single Pole Switches				
TM81111ICC	15 120	Ivory	•	•
TM81111WCC	15 120	White	•	•
TM81111CC	15 120	Brown	•	•
TM81111BKCC	15 120	Black	•	•
TM81111LACC	15 120	Light Almond	•	•

Devices & Wall Plates Color Selection Chart




Pass & Seymour

Devices & Plastic Wall Plate Colors

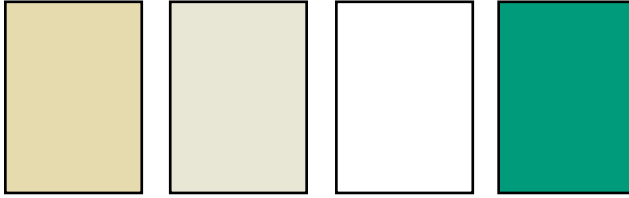


Ivory Light Almond White Green

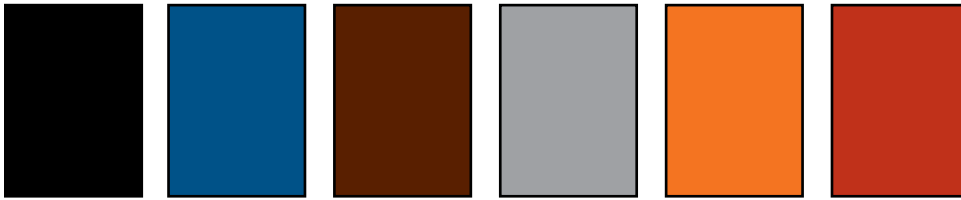

Black Blue Brown Gray Orange Red


See specific device and wall plate catalog charts for particular color availabilities.

Metal Wall Plates

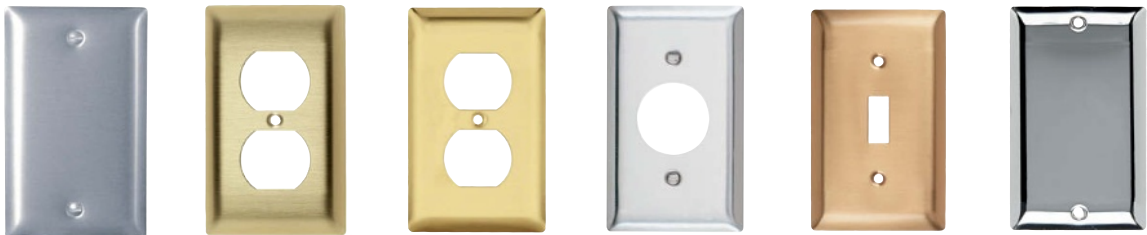

Metal Finish Aluminum Brass (Brushed) Polished Brass Stainless Steel Brushed Bronze Chrome

Custom Metal Wall Plates Paint Finish Colors

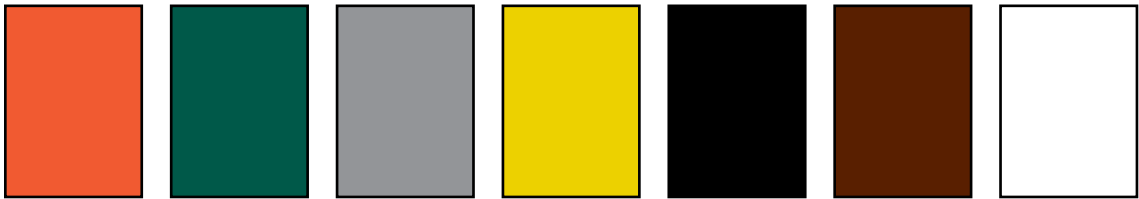

Paint Color Orange Green Gray Yellow Glossy Black Brown White



Paint Color Primer Red Pink Flat Black Ivory Light Almond Blue

To order custom metal wall plates, see Pages Q-43 – Q-45.

For additional colors consult factory.