



# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

3804 South Street  
75964-7263, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685



## TP614 Hndy BX CVR, BLNK W/1/2 Ko *Crouse-Hinds*

Catalog Number	TP614
Manufacturer	Crouse-Hinds
Description	Utility Box Cover, Steel, 2.125 In Width, Box Mount, 0.03 LB/Ea
Weight per unit	0.0300 (lbs/each)
Product Category	Bar Hangers & Outlet Box Accy.

### Features

Shape	RECTANGULAR
-------	-------------

### Material, Color, and Finish

Color	IVORY
Finish	NATURAL

### Descriptions

Description	HNDY BX CVR,BLNK W/1/2 KO
Special Features	Weight 10 Lb per 100

### Manufacturer Information

Brand	EATON CROUSE-HINDS SERIES
GTIN	00786189106145
sub brand	Commercial Products
UPC	786189106145

### Taxonomies, Classifications, and Categories

Category Description	HANDY BOXES
Type	BLANK

### Packaging

Carton	25
Package	100
Weight Per each	0.03

### Uses, Certifications, and Standards

standard	UL, CSA
----------	---------

# Steel Utility Boxes & Covers


## UTILITY BOXES – CUBIC INCH CAPACITY (SEE BELOW)

4" LONG x 2 1/8" WIDE


UL LISTED



TP588, TP647

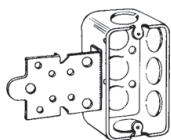

TP591

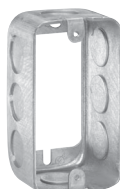

TP592, TP600,  
TP602



TP598, TP605



TP594, TP596



TP604, TP606

Cat. #	Bracket	Knockouts		Unit Qty.	Wt. Lbs. Per 100
		Sides	Bottom		
<b>1 1/4" Deep – 8.5 Cubic Inch Capacity</b>					
TP647	-	8 - 1/2"	3 - 1/2"	50	40
<b>1 1/2" Deep – 10.3 Cubic Inch Capacity</b>					
TP588	-	8 - 1/2"	3 - 1/2"	50	42
TP591	"F", Set 1/4"	5 - 1/2"	3 - 1/2"	50	51
<b>1 1/2" Deep Extension Rings – 10.3 Cubic Inch Capacity</b>					
TP592	-	8 - 1/2"	-	50	36
<b>1 7/8" Deep – 13.0 Cubic Inch Capacity</b>					
TP594	-	8 - 1/2"	3 - 1/2"	50	50
TP596	-	6 - 3/4"	3 - 1/2"	50	50
TP598	"S", Set 1/2"	5 - 1/2"	3 - 1/2"	50	60
<b>1 7/8" Deep Extension Rings – 13.0 Cubic Inch Capacity</b>					
TP600	-	8 - 1/2"	-	50	41
TP602	-	6 - 3/4"	-	50	41
<b>2 1/8" Deep – 14.5 Cubic Inch Capacity</b>					
TP604	-	8 - 1/2"	3 - 1/2"	50	56
TP606	-	6 - 3/4"	3 - 1/2"	50	56
TP605	"S", Set 1/2"	5 - 1/2"	3 - 1/2"	50	66

## UTILITY BOX COVERS

UL LISTED



TP608



TP610



TP612



TP613



TP614



TP616



TP618

Cat. #	Description	Unit Qty.	Wt. Lbs. Per 100
TP608*	Blank	100	10
TP610*	For 20 and 30 Amp, Twist Lock, 1 1/2" Dia.	100	9
TP612*	Single Receptacle, 1 1/2" Dia.	100	9
TP613*	For GFCI Device	100	7
TP614*	1/2" KO	100	10
TP616*	Duplex Receptacle	100	8
TP618*	One Toggle Switch	100	10

\*CSA certified.

Steel Boxes