


Specifications



Photo is representative

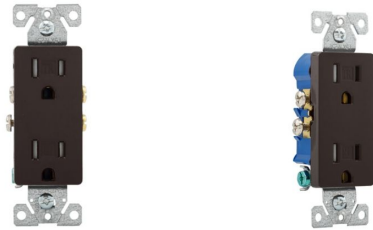

Eaton TR1107B-BOX

Eaton residential grade decorator duplex receptacle, #14-10 AWG, 15A, Commercial, Residential, Flush, 125V, Side and push, Brown, Brass, Impact-resistant thermoplastic face, PVC body, 5-15R, Duplex, Screw, Thermoplastic, ED Box

General specifications

PRODUCT NAME	Eaton residential grade decorator duplex receptacle
CATALOG NUMBER	TR1107B-BOX
UPC	032664752490
PRODUCT LENGTH/DEPTH	1.3 in
PRODUCT HEIGHT	3.81 in
PRODUCT WIDTH	0.69 in
PRODUCT WEIGHT	0.001 lb
CERTIFICATIONS	cULus Listed NOM
PRODUCT TYPE	Residential grade



Powering Business Worldwide

Product specifications

DEVICE TYPE	Receptacle
TYPE	Decorator duplex receptacle
AMPERAGE RATING	15A
VOLTAGE RATING	125V
CONTACT MATERIAL	Brass
FEATURES	Tamper resistant
APPLICATION	Commercial/residential
DEVICE GRADE	Standard grade
WIRING METHOD	Side and push
NUMBER OF WIRES	3
MOUNTING METHOD	Flush
NUMBER OF POLES	Two-pole
STYLE TYPE	Decorator
MATERIAL	Thermoplastic
PACKAGING TYPE	ED Box
COLOR	Brown
CONNECTION TYPE	Screw
ALLOWABLE WIRE SIZE	Push-In Terminals Wiring: #14 AWG copper (CU) Only, Side Wiring: #10-14 Copper or Copper Clad Aluminum
NEMA CONFIGURATION	5-15R
TORQUE RATING	14 lbf-inch
DESIGN TYPE	Straight blade
FACE/BODY MATERIAL	Impact-resistant thermoplastic face PVC body
RECEPTACLE TYPE	Duplex

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:

Resources

MULTIMEDIA	Residential straight blade receptacles
SPECIFICATIONS AND DATASHEETS	Eaton Specification Sheet - TR1107B-BOX Duplex tamper resistant receptacles spec sheet



Eaton Corporation plc Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2026 Eaton. All Rights Reserved.


Follow us on social media to get the latest product and support information.



Specifications



Photo is representative

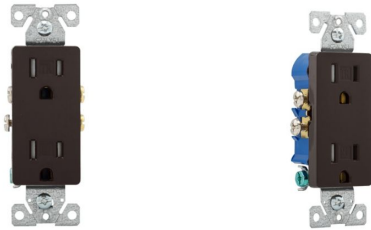

Eaton TR1107B-BOX

Eaton residential grade decorator duplex receptacle, #14-10 AWG, 15A, Commercial, Residential, Flush, 125V, Side and push, Brown, Brass, Impact-resistant thermoplastic face, PVC body, 5-15R, Duplex, Screw, Thermoplastic, ED Box

General specifications

PRODUCT NAME	Eaton residential grade decorator duplex receptacle
CATALOG NUMBER	TR1107B-BOX
UPC	032664752490
PRODUCT LENGTH/DEPTH	1.3 in
PRODUCT HEIGHT	3.81 in
PRODUCT WIDTH	0.69 in
PRODUCT WEIGHT	0.001 lb
CERTIFICATIONS	cULus Listed NOM
PRODUCT TYPE	Residential grade



Powering Business Worldwide

Product specifications

DEVICE TYPE	Receptacle
TYPE	Decorator duplex receptacle
AMPERAGE RATING	15A
VOLTAGE RATING	125V
CONTACT MATERIAL	Brass
FEATURES	Tamper resistant
APPLICATION	Commercial/residential
DEVICE GRADE	Standard grade
WIRING METHOD	Side and push
NUMBER OF WIRES	3
MOUNTING METHOD	Flush
NUMBER OF POLES	Two-pole
STYLE TYPE	Decorator
MATERIAL	Thermoplastic
PACKAGING TYPE	ED Box
COLOR	Brown
CONNECTION TYPE	Screw
ALLOWABLE WIRE SIZE	Push-In Terminals Wiring: #14 AWG copper (CU) Only, Side Wiring: #10-14 Copper or Copper Clad Aluminum
NEMA CONFIGURATION	5-15R
TORQUE RATING	14 lbf-inch
DESIGN TYPE	Straight blade
FACE/BODY MATERIAL	Impact-resistant thermoplastic face PVC body
RECEPTACLE TYPE	Duplex

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:

Resources

MULTIMEDIA	Residential straight blade receptacles
SPECIFICATIONS AND DATASHEETS	Eaton Specification Sheet - TR1107B-BOX Duplex tamper resistant receptacles spec sheet



Eaton Corporation plc Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2026 Eaton. All Rights Reserved.

Follow us on social media to get the latest product and support information.

