



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

3804 South Street
75964-7263, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685



TRVGF15W 15A TR WH GFI Rec *Eaton Wiring Devices*

Catalog Number	TRVGF15W
Manufacturer	Eaton Wiring Devices
Description	Duplex Receptacle, 15 A, 125 V, 2 Poles, 3 Wires, Screw Mount, 1.3 In Width, Nylon (Top Housing);PVC (Bottom Housing) Material, White, Tamper Resistant
Weight per unit	0.4000 (lbs/each)
Product Category	Gen Purpose Recept & Surge Pro

Features

amperage rating	15 A
connection	4714
Poles	2 Pole/ 3 Wire

Descriptions

Description	15A TR WH GFI REC
-------------	-------------------

Manufacturer Information

Brand	COOPER WIRING DEVICES
GTIN	00032664665776
sub brand	ARROW HART
UPC	032664665776

Taxonomies, Classifications, and Categories

Category Description	Commercial recepticals
Type	Duplex, GFCI, Straight Blade

Availability

Status	Inactive
--------	----------

Packaging

Carton	1
Package	10
Weight Per each	0.4

Uses, Certifications, and Standards



Enclosure	Tamper Resistant NEC Requirements
standard	UL mA

Specification grade GFCIs


Specification grade ground fault circuit interrupter receptacles

Product description


2-pole, 3-wire grounding
15A, 125V/AC; 20A, 125V/AC
NEMA 5-15, 5-20

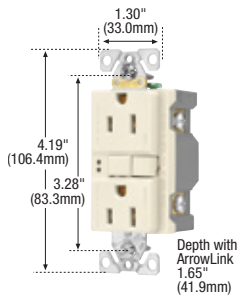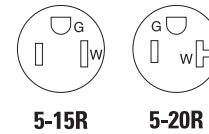

SGF15

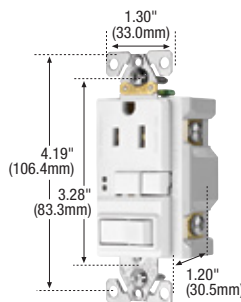



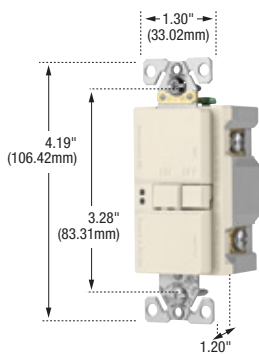







SGFS15





SGFD20

Specification grade GFCIs

Rating							
A	V/AC	NEMA	Description	Color suffix	Catalog no.		
15	125	5-15R	Duplex GFCI, back & side wire	A, B, BK, GY, LA, V, W	<input type="checkbox"/> SGF15__		
			Duplex GFCI, mid-size wallplate, back & side wire	A, LA, V, W	<input type="checkbox"/> SGF15__-M		
			Duplex GFCI, back & side wire	B, BK, GY, LA, RD, V, W	<input type="checkbox"/> SGF15F__		
20	125	5-20R	Duplex GFCI, back & side wire	A, B, BK, GY, LA, RD, V, W	<input type="checkbox"/> SGF20__		
			Duplex GFCI, back & side wire	B, BK, GY, LA, RD, V, W	<input type="checkbox"/> SGF20F__		

Includes standard size unbreakable wallplate unless otherwise noted
Consult factory customer service representative for additional packaging options









Specification grade combination GFCI receptacle & switch

Rating							
A	V/AC	NEMA	Description	Color suffix	Catalog no.		
15	125	5-15R	GFCI receptacle with feed-through single-pole switch (rated 1800W @ 120V/AC, 60Hz)	A, LA, V, W	<input type="checkbox"/> SGFS15__-MSP		

Specification grade blank face GFCI

Rating							
A	V/AC	Description	Color suffix	Catalog no.			
20	125	Blank face (dead front) GFCI, rated as 1.5HP motor control switch, back & side wire	A, BK, LA, V, W	<input type="checkbox"/> SGFD20__			

Accessories for GFCIs

Description	Color suffix	Catalog no.		
GFCI 7/8" extension ring, cULus Listed	BLK, LA, V, W	<input type="checkbox"/> GFER__		
Metal self-closing horizontal 1-Gang weather protective cover, decorator opening		<input type="checkbox"/> S1966		
While-in-use metal weather protective standard depth 1-Gang cover, vertical mount		<input type="checkbox"/> WIUMV-1		



GFER



S1966



WIUMV-1



WIUMH-1


Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), GY (Gray), LA (Light Almond), RD (Red), V (Ivory), W (White)

A	B	BK/BLK	GY	LA	RD	V	W
(Almond)	(Brown)	(Black)	(Gray)	(Lt. Almond)	(Red)	(Ivory)	(White)

Specification information: Specification grade GFCI: H-18

Compliances, specifications and availability are subject to change without notice.

 ArrowLink option available. Add "MOD" suffix to standard catalog number (example SGF15W, SGF15WMOD). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page H-4



RoHS compliant - Page Q-32