



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.
75964-0000, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685



U5168XTL100 100A 8/16 CKT Oh 4 Jaw Ringless Combo Panel

Milbank MFG.

Catalog Number	U5168XTL100
Manufacturer	Milbank MFG.
Description	Load Center Combination Meter Socket, Ringless Type; 14-1/8 Inch W X 4-1/2 Inch D X 32 Inch H Size; 6 Awg to 250 Kcmil Wire Size; Galvanized Steel Enclosure Material; UL Approval; 120/240 Vac Voltage Rating; Surface Mounting; Nema 3R Enclosure
Weight per unit	39.0 (lbs/each)
Product Category	Commercial Meter Mains

Features

Bypass Switch Type	NO
Circuit Configuration	1-Phase 3-Wire
Current Rating	100 AMPERE
Hub Type	CLOSING PLATE
Knockouts	(3) 2 Inch, (1) 3 Inch, (1) 2-1/2 Inch, (4) 1 Inch, (3) 3/4 Inch
Number of Circuits	10 A
Number of Jaws	4 in
Service Type	OVERHEAD/UNDERGROUND
Voltage Rating	120/240 VAC
Wire Size	6 AWG TO 250 KCMIL

Material, Color, and Finish

Enclosure Material	GALVANIZED STEEL
--------------------	------------------

Dimensions and Weight

Size	14-1/8 Inch W x 4-1/2 Inch D x 32 Inch H
------	--

Descriptions

Commodity Description	COMMERCIAL METER MAINS
Description	100A 8/16 CKT OH 4 JAW RINGLESS COMBO PANEL
Long Description	LOAD CENTER COMBINATION METER SOCKET, RINGLESS TYPE; 14-1/8 INCH W X 4-1/2 INCH D X 32 INCH H SIZE; 6 AWG TO 250 KCMIL WIRE SIZE; GALVANIZED STEEL ENCLOSURE MATERIAL; UL APPROVAL; 120/240 VAC VOLTAGE RATING; SURFACE MOUNTING; NEMA 3R ENCLOSURE
Product Type	Load Center Combination Meter Socket

Manufacturer Information

Brand	MILBANK
GTIN	00784572475281
Manufacturers Part Number	U5168-XTL-100
Model	U5168
UPC	784572475281



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.
75964-0000, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685

Taxonomies, Classifications, and Categories

Category Description	TEMP. POWER PANELS & ACCESSORIES
Type	RINGLESS

Packaging

Carton	1
Package	48
Weight Per each	39


Uses, Certifications, and Standards

Approval	UL mA
Enclosure	NEMA 3R
Mounting	SURFACE

Meter Main with Load Center

100–200 amp | 4 & 5 Terminal | Ringless & Ring Type

25
METER
MAIN WITH
LOAD CENTER

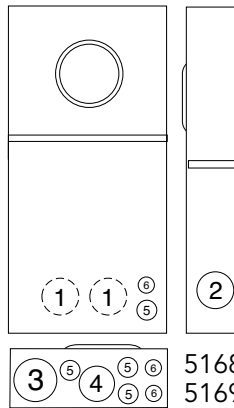

5168 5268
5169 5269



U5268-XTL-200-KK

Generator Interlock



K5815 - large QN with small frame Q

K5820 - large frame QN with large frame QN

K5830 - small frame Q to small frame Q

U5168-XTL-200

100–200 amp | Meter Mains | 120/240 Volts | 1Ø3W | Overhead/Underground

Catalog Number	Terminal	amp	Circuits	Hub	Connectors	Bypass	Dimensions			Knockouts					
							D"	W"	H"	1	2	3	4	5	6
U5168-XTL-100**	4	100	10	C.P.	#6-350	None	4½	14⅞	32	2	2	3	2½	1	¾
U5168-XTL-150**	4	150	8	C.P.	#6-350	None	4½	14⅞	32	2	2	3	2½	1	¾
U5168-XTL-200**	4	200	8	C.P.	#6-350	None	4½	14⅞	32	2	2	3	2½	1	¾
U5168-XTL-100-KK**	4	100	10	C.P.	#6-350	Horn	4½	14⅞	32	2	2	3	2½	1	¾
U5168-XTL-150-KK**	4	150	8	C.P.	#6-350	Horn	4½	14⅞	32	2	2	3	2½	1	¾
U5168-XTL-200-KK**	4	200	8	C.P.	#6-350	Horn	4½	14⅞	32	2	2	3	2½	1	¾
U5168-XTL-100-KK-5T**	5	100	10	C.P.	#6-350	Horn	4½	14⅞	32	2	2	3	2½	1	¾
U5168-XTL-150-KK-5T**	5	150	8	C.P.	#6-350	Horn	4½	14⅞	32	2	2	3	2½	1	¾
U5169-XTL-100	4	100	10	C.P.	#6-350	None	4½	14⅞	32	2	2	3	2½	1	¾
U5169-XTL-150	4	150	8	C.P.	#6-350	None	4½	14⅞	32	2	2	3	2½	1	¾
U5169-XTL-200	4	200	8	C.P.	#6-350	None	4½	14⅞	32	2	2	3	2½	1	¾
U5268-XTL-150**	4	150	20	C.P.	#6-350	None	4½	14⅞	32	2	2	3	2½	1	¾
U5268-XTL-200**	4	200	20	C.P.	#6-350	None	4½	14⅞	32	2	2	3	2½	1	¾
U5268-XTL-150-KK**	4	150	20	C.P.	#6-350	Horn	4½	14⅞	32	2	2	3	2½	1	¾
U5268-XTL-200-KK**	4	200	20	C.P.	#6-350	Horn	4½	14⅞	32	2	2	3	2½	1	¾
U5269-XTL-200	4	200	20	C.P.	#6-350	Horn	4½	14⅞	32	2	2	3	2½	1	¾

Notes

- **Hubs:** Supplied with (2) closing plates packed inside. Order hubs as a separate item. See accessory page for hub options.
 - **Interior:** U5168 units have 8-circuit interior; U5268 units have 20-circuit interior
 - **Fifth Terminal:** Order K5T and field install for 208Y/120 network systems. Installs in the 9 o'clock position only.
 - **Branch Breakers:** Series rated 22K AIC with Milbank QNR2200H main installed.
 - **Interlock Kit:** For generator auxiliary circuit breaker interlock, order K5815 for large QN with small frame Q; order K5820 for large frame QN with large frame QN; order K5830 for small frame Q with small frame Q.
 - **Sub-Feed Lugs:** #6-350 kcmil sub-feed lugs provided on 8 and 10 circuit interior. **Not available on 20 circuit interior.**
- * amp rating limited to main breaker rating. Interior has 10 branch circuit breaker provisions.
** Ringless

Utility requirements for this equipment may vary. Always consult the serving utility for their requirements prior to ordering or installing this equipment. This product must be installed by a licensed electrician. Installation of this equipment may require local electrical inspector approval.

