


# Meter Main with Load Center

100–200 amp | 4 & 5 Terminal | Ringless & Ring Type

**25**  
METER  
MAIN WITH  
LOAD CENTER

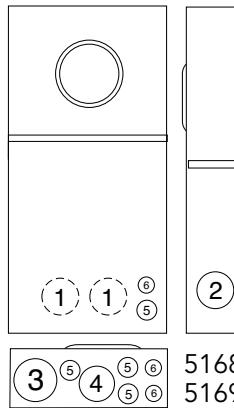

5168 5268  
5169 5269



## Generator Interlock



**K5815** - large QN with small frame Q

**K5820** - large frame QN with large frame QN

**K5830** - small frame Q to small frame Q

**U5168-XTL-200**

**U5268-XTL-200-KK**

100–200 amp | Meter Mains | 120/240 Volts | 1Ø3W | Overhead/Underground

Catalog Number	Terminal	amp	Circuits	Hub	Connectors	Bypass	Dimensions			Knockouts					
							D"	W"	H"	1	2	3	4	5	6
<b>U5168-XTL-100**</b>	4	100	10	C.P.	#6-350	None	4½	14⅞	32	2	2	3	2½	1	¾
<b>U5168-XTL-150**</b>	4	150	8	C.P.	#6-350	None	4½	14⅞	32	2	2	3	2½	1	¾
<b>U5168-XTL-200**</b>	4	200	8	C.P.	#6-350	None	4½	14⅞	32	2	2	3	2½	1	¾
<b>U5168-XTL-100-KK**</b>	4	100	10	C.P.	#6-350	Horn	4½	14⅞	32	2	2	3	2½	1	¾
<b>U5168-XTL-150-KK**</b>	4	150	8	C.P.	#6-350	Horn	4½	14⅞	32	2	2	3	2½	1	¾
<b>U5168-XTL-200-KK**</b>	4	200	8	C.P.	#6-350	Horn	4½	14⅞	32	2	2	3	2½	1	¾
<b>U5168-XTL-100-KK-5T**</b>	5	100	10	C.P.	#6-350	Horn	4½	14⅞	32	2	2	3	2½	1	¾
<b>U5168-XTL-150-KK-5T**</b>	5	150	8	C.P.	#6-350	Horn	4½	14⅞	32	2	2	3	2½	1	¾
<b>U5169-XTL-100</b>	4	100	10	C.P.	#6-350	None	4½	14⅞	32	2	2	3	2½	1	¾
<b>U5169-XTL-150</b>	4	150	8	C.P.	#6-350	None	4½	14⅞	32	2	2	3	2½	1	¾
<b>U5169-XTL-200</b>	4	200	8	C.P.	#6-350	None	4½	14⅞	32	2	2	3	2½	1	¾
<b>U5268-XTL-150**</b>	4	150	20	C.P.	#6-350	None	4½	14⅞	32	2	2	3	2½	1	¾
<b>U5268-XTL-200**</b>	4	200	20	C.P.	#6-350	None	4½	14⅞	32	2	2	3	2½	1	¾
<b>U5268-XTL-150-KK**</b>	4	150	20	C.P.	#6-350	Horn	4½	14⅞	32	2	2	3	2½	1	¾
<b>U5268-XTL-200-KK**</b>	4	200	20	C.P.	#6-350	Horn	4½	14⅞	32	2	2	3	2½	1	¾
<b>U5269-XTL-200</b>	4	200	20	C.P.	#6-350	Horn	4½	14⅞	32	2	2	3	2½	1	¾

## Notes

- **Hubs:** Supplied with (2) closing plates packed inside. Order hubs as a separate item. See accessory page for hub options.
  - **Interior:** **U5168** units have 8-circuit interior; **U5268** units have 20-circuit interior
  - **Fifth Terminal:** Order **K5T** and field install for 208Y/120 network systems. Installs in the 9 o'clock position only.
  - **Branch Breakers:** Series rated **22K AIC** with Milbank **QNR2200H** main installed.
  - **Interlock Kit:** For generator auxiliary circuit breaker interlock, order **K5815** for large **QN** with small frame **Q**; order **K5820** for large frame **QN** with large frame **QN**; order **K5830** for small frame **Q** with small frame **Q**.
  - **Sub-Feed Lugs:** #6-350 kcmil sub-feed lugs provided on 8 and 10 circuit interior. **Not available on 20 circuit interior.**
- \* amp rating limited to main breaker rating. Interior has 10 branch circuit breaker provisions.  
\*\* Ringless

Utility requirements for this equipment may vary. Always consult the serving utility for their requirements prior to ordering or installing this equipment. This product must be installed by a licensed electrician. Installation of this equipment may require local electrical inspector approval.

