

# Meter Mains

200 Amp | 4 & 7 Terminal | Lever Bypass | Ringless

23

200 AMP  
METER  
MAINS



 

U5880-RXL-200-BL




U5871-XL-200



U5750-RXL-200-BL

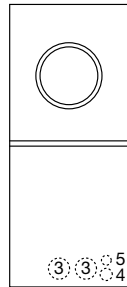

5871  
5872  
5880

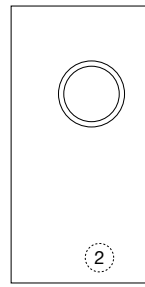

5750

## 200 Amp – Meter Mains – Lever Bypass – Ringless

Catalog Number	Terminals	Service	Hub	Connectors CU/AL - Line	Branch Circuits	Dimensions			Knockouts					
						D"	W"	H"	1	2	3	4	5	6
U5880-RXL-200-BL	4	OH/UG	C.P.	#6-350	—	4½	14⅛	33½	3	2½	2	1	½,¾	¼,½
U5871-XL-200	4	OH/UG	C.P.	#6-350	8	4½	14⅛	32	3	2½	2	1	½,¾	¼,½
U5872-XL-200	4	OH/UG	C.P.	#6-350	20	4½	14⅛	32	3	2½	2	1	½,¾	¼,½
U5750-RXL-200-BL	7	OH/UG	C.P.	#6-350	—	5¾	17⅞	34	4	3	1	¼	—	—

### Notes

- **Breakers:** Rated 22K AIC with Milbank **QNR2200H** main installed.
- **Fifth Terminal:** For field installed fifth terminal, order **K5T**.
- **Interlock Kit:** For generator auxiliary circuit breaker interlock for **U5871** and **U5872**, order **K5815** for large **QN** with small frame **Q**; order **K5820** for large frame **QN** with large frame **QN**.
- **Sub Feed Lugs:** #6-350 sub feed lugs provided on 8 circuit interior. **Not available on 20 circuit interior.**
- **-BL:** Barrel lock