

UAP6095-O-NES







Catalog Number	UAP6095-O-NES
Marketing Product Description	Aluminum Painted Shell 22 Position Per Phase Bar 500 Kcmil Penta Bolt
UPC	784572703926
Length (IN)	16
Width (IN)	32.375
Height (IN)	43
Weight (LB)	138
Brand Name	Milbank
Type	Terminal Box
Special Features	4000 Ampere; Three Phase Four Wire; Penta Bolt; 10,000 Short Circuit Current Rating
Application	Terminate Conductors
Standard	UL Listed
Number Of Outlet	0
Material	Aluminum
Size	16L x 32.375W x 43H
Color	ANSI 61 Gray
Construction	Welded
Cable Entry	No Knockouts
Mounting	Pad Mount or Wall Mount
NEMA Rating	Type 3R

Hinge Type	Lift Off Hinges
Top	Plain Top
Door	Hinged Cover
Latch	Padlocking Handle with 3 Point Latch Assembly
Support	Body Stiffeners

Please consult serving utility for their requirements prior to ordering or installing, as specifications and approvals vary by utility and may require local electrical inspector approval. All installations must be installed by a licensed electrician and must comply with all national and local codes, laws and regulations. Milbank reserves the right to make changes in specifications and features shown without notice or obligation.

FEATURE TABLE		
ITEM	QTY	DESCRIPTION
A	4	TRANS. MNTG.EMBOSS, NO HOLE

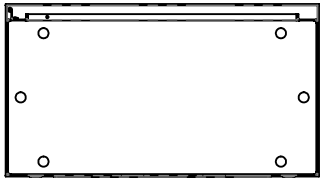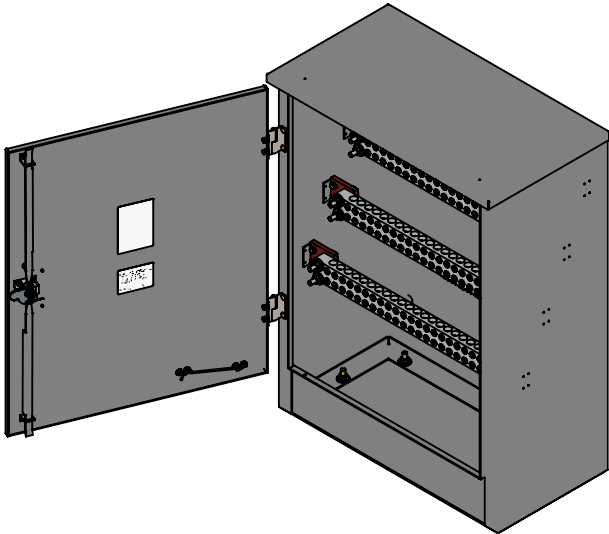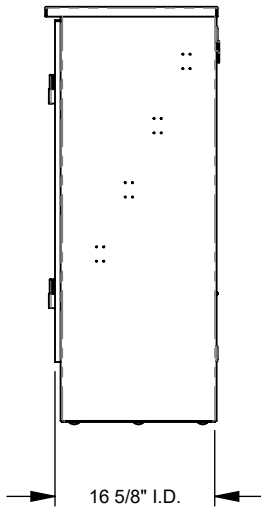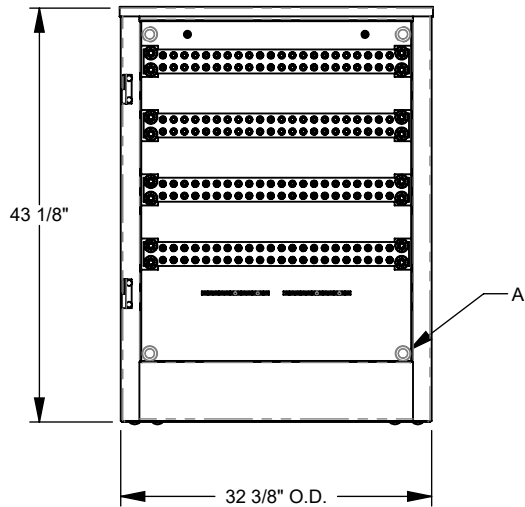

Version:

1

**All dimensions are +/- 1/16".
Drawing views are not to scale.**

Please consult serving utility for their requirements prior to ordering or installing, as specifications and approvals vary by utility, and may require local electrical inspector approval. All installations must be installed by a licensed electrician and must comply with all national and local codes, laws and regulations. Milbank reserves the right to make changes in specifications and features shown without notice or obligation.

UAP6095-O-NES







Catalog Number	UAP6095-O-NES
Marketing Product Description	Aluminum Painted Shell 22 Position Per Phase Bar 500 Kcmil Penta Bolt
UPC	784572703926
Length (IN)	16
Width (IN)	32.375
Height (IN)	43
Weight (LB)	138
Brand Name	Milbank
Type	Terminal Box
Special Features	4000 Ampere; Three Phase Four Wire; Penta Bolt; 10,000 Short Circuit Current Rating
Application	Terminate Conductors
Standard	UL Listed
Number Of Outlet	0
Material	Aluminum
Size	16L x 32.375W x 43H
Color	ANSI 61 Gray
Construction	Welded
Cable Entry	No Knockouts
Mounting	Pad Mount or Wall Mount
NEMA Rating	Type 3R

Hinge Type	Lift Off Hinges
Top	Plain Top
Door	Hinged Cover
Latch	Padlocking Handle with 3 Point Latch Assembly
Support	Body Stiffeners

Please consult serving utility for their requirements prior to ordering or installing, as specifications and approvals vary by utility and may require local electrical inspector approval. All installations must be installed by a licensed electrician and must comply with all national and local codes, laws and regulations. Milbank reserves the right to make changes in specifications and features shown without notice or obligation.

FEATURE TABLE		
ITEM	QTY	DESCRIPTION
A	4	TRANS. MNTG.EMBOSS, NO HOLE

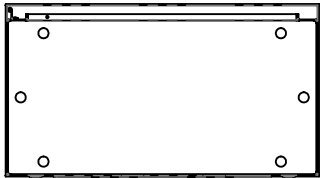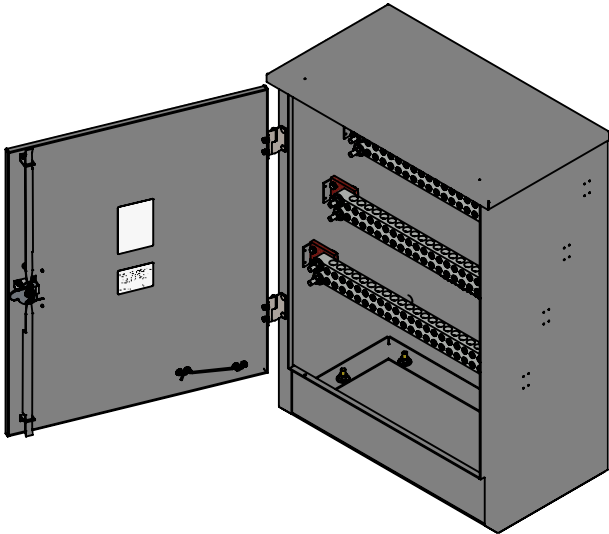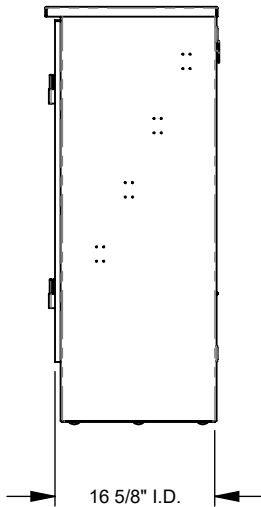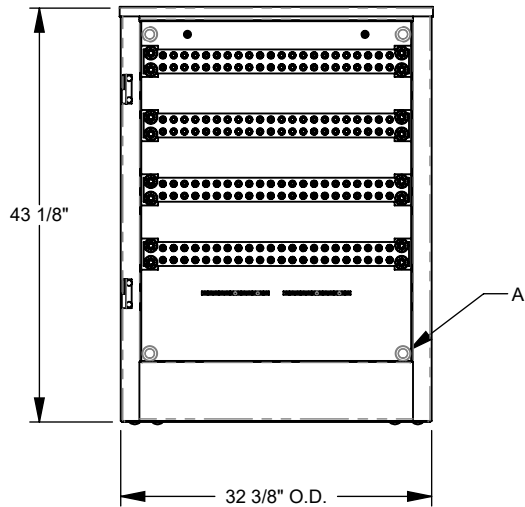

Version:

1

**All dimensions are +/- 1/16".
Drawing views are not to scale.**

Please consult serving utility for their requirements prior to ordering or installing, as specifications and approvals vary by utility, and may require local electrical inspector approval. All installations must be installed by a licensed electrician and must comply with all national and local codes, laws and regulations. Milbank reserves the right to make changes in specifications and features shown without notice or obligation.