
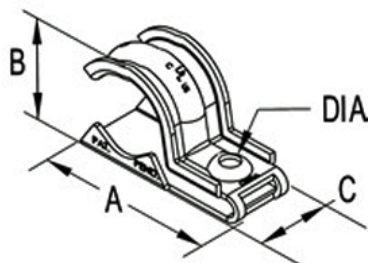


Universal Clamp Straps

Images

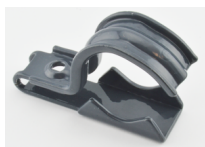

Application

The one piece clamp back and strap secures both cable and conduit. The UCSC125150 secures 1 1/4" and 1-1/2" EMT/Rigid/IMC, Coated EMT/Rigid/IMC, Metallic Liquid Tight, Nonmetallic Liquid Tight, FMC, and Schedule 40 and Schedule 80 PVC conduit, as well as 1.505" Ø to 1.950" Ø steel and aluminum AC/MC/Jacketed MC cable. Patent Pending

Product Information

Material: Polyolefin Coated Zinc Plated Steel

Certifications & Codes:

Federal Specification Number:	A-A-50553
NEMA Standard:	FB-1
UL File Number:	ETL Listed
UL Standard:	UL-514B
UNSPSC:	39121705

Catalog ID: UCSC125150

UPC Number: 78174714935

Description: One piece clamp back and strap combination, 1 hole, Steel, 1-1/4" - 1-1/2" Trade Size, Polyolefin Coated

Application: The one piece clamp back and strap secures both cable and conduit. The UCSC125150 secures 1 1/4" and 1-1/2" EMT/Rigid/IMC, Coated EMT/Rigid/IMC, Metallic Liquid Tight, Nonmetallic Liquid Tight, FMC, and Schedule 40 and Schedule 80 PVC conduit, as well as 1.505" Ø to 1.950" Ø steel and aluminum AC/MC/Jacketed MC cable. Patent Pending

Trade Size: 1-1/4" - 1-1/2"

Std Pkg Qty: 25

Unit Qty: 1

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 3.38

Dimension B in Inches: 2.28

Dimension C in Inches: 1.13

Dimension D in Inches: 0.28