



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

3804 South Street
75964-7263, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685



V4034WWH 4" Eco Trim *Lithonia Lighting*

Catalog Number	V4034WWH
Manufacturer	Lithonia Lighting
Description	Eco Trim, White Baffle, 1 LB
Weight per unit	1.0 (lbs/each)
Product Category	Lighting Accessories

Features

aperture size	4-in
Shape	Round IN

Descriptions

Description	4" ECO TRIM
-------------	-------------

Manufacturer Information

Brand	LITHONIA LIGHTING
GTIN	00661209210739
UPC	661209210739

Taxonomies, Classifications, and Categories

Category Description	All Recessed Cans & Trims
Type	Downlight

Packaging

Carton	1
Weight Per each	1



4" TC REMODEL HOUSING

INCANDESCENT LAMPS

TC1RC

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

PRODUCT DESCRIPTION

TC Remodel Housing designed for use in non-insulated areas

- Shallow housing construction allows for fit in 2 x 6 construction
- Juno Type TC fixtures are designed for installations where housing and J-Box will not come into contact with insulation
- Blinking light after installation indicates that improper bulb or trim is being used or that fixture has been improperly covered with insulation
- In U.S., insulation must be spaced 3" away from the housing and J-Box
- TC Remodel Housing for remodel application where back side of ceiling is not accessible
- Installs through an opening in the ceiling from below
- Secured in place by factory installed screw driven remodel clamps for easy installation into ceiling material.

PRODUCT SPECIFICATIONS

Lamp Lamp ratings based on trim selected – see reverse.

Socket Detachable medium base porcelain with nickel-plated copper screw shell.

Trims Trim selection shown on reverse.

Labels UL/cUL listed for U.S. and Canada through-branch wiring and damp locations

- Product thermally protected against improper use of insulation
- UL/cUL Listed
- Trim No. 11, 12, 12SQ, 4101, 4102, V4012 and V4041 are wet location approved for covered ceiling applications
- Trims 14, 17, 17SQ, V4017 and V4034 are wet location approved for covered ceiling applications, **when used with outdoor rated lamps.**

Testing All reports are based on published industry procedures; field performance may differ from laboratory performance.

Specifications subject to change without notice.

INSTALLATION

Junction Box Pre-wired junction box, UL/cUL listed for through-branch wiring maximum 4 No. 12 AWG 90° C branch circuit conductors (2 in, 2 out)

- Junction box provided with removable access plate, (5) 1/2" knockouts, (4) Non-metallic sheathed cable connectors and ground wire
- Knockouts equipped with pryout slots
- Supplied with push-in electrical connectors for fast installation.

Housing TC housing, 22-gauge steel with white finish

- Remodel clamps provided with #2 Quadrex drive screws (#2 Robertson/#2 Phillips combo)
- Clamps accommodate up to a 5/8" ceiling thickness.



PRODUCT CODES

Catalog No.	Input Voltage	Lamp Types
TC1RC W N	4" Incandescent Remodel Clamp Style Non-IC Housing	120V PAR20/PAR16 Medium Base, MR16/PAR16/ES16 GU10 Base (See reverse for Trim/Lamp/Max. Wattage Ratings)

Housing and trim can be ordered together or separate, but will always ship separately.



DIMENSIONS

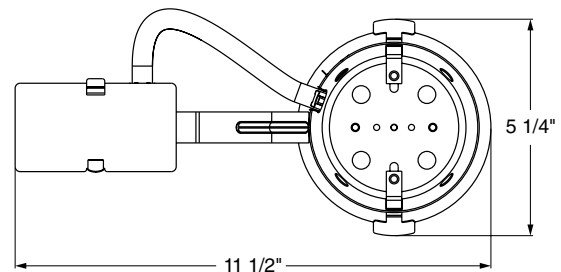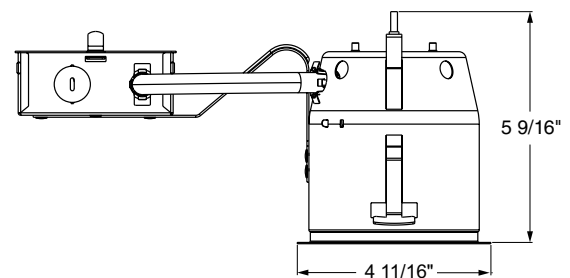

4 3/8" CEILING CUTOUT

ACCESSORIES

Catalog No.	Description
GU10WHIP	GU10 Socket Whip
SMPLT4	4" Housing Locator

















To order, specify catalog number.

4" TC REMODEL HOUSING

INCANDESCENT LAMPS

TC1RC

ROUND TRIMS/ LAMPS

	Cat. No.	Description	Max. Lamp Rating
	13 WH	4" Downlight Pinhole with Integral Shield Trim - White	50W PAR20
	14 BWH ♦♦	4" Downlight Baffle Trim - Black Baffle, White Trim Ring	
	14 BSC ♦♦	4" Downlight Baffle Trim - Black Baffle, Satin Chrome Trim Ring	50W PAR20
	14 BABZ ♦♦	4" Downlight Baffle Trim - Black Baffle, Classic Aged Bronze Trim Ring	
	14 BBL ♦♦	4" Downlight Baffle Trim - Black Baffle, Black Trim Ring	
	14 WWH ♦♦	4" Downlight Baffle Trim - White Baffle, White Trim Ring	
	17 CWH ♦♦	4" Downlight Cone Trim - Clear Alzak® Cone, White Trim Ring	50W PAR20
	17 GWH ♦♦	4" Downlight Cone Trim - Gold Cone, White Trim Ring	
	17 BWH ♦♦	4" Downlight Cone Trim - Black Cone, White Trim Ring	
	17 PTSC ♦♦	4" Downlight Cone Trim - Pewter Cone, Satin Chrome Trim Ring	
	17 WWH ♦♦	4" Downlight Cone Trim - White Cone, White Trim Ring	
	17 HZWH ♦♦	4" Downlight Cone Trim - Haze Cone, White Trim Ring	
	17 WHZWH ♦♦	4" Downlight Cone Trim - Wheat Haze Cone, White Trim Ring	
	17 WHZABZ ♦♦	4" Downlight Cone Trim - Wheat Haze Cone, Classic Aged Bronze Trim Ring	
	10 WH	4" Flush Gimbal Ringed - White	50W PAR20
	10 BL	4" Flush Gimbal Ringed - Black	
	10 SC	4" Flush Gimbal Ringed - Satin Chrome	
	10 ABZ	4" Flush Gimbal Ringed - Classic Aged Bronze	
	18 WH	4" Adjustable Mini Eyeball Trim - White	60W PAR16
	18 SC	4" Adjustable Mini Eyeball Trim - Satin Chrome	
	440 WH	4" Adjustable Flush Gimbal Ring Trim - White	50W MR16, PAR16, ES16 120V GU10 Base (Requires GU10WHIP)
	440 BL	4" Adjustable Flush Gimbal Ring Trim - Black	
	440 SC	4" Adjustable Flush Gimbal Ring Trim - Satin Chrome	
	440 ABZ	4" Adjustable Flush Gimbal Ring Trim - Classic Aged Bronze	
	445 WH	4" Adjustable Slot Aperture Trim - White	50W MR16, PAR16 ES16 120V GU10 Base (Requires GU10WHIP)
	448 WH	4" Adjustable Eyeball with Black Baffle Trim - White	50W MR16, PAR16
	448 SC	4" Adjustable Eyeball with Black Baffle Trim - Satin Chrome	ES16 120V GU10 Base (Requires GU10WHIP)
	11 WH ♦	4" Lensed Drop Opal Trim - White	50W PAR20
	12 WWH ♦	4" Frosted Lens with Clear Center Trim - Perimeter Frosted Lens, Classic Aged Bronze Trim Ring	50W PAR20
	12 WSC ♦	4" Frosted Lens with Clear Center Trim - Perimeter Frosted Lens, Satin Chrome Trim Ring	
	12 WABZ ♦	4" Frosted Lens with Clear Center Trim - White, White Trim Ring	
	446 WH	4" Wall Wash Adjustable Scoop Trim - White	50W MR16, PAR16 ES16 120V GU10 Base (Requires GU10WHIP)
	4101 WH ♦	4" Decorative Beveled Dome Lens Trim - White	50W PAR20
	4101 SC ♦	4" Decorative Beveled Dome Lens Trim - Satin Chrome	
	4101 ABZ ♦	4" Decorative Beveled Dome Lens Trim - Classic Aged Bronze	
	4102 WH ♦	4" Decorative Beveled Lensed Trim - White	50W PAR20
	4102 SC ♦	4" Decorative Beveled Lensed Trim - Satin Chrome	
	4102 ABZ ♦	4" Decorative Beveled Lensed Trim - Classic Aged Bronze	
	4103 FROSTWH	4" Decorative Beveled Cylinder Trim - Frosted Glass, White Trim Ring	50W PAR20
	4103 FROSTSC	4" Decorative Beveled Cylinder Trim - Frosted Glass, Satin Chrome Trim Ring	
	4104 HZSC	4" Decorative Beveled Cone Trim - Haze Cone, Satin Chrome Trim Ring	50W PAR20
	4104 WHZABZ	4" Decorative Beveled Cone Trim - Wheat Haze Cone, Classic Aged Bronze Trim Ring	
	4150 MESHSC	4" Decorative Glass Cylinder Trim - Mesh Glass, Satin Chrome Trim Ring	50W PAR20

4" TC REMODEL HOUSING



INCANDESCENT LAMPS

TC1RC

SQUARE TRIMS/ LAMPS

	Cat. No.	Description	Max. Lamp Rating
	175Q BWH ♦♦	4" Square Downlight Trim - Black, White Trim Ring	50W PAR20
	175Q WWH ♦♦	4" Square Downlight Trim - White, White Trim Ring	
	175Q HZWH ♦♦	4" Square Downlight Trim - Haze, White Trim Ring	
	175Q WHZWH ♦♦	4" Square Downlight Trim - Wheat Haze, White Trim Ring	
	135Q WH	4" Square Pinhole Trim - White	50W PAR20
	4405Q WH	4" Square Flush Gimbal Trim - White	50W MR16
	4405Q BL	4" Square Flush Gimbal Trim - Black	120V GU10 Base (Requires GU10WHIP, 35° Vertical Adjustment)
	125Q WWH ♦	4" Square Frosted Lens with Clear Center Trim - White, White Trim Ring	50W PAR20

VULITE TRIMS/ LAMPS

	Cat. No.	Description	Max. Lamp Rating
	V4034 BWH ♦♦	4" Baffle - Black, White Trim Ring	50W PAR20
	V4034 WWH ♦♦	4" Baffle - White, White Trim Ring	
	V4017 CWH ♦♦	4" Cone - Clear Alzak, White Trim Ring	50W PAR20
	V4010 WH	4" Gimbal Ring - White Trim Ring	50W PAR20
	V4010 BN	4" Gimbal Ring - Brushed Nickel Trim Ring	
	V4018 WH	4" Eyeball - White Trim Ring	60W PAR16
	V4012 WH	4" Stippled Opal Lens Shower With Reflector - White Trim Ring	50W PAR20
	V4040 WH	4" Gimbal Ring - White Trim Ring	50W MR16 PAR16, ES16 120V GU10 Base (Requires GU10WHIP)
	V4040 BN	4" Gimbal Ring - Brushed Nickel Trim Ring	
	V4041 WH	4" Stippled Lens Ring - White Trim Ring	50W MR16 PAR16, ES16 120V GU10 Base (Requires GU10WHIP)
	V4048 WH	4" Low Voltage Eyeball with Baffle - White Trim Ring	50W MR16 PAR16, ES16 120V GU10 Base (Requires GU10WHIP)
	GU10WHIP	GU10 Socket Whip	

♦ UL Listed for use in wet location.

♦♦ UL Listed for use in wet location with outdoor rated lamp.

Trim Size: 5" O.D.

Alzak is a registered trademark of Alcoa Corp.

Note: In Canada when insulation is present, Type IC fixtures must be used.