


Vaportight lighting


Indoor/outdoor lighting

VKG				
Cat. No.	A (in.)	B (in.)	C (in.)	D (in.)
VKG-11	3%	8 ³ / ₁₆	—	—
VKG-21	3%	8 ³ / ₁₆	—	—
VKG-12	4%	10 ¹ / ₈	—	—
VKG-22	4%	10 ¹ / ₈	—	—
VKG-11-C	—	—	4 ¹ / ₁₆	8 ³ / ₈
VKG-21-C	—	—	4 ¹ / ₁₆	8 ³ / ₈
VKG-12-C	—	—	5 ¹ / ₄	10 ⁵ / ₈
VKG-22-C	—	—	5 ¹ / ₄	10 ⁵ / ₈

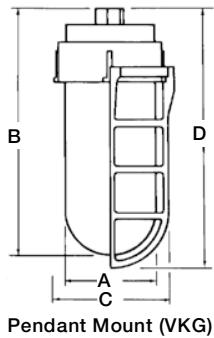


Pendant Mount (VKG)

VXG				
Cat. No.	A (in.)	B (in.)	E (in.)	F (in.)
VXG-11	3%	8 ¹³ / ₁₆	3 ¹ / ₂	1 ⁵ / ₈
VXG-21	3%	8 ¹³ / ₁₆	3 ¹ / ₂	1 ⁵ / ₈
VXG-12	4%	10 ³ / ₁₆	3 ¹ / ₂	1 ⁵ / ₈
VXG-22	4%	10 ³ / ₁₆	3 ¹ / ₂	1 ⁵ / ₈
Cat. No.	C (in.)	D (in.)		
VXG-11-C	4 ¹ / ₁₆	9 ⁹ / ₁₆		
VXG-21-C	4 ¹ / ₁₆	9 ⁹ / ₁₆		
VXG-12-C	5 ¹ / ₄	11 ¹³ / ₁₆		
VXG-22-C	5 ¹ / ₄	11 ¹³ / ₁₆		

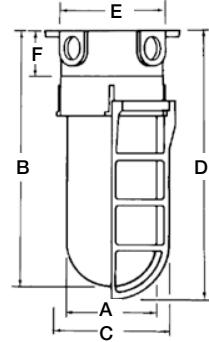


Ceiling Mount Cross Feed (VXG)

VAG				
Cat. No.	A (in.)	B (in.)	C (in.)	D (in.)
VAG-01	3 ³ / ₈	7 ⁷ / ₁₆	—	—
VAG-02	4 ¹ / ₈	9 ³ / ₈	—	—
VAG-01-C	—	—	4 ¹ / ₁₆	7 ¹⁵ / ₁₆
VAG-02-C	—	—	5 ¹ / ₄	9 ¹³ / ₁₆

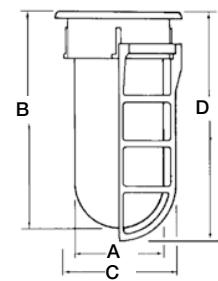


Ceiling Mount (VAG)

VWG				
Cat. No.	A (in.)	B (in.)	E (in.)	F (in.)
VWG-01	3 ³ / ₈	8 ⁷ / ₁₆	3 ³ / ₄	3 ¹ / ₂
VWG-02	4 ¹ / ₈	10 ³ / ₁₆	5 ¹ / ₄	3 ¹ / ₂
Cat. No.	C (in.)	D (in.)		
VWG-01-C	4 ¹ / ₁₆	8 ¹⁵ / ₁₆		
VWG-02-C	5 ¹ / ₄	10 ¹³ / ₁₆		

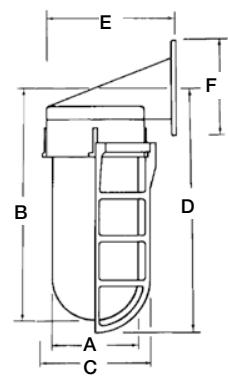

Wall Mount (VWG)


Dimensions (in.)											
Cat. No.	A	B	C	D	E	F	G	H	I	J	CI
VXWG-11	3 ³ / ₈	8 ⁷ / ₁₆	—	—	1 ⁵ / ₈	3 ¹ / ₂	—	—	—	—	—
VXWG-21	3 ³ / ₈	8 ⁷ / ₁₆	—	—	1 ⁵ / ₁₆	3 ¹ / ₂	—	—	—	—	—
VXWG-12	4 ¹ / ₈	10 ³ / ₁₆	—	—	1 ⁵ / ₁₆	3 ¹ / ₂	—	—	—	—	—
VXWG-22	4 ¹ / ₈	10 ³ / ₁₆	—	—	1 ⁵ / ₁₆	3 ¹ / ₂	—	—	—	—	—
VXWG-11-C	3 ³ / ₈	8 ⁷ / ₁₆	4 ¹ / ₁₆	8 ¹⁵ / ₁₆	1 ⁵ / ₁₆	3 ¹ / ₂	—	—	—	—	—
VXWG-21-C	3 ³ / ₈	8 ⁷ / ₁₆	4 ¹ / ₁₆	8 ¹⁵ / ₁₆	1 ⁵ / ₁₆	3 ¹ / ₂	—	—	—	—	—
VXWG-12-C	4 ¹ / ₈	10 ³ / ₁₆	5 ¹ / ₁₆	10 ¹³ / ₁₆	1 ⁵ / ₁₆	3 ¹ / ₂	—	—	—	—	—
VXWG-22-C	4 ¹ / ₈	10 ³ / ₁₆	5 ¹ / ₁₆	10 ¹³ / ₁₆	1 ⁵ / ₁₆	3 ¹ / ₂	—	—	—	—	—
LVX-1	—	—	—	—	1 ⁵ / ₈	3 ¹ / ₂	9 ¹ / ₈	5	4 ⁷ / ₁₆	2 ¹³ / ₁₆	10.3
LVX-2	—	—	—	—	1 ⁵ / ₈	3 ¹ / ₂	9 ¹ / ₈	5	4 ⁷ / ₁₆	2 ¹³ / ₁₆	10.3

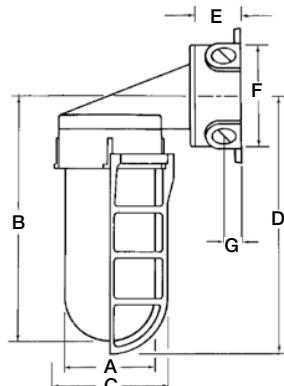

Wall Mount Cross Feed (VXWG)

Vaportight lighting Indoor/outdoor lighting

Pendant fixtures

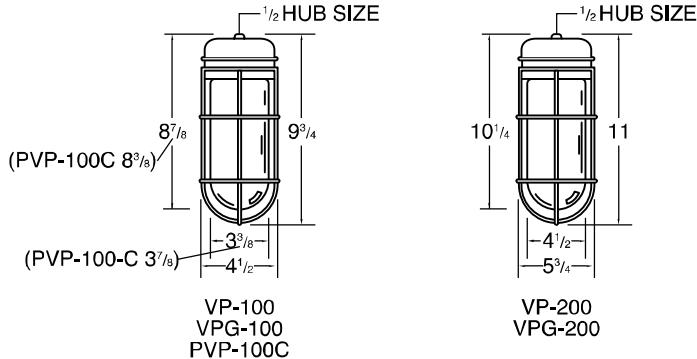


Cat. No.	Description	Max. watts	Packaging	
			Box	Std. ctn.
PVP-100*	Fixture and Clear LEXAN® Globe	100	1	12
PVPG-100B	Fixture, Blue LEXAN® Globe, Guard	100	1	12
PVPG-100R	Fixture, Red LEXAN® Globe, Guard	100	1	12


UL Listed. CSA Certified LR-95792.

* Guard not included.

VGL

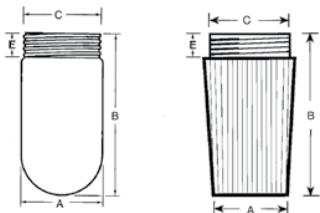

VGD, VGW

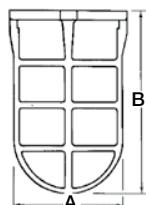

Guards (VGD, VGW)

Cat. No.	A (in.)	B (in.)	C (in.)	D (in.)	E (in.)	I.D. (in.)
VGL-01 series	3 ¹ / ₈	6 ¹⁷ / ₃₂	3 ⁵ / ₁₆	1	—	2 ¹ / ₁₆
VGL-02 series	4 ¹ / ₈	8 ¹ / ₈	4 ³ / ₁₆	1	—	3 ¹³ / ₁₆
VGLL-01	3 ¹⁷ / ₃₂	5 ¹⁵ / ₁₆	3 ⁷ / ₈	—	7/8	2 ⁷ / ₈
VGLL-02	4 ¹⁷ / ₃₂	8 ¹ / ₄	4 ³ / ₈	—	7/8	3 ⁷ / ₈
VGLA-A1	3 ¹⁷ / ₃₂	5 ¹⁵ / ₁₆	3 ⁷ / ₈	—	7/8	2 ⁷ / ₈
VGLA-R1	3 ¹⁷ / ₃₂	5 ¹⁵ / ₁₆	3 ⁷ / ₈	—	7/8	2 ⁷ / ₈

Cat. No.	A (in.)	B (in.)
VGD-01	4 ¹ / ₁₆	7
VGD-02	5 ¹ / ₁₆	8 ⁵ / ₈
VGW-01	4 ¹ / ₁₆	6 ⁴¹ / ₆₄
VGW-02	5 ¹ / ₁₆	8 ³⁷ / ₆₄