




Pass & Seymour

Weatherproof Boxes & Covers While-In-Use Covers

The NEC Section 406.8(B)(1) requires that all 15 and 20 Amp, 125 and 250 Volt outdoor receptacles in wet locations have a cover that is weatherproof — even when a plug is inserted into the receptacle.

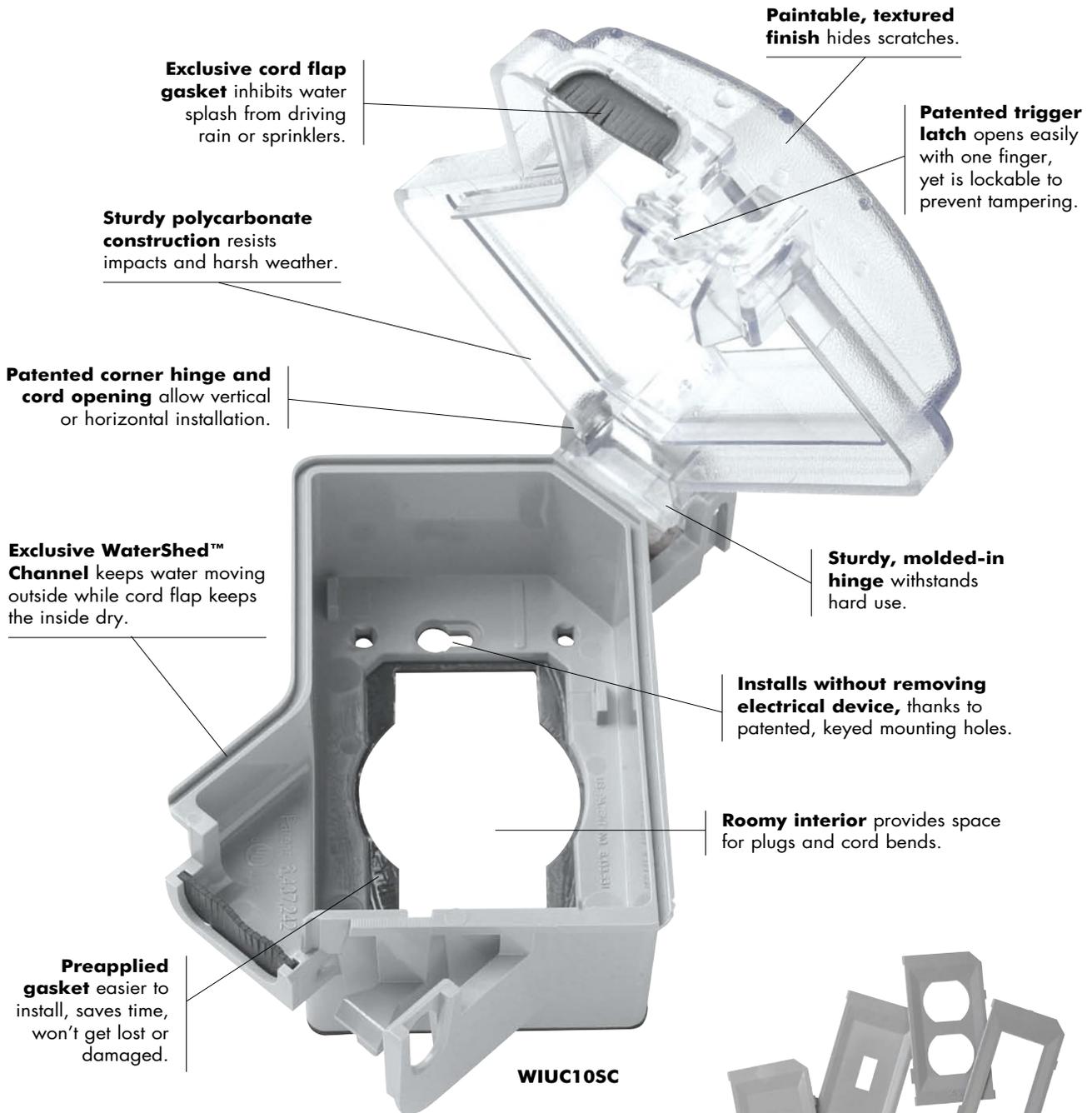

Shallow profile models have 1" shorter top lid than prior models.



Snap-in device plates require no tools to install and won't fall out. See chart for plates provided with each catalog number.


Weatherproof Boxes & Covers While-In-Use Covers



Pass & Seymour

Features	
<ul style="list-style-type: none"> Comply with NEC Section 406.8(B)(1) for wet location covers, and conform to NEMA 3R. Covers are self-closing as required by UL514C42.3. Covers mount vertically or horizontally. Body, cover, and plates made of polycarbonate. Gasket made of closed cell foam, neoprene blend regular density, UL Rated HBF. 	<ul style="list-style-type: none"> Mounting screws made of 302 stainless steel. Single receptacle plate available in 1.405" and 1.595" openings. Deep model available for 20A locking plugs. Shallow covers accommodate up to 14/3 AWG extension cords. New trigger latch opens easily with one finger.


SINGLE GANG COVERS

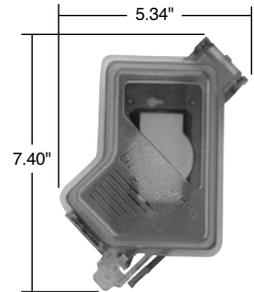

SINGLE GANG



SINGLE GANG SHALLOW

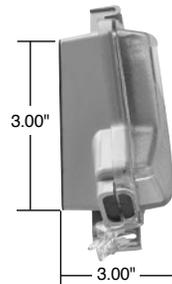

SINGLE GANG DEEP



Catalog Number	Bottom Color	Top Color	Device Plates Provided	Plate Width	Package Quantity	3rd Party Compliance
Single Gang						
WIUC10GL WIUC10CL WIUC10WL	Gray Clear White	Gray Clear White		2 3/8"	12	•
Single Gang Shallow						
WIUC10SG WIUC10SC WIUC10SW WIUC10SB	Gray Gray White White	Gray Clear White Clear		2 3/8"	14	•
Single Gang Deep						
WIUC10DGL WIUC10DCL WIUC10DWL	Gray Gray White	Gray Clear White		2 3/8"	9	•
Two Gang						
WIUC20GL WIUC20CL WIUC20WL	Gray Gray White	Gray Clear White		2"	8	•
Extra Plate Kits						
WIU10PK WIU10PKW	Gray White		Single Gang Plate Kit 	2 3/8"		•
WIU20PK WIU20PKW	Gray White		Two Gang Plate Kit 	2"		•

TWO GANG COVER

