

Wall Light

20 Watt LED

Classic Series LED
TRADITIONAL HID REPLACEMENT



Glare Free

WL20LED

WATTS: 20

CCT: 4500K

LUMENS: 1,788

LPW: 92 CRI: 84

DIMMING: 10-100%

CCT: 3000K

LUMENS: 1,696

LPW: 87 CRI: 83

DIMMING: 10-100%

Ordering Information

CATALOG #	DESCRIPTION	VOLTS	COLOR TEMP
WL20LED	20W LED Wall Light	120-277	4500K
WL20LEDPC	20W LED Wall Light with Photocontrol	120	4500K
WL20LED3K	20W LED Wall Light	120-277	3000K
WL20LED3KPC	20W LED Wall Light with Photocontrol	120	2000K

Options


ADD SUFFIX #	DESCRIPTION
PC	120V Photocontrol
PM	208-277V Photocontrol

Note: Atlas uses only premium LED compatible photocontrols

Performance

- Eliminates Glare & Offensive Light
- Less Wasted Light
- More Footcandles on the Ground
- Creates a Smooth & Uniform Light Pattern

Recommended Mounting Height - 8-10 ft.

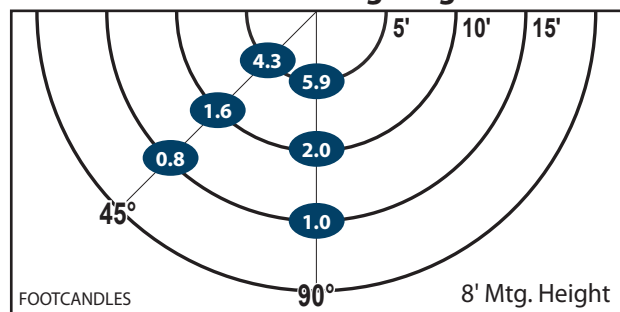


Dimensions and Specifications

Overall Height: 10.95"

Depth: 5.24"

Overall Width: 6.83"

Weight: 6 lbs.

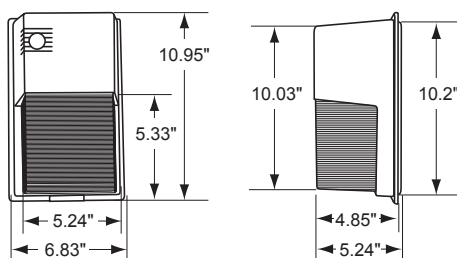

Mtg. Hgt.	FOOTCANDLES ON THE GROUND						Avg. FCs 450 SQ. FT.
	90°			45°			
	5'	10'	15'	5'	10'	15'	
8'	5.9	2.0	1.0	5.4	1.5	0.7	2.8
10'	4.3	1.8	1.0	4.3	1.6	0.8	2.3

200,000+ HOURS



*The majority of Atlas Lighting Products are assembled in USA facilities by an American Workforce utilizing both Domestic and Foreign components



Wall Light

20 Watt LED

Classic Series LED
TRADITIONAL HID REPLACEMENT



Glare Free

WL20LED

WATTS: 20

CCT: 4500K

CCT: 3000K

LUMENS: 1,788

LUMENS: 1,696

LPW: 92 CRI: 84

LPW: 87 CRI: 83

DIMMING: 10-100%

DIMMING: 10-100%

Ordering Information

CATALOG #	DESCRIPTION	VOLTS	COLOR TEMP
WL20LED	20W LED Wall Light	120-277	4500K
WL20LEDPC	20W LED Wall Light with Photocontrol	120	4500K
WL20LED3K	20W LED Wall Light	120-277	3000K
WL20LED3KPC	20W LED Wall Light with Photocontrol	120	2000K

Options


ADD SUFFIX #	DESCRIPTION
PC	120V Photocontrol
PM	208-277V Photocontrol

Note: Atlas uses only premium LED compatible photocontrols

Performance

- Eliminates Glare & Offensive Light
- Less Wasted Light
- More Footcandles on the Ground
- Creates a Smooth & Uniform Light Pattern

Recommended Mounting Height - 8-10 ft.

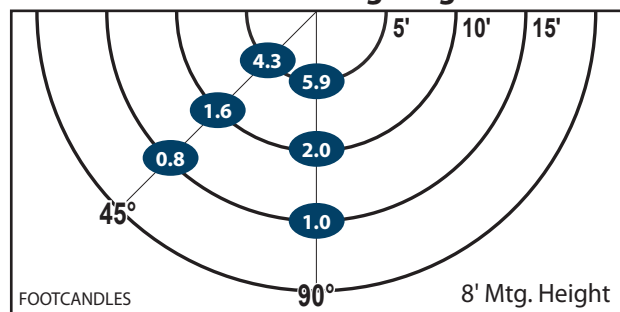


Dimensions and Specifications

Overall Height: 10.95"

Depth: 5.24"

Overall Width: 6.83"

Weight: 6 lbs.

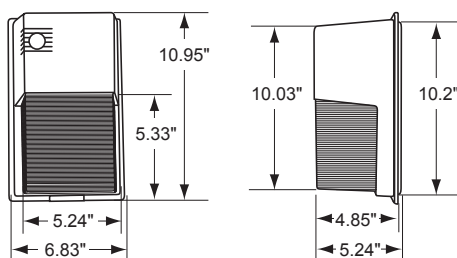

Mtg. Hgt.	FOOTCANDLES ON THE GROUND						Avg. FCs 450 SQ. FT.
	90°			45°			
	5'	10'	15'	5'	10'	15'	
8'	5.9	2.0	1.0	5.4	1.5	0.7	2.8
10'	4.3	1.8	1.0	4.3	1.6	0.8	2.3

200,000+ HOURS



*The majority of Atlas Lighting Products are assembled in USA facilities by an American Workforce utilizing both Domestic and Foreign components

