

Wall Light

20 Watt LED

Classic Series LED
TRADITIONAL HID REPLACEMENT



Glare Free

WL20LED

WATTS: 20

CCT: 4500K

LUMENS: 1,788

LPW: 92 CRI: 84

DIMMING: 10-100%

CCT: 3000K

LUMENS: 1,696

LPW: 87 CRI: 83

DIMMING: 10-100%

Ordering Information

| CATALOG # | DESCRIPTION | VOLTS | COLOR TEMP |
|--------------------|--------------------------------------|---------|------------|
| WL20LED | 20W LED Wall Light | 120-277 | 4500K |
| WL20LEDPC | 20W LED Wall Light with Photocontrol | 120 | 4500K |
| WL20LED3K | 20W LED Wall Light | 120-277 | 3000K |
| WL20LED3KPC | 20W LED Wall Light with Photocontrol | 120 | 2000K |

Options


| ADD SUFFIX # | DESCRIPTION |
|--------------|-----------------------|
| PC | 120V Photocontrol |
| PM | 208-277V Photocontrol |

Performance

- Eliminates Glare & Offensive Light
- Less Wasted Light
- More Footcandles on the Ground
- Creates a Smooth & Uniform Light Pattern

Note: Atlas uses only premium LED compatible photocontrols

Recommended Mounting Height - 8-10 ft.

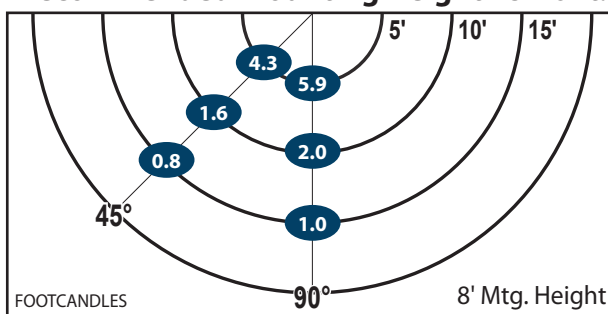


Dimensions and Specifications

Overall Height: 10.95"

Depth: 5.24"

Overall Width: 6.83"

Weight: 6 lbs.

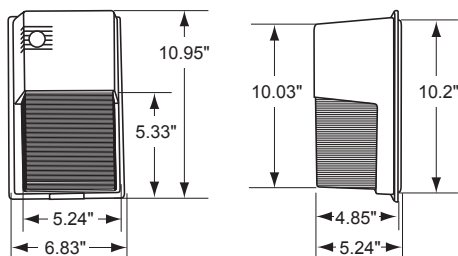

| FOOTCANDLES ON THE GROUND | | | | | | | |
|---------------------------|-----|-----|-----|-----|-----|-----|-------------------------|
| Mtg. Hgt. | 90° | | | 45° | | | Avg. FCs 450 SQ. FT. |
| | 5' | 10' | 15' | 5' | 10' | 15' | |
| 8' | 5.9 | 2.0 | 1.0 | 5.4 | 1.5 | 0.7 | 2.8 |
| 10' | 4.3 | 1.8 | 1.0 | 4.3 | 1.6 | 0.8 | 2.3 |

200,000+ HOURS



*The majority of Atlas Lighting Products are assembled in USA facilities by an American Workforce utilizing both Domestic and Foreign components



Wall Light

20 Watt LED

Classic Series LED
TRADITIONAL HID REPLACEMENT



Glare Free

WL20LED

WATTS: 20

CCT: 4500K

LUMENS: 1,788

LPW: 92 CRI: 84

DIMMING: 10-100%

CCT: 3000K

LUMENS: 1,696

LPW: 87 CRI: 83

DIMMING: 10-100%

Ordering Information

| CATALOG # | DESCRIPTION | VOLTS | COLOR TEMP |
|--------------------|--------------------------------------|---------|------------|
| WL20LED | 20W LED Wall Light | 120-277 | 4500K |
| WL20LEDPC | 20W LED Wall Light with Photocontrol | 120 | 4500K |
| WL20LED3K | 20W LED Wall Light | 120-277 | 3000K |
| WL20LED3KPC | 20W LED Wall Light with Photocontrol | 120 | 2000K |

Options


| ADD SUFFIX # | DESCRIPTION |
|--------------|-----------------------|
| PC | 120V Photocontrol |
| PM | 208-277V Photocontrol |

Performance

- Eliminates Glare & Offensive Light
- Less Wasted Light
- More Footcandles on the Ground
- Creates a Smooth & Uniform Light Pattern

Note: Atlas uses only premium LED compatible photocontrols

Recommended Mounting Height - 8-10 ft.

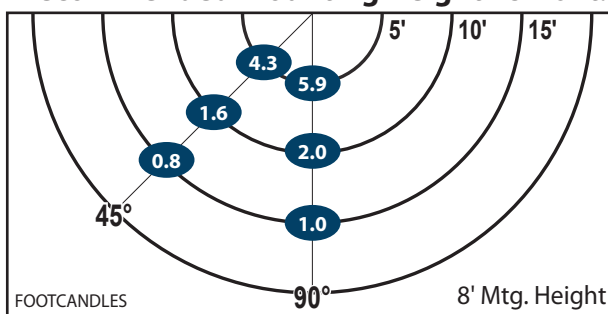


Dimensions and Specifications

Overall Height: 10.95"

Depth: 5.24"

Overall Width: 6.83"

Weight: 6 lbs.

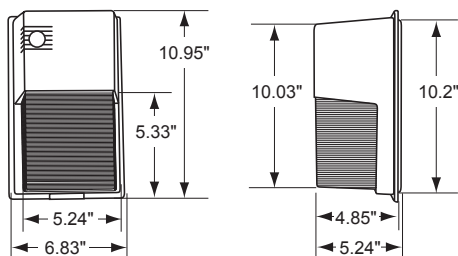

| FOOTCANDLES ON THE GROUND | | | | | | | |
|---------------------------|-----|-----|-----|-----|-----|-----|-------------------------|
| Mtg. Hgt. | 90° | | | 45° | | | Avg. FCs 450 SQ. FT. |
| | 5' | 10' | 15' | 5' | 10' | 15' | |
| 8' | 5.9 | 2.0 | 1.0 | 5.4 | 1.5 | 0.7 | 2.8 |
| 10' | 4.3 | 1.8 | 1.0 | 4.3 | 1.6 | 0.8 | 2.3 |

200,000+ HOURS



*The majority of Atlas Lighting Products are assembled in USA facilities by an American Workforce utilizing both Domestic and Foreign components

