

Wall Light

20 Watt LED

Classic Series LED
TRADITIONAL HID REPLACEMENT



Glare Free

WL20LED

WATTS: 20

CCT: 4500K

LUMENS: 1,788

LPW: 92 CRI: 84

DIMMING: 10-100%

CCT: 3000K

LUMENS: 1,696

LPW: 87 CRI: 83

DIMMING: 10-100%

Ordering Information

CATALOG #	DESCRIPTION	VOLTS	COLOR TEMP
WL20LED	20W LED Wall Light	120-277	4500K
WL20LEDPC	20W LED Wall Light with Photocontrol	120	4500K
WL20LED3K	20W LED Wall Light	120-277	3000K
WL20LED3KPC	20W LED Wall Light with Photocontrol	120	2000K

Options


ADD SUFFIX #	DESCRIPTION
PC	120V Photocontrol
PM	208-277V Photocontrol

Performance

- Eliminates Glare & Offensive Light
- Less Wasted Light
- More Footcandles on the Ground
- Creates a Smooth & Uniform Light Pattern

Note: Atlas uses only premium LED compatible photocontrols

Recommended Mounting Height - 8-10 ft.

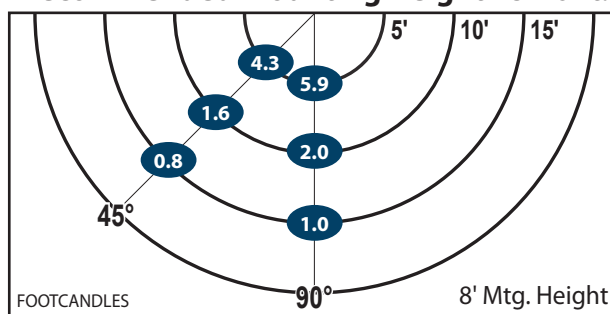


Dimensions and Specifications

Overall Height: 10.95"

Depth: 5.24"

Overall Width: 6.83"

Weight: 6 lbs.

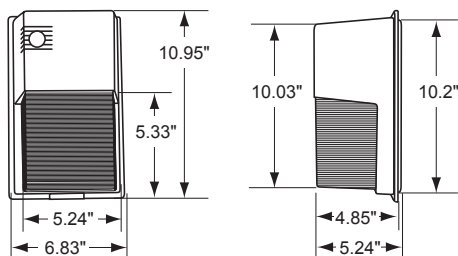

FOOTCANDLES ON THE GROUND							
Mtg. Hgt.	90°			45°			Avg. FCs 450 SQ. FT.
	5'	10'	15'	5'	10'	15'	
8'	5.9	2.0	1.0	5.4	1.5	0.7	2.8
10'	4.3	1.8	1.0	4.3	1.6	0.8	2.3

200,000+ HOURS



*The majority of Atlas Lighting Products are assembled in USA facilities by an American Workforce utilizing both Domestic and Foreign components

