

Glare Free



WATTS: 64

WLM64LED

CCT: 4500K

LUMENS: 6,349

LPW: 101 CRI: 83

DIMMING: 10-100%

CCT: 3000K

LUMENS: 5,699

LPW: 92 CRI: 81

DIMMING: 10-100%

Design is Protected by U.S. Patent No. 9,482,395



Ordering Information


CATALOG #	DESCRIPTION	VOLTS	COLOR TEMP
WLM64LED	64W LED Wall Light	120-277	4500K
WLM64LED3K	64W LED Wall Light	120-277	3000K

Options

ADD SUFFIX #	DESCRIPTION
PC	120V Photocontrol
PM	208-277V Photocontrol
EB	Emergency Back-Up
4	480V Driver

Note: Atlas uses only premium LED compatible photocontrols

Recommended Mounting Height - 16-18 ft.

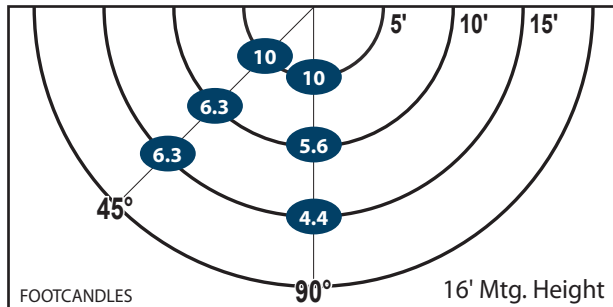

FOOTCANDLES ON THE GROUND							
Mtg. Hgt.	90°			45°			Avg. FCs 450 SQ. FT.
	5'	10'	15'	5'	10'	15'	
16'	10.0	6.3	6.3	10.0	5.6	4.4	7.1
18'	8.5	5.3	5.0	8.3	5.0	3.8	6.0

Performance

- **95% Efficient Reflector Targets the Light**
- **Eliminates Glare & Offensive Light**
- **Less Wasted Light**
- **More Footcandles on the Ground**
- **Creates a Smooth & Uniform Light Pattern**


Dimensions and Specifications

Overall Height: 9.02"


Overall Width: 14.2"

Depth: 7.85"

Weight: 9.2 lbs.

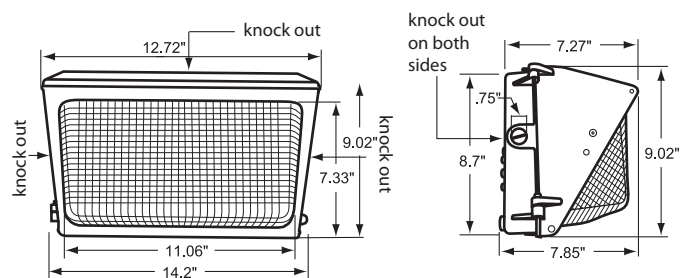

200,000+ HOURS

 

*The majority of Atlas Lighting Products are assembled in USA facilities by an American Workforce utilizing both Domestic and Foreign components



Glare Free



WATTS: 64

WLM64LED

CCT: 4500K

LUMENS: 6,349

LPW: 101 CRI: 83

DIMMING: 10-100%

CCT: 3000K

LUMENS: 5,699

LPW: 92 CRI: 81

DIMMING: 10-100%

Design is Protected by U.S. Patent No. 9,482,395



Ordering Information


CATALOG #	DESCRIPTION	VOLTS	COLOR TEMP
WLM64LED	64W LED Wall Light	120-277	4500K
WLM64LED3K	64W LED Wall Light	120-277	3000K

Options

ADD SUFFIX #	DESCRIPTION
PC	120V Photocontrol
PM	208-277V Photocontrol
EB	Emergency Back-Up
4	480V Driver

Note: Atlas uses only premium LED compatible photocontrols

Recommended Mounting Height - 16-18 ft.

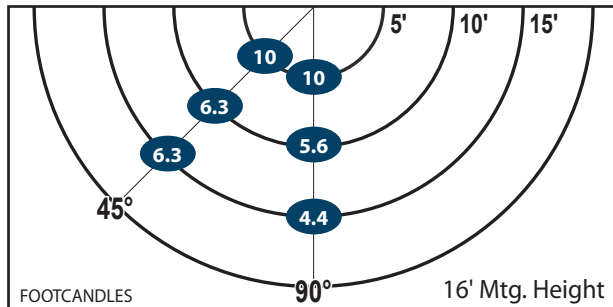

FOOTCANDLES ON THE GROUND							
Mtg. Hgt.	90°			45°			Avg. FCs 450 SQ. FT.
	5'	10'	15'	5'	10'	15'	
16'	10.0	6.3	6.3	10.0	5.6	4.4	7.1
18'	8.5	5.3	5.0	8.3	5.0	3.8	6.0

Performance

- **95% Efficient Reflector Targets the Light**
- **Eliminates Glare & Offensive Light**
- **Less Wasted Light**
- **More Footcandles on the Ground**
- **Creates a Smooth & Uniform Light Pattern**


Dimensions and Specifications

Overall Height: 9.02"


Overall Width: 14.2"

Depth: 7.85"

Weight: 9.2 lbs.

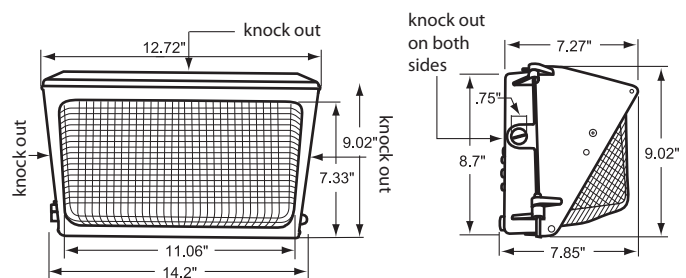

200,000+ HOURS

 

*The majority of Atlas Lighting Products are assembled in USA facilities by an American Workforce utilizing both Domestic and Foreign components

