



# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

3804 South Street  
75964-7263, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685



## WMGLT3 3/4" LT Wire Mesh Grip

*Thomas&Betts-Abb Ins Prod*

Catalog Number	WMGLT3
Manufacturer	Thomas&Betts-Abb Ins Prod
Description	
Weight per unit	0.1200 (lbs/each)
Product Category	Liquid Tight Fittings

### Features

Material	Stainless Steel Standard
----------	--------------------------

### Dimensions and Weight

Size	3/4 INCH
------	----------

### Descriptions

Description	3/4" LT WIRE MESH GRIP
Product Type	Repartit Effort Pour Racc Etanc 3/4

### Manufacturer Information

Brand	Thomas & Betts
GTIN	00786210776255
Manufacturers Part Number	WMG-LT3
UPC	786210776255

### Taxonomies, Classifications, and Categories

Category Description	CORD CONNECTORS & CORD GRIPS
Type	Wiremesh Grips

### Packaging


Carton	10
Package	50
Weight Per each	0.12

### Uses, Certifications, and Standards

Application	Prevents severe conduit bends and pullout.
standard	UL E23018, CSA

## 52®/53® Series Liquidtight Fittings and Flexible Metallic Conduits

### Nylon-Insulated CHASE® Connectors

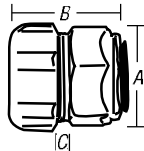


Steel or malleable iron with O-Ring Seal

CAT. NO.	CONDUIT SIZE	DIMENSIONS (IN.)		
		A	B	C
5361 <sup>†</sup>	3/8"	1 1/2	1 3/8	1/8
5362 <sup>†</sup>	1/2"	1 3/8	1 3/8	3/16
5363 <sup>†</sup>	3/4"	1 11/16	1 3/8	1/4
5364 <sup>†</sup>	1"	2 1/2	2 1/16	1/4
5365 <sup>†</sup>	1 1/4"	2 3/8	2 3/8	3/16
5366 <sup>†</sup>	1 1/2"	2 5/16	2 3/4	3/8
5367 <sup>†</sup>	2"	3 3/16	3	3/8
5368 <sup>†</sup>	2 1/2"	4 3/8	3 15/16	1/16
5369 <sup>†</sup>	3"	5 1/8	4 1/8	1/2
5370 <sup>†</sup>	4"	5 1/8	4 1/8	1/2

With SAFE-EDGE® ground cone and double bevel sealing ring (through 2").

<sup>†</sup> UL listed as grounding means under NEC 351-7.

### Nylon-Insulated 90° Angle CHASE® Connectors

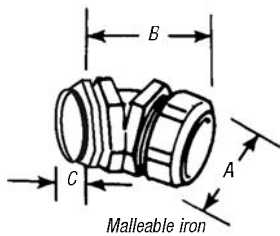

Malleable iron


CAT. NO.	CONDUIT SIZE	DIMENSIONS (IN.)		
		A	B	C
5371 <sup>†</sup>	3/8"	1 1/2	1 1/2	3/16
5372 <sup>†</sup>	1/2"	1 15/64	1 13/32	3/16
5373 <sup>†</sup>	3/4"	1 31/64	1 1/8	3/32
5374 <sup>†</sup>	1"	1 23/32	2 1/4	1 1/32

With SAFE-EDGE® ground cone and double bevel sealing ring.

**Note:** UL Listed Liquidtight; & CSA certified watertight. Suitable for hazardous locations use in Class I, Div. 2; Class II, Div. 1 and 2; Class III, Div. 1 and 2, where general purpose equipment is specifically permitted per NEC® Section 500-2(a).

<sup>†</sup> UL listed as grounding means under NEC 351-7.

### Standard Liquidtight Female Hub Adapter

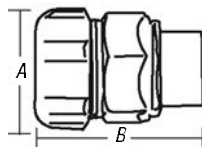

CAT. NO.	CONDUIT SIZE	DIMENSIONS (IN.)	
		A	B
5271 <sup>†</sup>	3/8"	1 1/2	1 3/16
5272 <sup>†</sup>	1/2"	1 3/8	1 11/16
5273 <sup>†</sup>	3/4"	1 7/8	1 3/4
5274 <sup>†</sup>	1"	1 3/8	2 1/8
5275 <sup>†</sup>	1 1/4"	2 3/8	2 1/2
5276 <sup>†</sup>	1 1/2"	2 3/4	2 11/16
5277 <sup>†</sup>	2"	3 1/2	3 1/8

<sup>†</sup> UL Listed as grounding means under NEC 351-7.

Prevents severe conduit bends and pullout!

### Wiremesh Grips for Liquidtight Fittings



CAT. NO.	CONDUIT SIZE	LIQUIDTIGHT CONNECTORS					
		STRAIGHT	45°	90°	CHASE	90° CHASE	ADAPTER
WMG-LT1	3/8"	5331	5341	5351	5361	5371	5271
WMG-LT2	1/2"	5332	5342	5352	5362	5372	5272
WMG-LT3	3/4"	5333	5343	5353	5363	5373	5273
WMG-LT4	1"	5334	5344	5354	5364	5374	5274
WMG-LT5	1 1/4"	5335	5345	5355	5365	—	5275
WMG-LT6	1 1/2"	5336	5346	5356	5366	—	5276
WMG-LT7	2"	5337	5347	5357	5367	—	5277
WMG-LT8	2 1/2"	5338	5348	5358	5368	—	5278
WMG-LT9	3"	5339	5349	5359	5369	—	5279
WMG-LT10	4"	5340	5350	5360	5370	—	5282

Order wiremesh grip separately; no need to duplicate inventory.

UL File No. E23018

CSA File No. 2884 & 4484