



# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

3804 South Street  
75964-7263, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685



## X207EG 4 Hole Flat Splice Plate Electro Gal Fitting

*Thomas&Betts-Abb Ins Prod*

|                  |  |
|------------------|--|
| Catalog Number   | X207EG   |
| Manufacturer     | Thomas&Betts-Abb Ins Prod  |
| Description      | Splice Plate, Steel, Electro-Galvanized, 7-1/4 In Length, 1/4 In Thickness, 9/16 In Hole Size, 4 Holes, 73.19 LB/100 |
| Weight per unit  | 0.7300 (lbs/each)  |
| Product Category | Channel & Strut Fittings   |

### Dimensions and Weight

|                |              |
|----------------|--------------|
| Overall Length | 7-1/4 Inches |
|----------------|--------------|

### Descriptions

|             |  |
|-------------|--|
| Description | 4 HOLE FLAT SPLICE PLATE ELECTRO GAL FITTING |
|-------------|--|

### Manufacturer Information

|       |                |
|-------|----------------|
| Brand | Superstrut     |
| GTIN  | 00616013011348 |
| UPC   | 616013011348   |


### Taxonomies, Classifications, and Categories

|                      |                               |
|----------------------|-------------------------------|
| Category Description | MISC FITTINGS                 |
| Type                 | Fittings, Brackets & Hardware |


### Packaging

|                 |      |
|-----------------|------|
| Carton          | 25   |
| Weight Per each | 0.73 |

## Fittings and Brackets

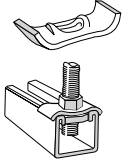


**CAT. NO. AB-242**  
For use with either 3/8" or 1/2" hanger rod

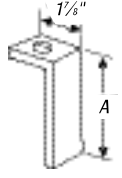


**CAT. NO. AB252**


| CAT. NO. | A (IN.) | STD. CTN. |
|----------|---------|-----------|
| AB252 1  | 3 7/8   | 10        |
| AB252 2  | 5 7/8   | 10        |
| AB252 3  | 7 7/8   | 10        |
| AB252 4  | 9 7/8   | 10        |

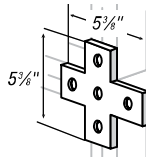


**CAT. NO. AB253**

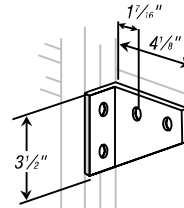


**CAT. NO. AB254 L**

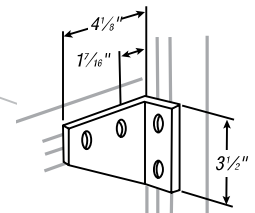


**CAT. NO. AB254 R**

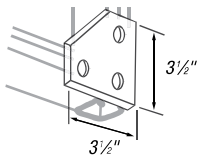


**CAT. NO. AB255**

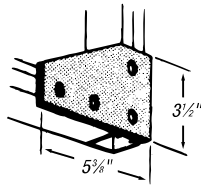


**CAT. NO. AB257**

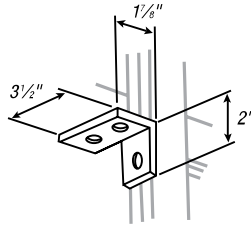


**CAT. NO. AB260 L**

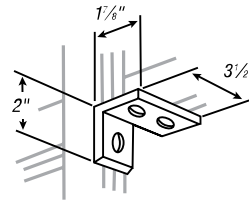


**CAT. NO. AB260 R**

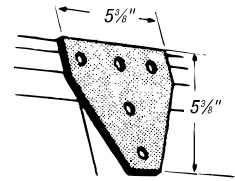


**CAT. NO. AB261**

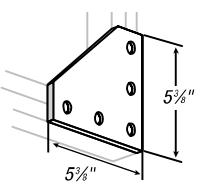


**CAT. NO. AB263**

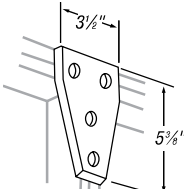


**CAT. NO. AB265**

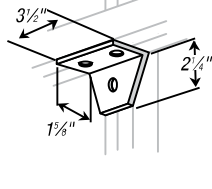


**CAT. NO. AB274**

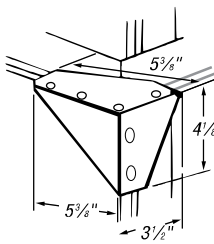


**CAT. NO. AB284 L**

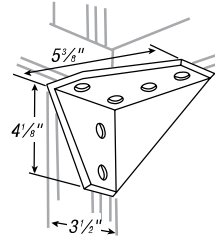


**CAT. NO. AB284 R**

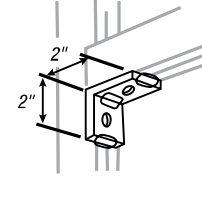


**CAT. NO. AB299**

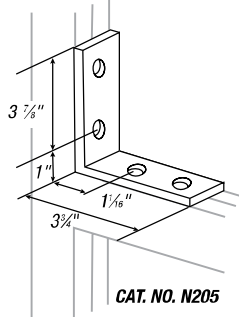


**CAT. NO. N205**

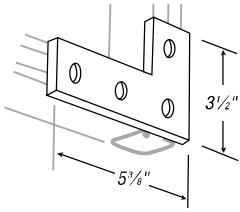


**CAT. NO. N-219**

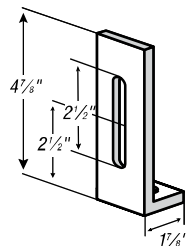


**CAT. NO. X201**

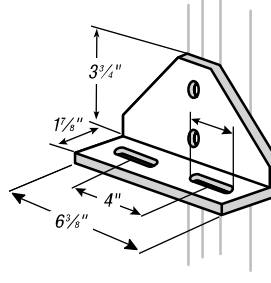


**CAT. NO. X204**  
Slot size is 3/16" x 1 1/2"

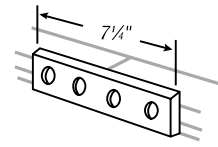


**CAT. NO. X207**

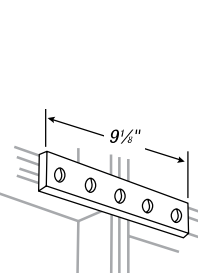

**CAT. NO. X208**

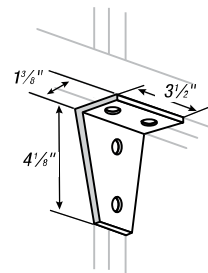

**CAT. NO. X289**

 

**CAT. NO. X299**

### Standard Dimensions

- Hole Spacing: 13/16" From End
- Hole Spacing: 1 7/8" Centers
- Hole Size: 3/16" Diameter
- Material: 1 1/2" Width
- Material: 1/4" Thick

Standard Finish – GoldGalv®, unless otherwise stated.  
Add EG suffix for SilverGalv® Finish