


Specifications

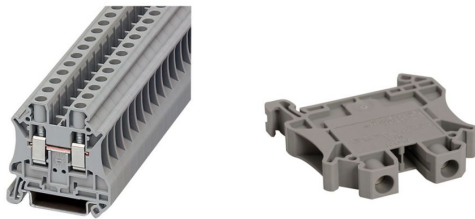

Eaton XBUT6

Eaton XB IEC terminal block, Screw connection single level through-feed terminal block, 8.2 mm, Gray, 8 AWG/6 mm² maximum wire, IEC 800V, EN 700V, UL 600V, IEC #24-8 AWG, EN #24-8 AWG, UL #24-8 AWG wire

General specifications

PRODUCT NAME	Eaton XB IEC terminal block
CATALOG NUMBER	XBUT6
UPC	782116904945
PRODUCT LENGTH/DEPTH	1.75 in
PRODUCT HEIGHT	2.17 in
PRODUCT WIDTH	0.1 in
PRODUCT WEIGHT	0.01 lb
WARRANTY	1 year
CERTIFICATIONS	UL Listed CSA Certified
PRODUCT TYPE	Terminal block



Powering Business Worldwide

Product specifications

TYPE	IEC-XB Series
AMPERAGE RATING	527 (IEC), 40A (EN), 50A (EN), 50A (UL)
VOLTAGE RATING	IEC 800V, EN 700V, UL 600V

Resources

SPECIFICATIONS AND DATASHEETS	Eaton Specification Sheet - XBUT6
-------------------------------	---

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:



Eaton Corporation plc Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2026 Eaton. All Rights Reserved.

Follow us on social media to get the latest product and support information.

