




YGHC34C29 Compression Grounding C-TAP Connector

By Burndy
Catalog # [YGHC34C29](#)

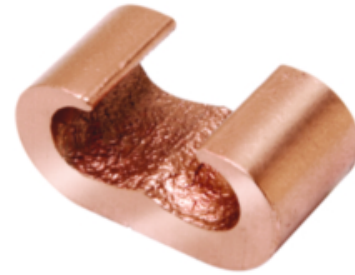

Copper Compression C Connector, 300-500 kcmil (Run) & 3/0 AWG(Str) - 250 kcmil (Tap).

Application

For Direct Burial Cables

General

Connector Type	Tap
Die Index	1011
EU RoHS Indicator	Yes
Material	Copper
Physical Attribute - Number of Crimps Required	2
Plated	N
Plating Type	Unplated
Sub Brand	HYGROUND, HYTAP
Trade Name	HYTAP™
Type	Taps
UPC	781810221075
UPC 12 Digit	7818102210755

Dimensions

Dimension - B Length inch	0.88 in
Dimension - Height fraction	2-2/3 in
Dimension - Height inch	2.67 in
Dimension - L Length Overall mm	22 mm
Dimension - Length Overall inch	0.88 in

Conductor Related

Conductor - Copper Str Run	300 kcmil;350 kcmil;400 kcmil;450 kcmil;500 kcmil
Conductor - Copper Str Run Range	300 kcmil-500 kcmil
Conductor - Copper Str Tap	3/0 AWG;4/0 AWG;250 kcmil
Conductor - Copper Str Tap Range	3/0 AWG-250 kcmil

Certifications and Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	Direct Burial
Standards - Industry Standards Met	UL467;IEEE 837;UL468A-468B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

[3D Models - YGHC34C29_MODEL-PDF](#)
[3D Models - YGHC34C29_MODEL-IGES](#)
[3D Models - YGHC34C29_MODEL-STEP](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - SD086223-01](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRDY-YGHC34C29-SPEC-EN | REV 8/2023