




# YGHC34C34 Compression Grounding C-TAP Connector

By Burndy  
Catalog # [YGHC34C34](#)

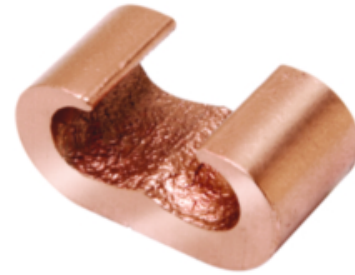

Copper Compression C Connector, 300-500 kcmil (Run & Tap).

## Application

For Direct Burial Cables

## General

Connector Type	Tap
Die Index	1011
EU RoHS Indicator	Yes
Material	Copper
Physical Attribute - Number of Crimps Required	3
Plated	N
Plating Type	Unplated
Sub Brand	HYGROUND, HYTAP
Trade Name	HYTAP™
Type	Taps
UPC	781810221082
UPC 12 Digit	7818102210822

## Dimensions

Dimension - B Length inch	1.10 in
Dimension - Height fraction	2-81/89 in
Dimension - Height inch	2.91 in
Dimension - L Length Overall mm	28 mm
Dimension - Length Overall inch	1.10 in

## Conductor Related

Conductor - Copper Str Run	300;350;400;450;500
Conductor - Copper Str Run Range	300-500
Conductor - Copper Str Tap	300;350;400;450;500
Conductor - Copper Str Tap Range	300-500

## Certifications and Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	Direct Burial
Standards - Industry Standards Met	<ul style="list-style-type: none"><li>UL467</li><li>IEEE 837</li><li>UL468A-468B</li></ul>
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Carton Quantity	20
Minimum Pack Quantity	1
Pallet Quantity	2960

## Product Assets

[3D Models - YGHC34C34\\_MODEL-PDF](#)  
[3D Models - YGHC34C34\\_MODEL-IGES](#)  
[3D Models - YGHC34C34\\_MODEL-STEP](#)  
[Catalogs - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - SD086223-01](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRDY-YGHC34C34-SPEC-EN | REV 8/2023